

REV. A

DCO 300781

TOLERANCES $\pm .010"$ - UNLESS OTHERWISE SPECIFIED

COIL: @ 25°C

RESISTANCE 320 OHMS $\pm 10\%$

NOMINAL VOLTAGE 28 VDC

MUST OPERATE 13.5 VDC MAX.

MUST RELEASE 5.5 VDC MAX., 2.3 VDC MIN.

ENVIRONMENT:

VIBRATION 10 Hz TO 3000 Hz @ 30 g's

SHOCK 200 g's 6 MS. DURATION


TEMPERATURE -70 °C TO +125 °C

NOTES: OPERATE, RELEASE 10 MS MAX.

CONTACT STABILIZATION 2.5 MS MAX.

CONTACT BOUNCE 1 MS MAX.

CUSTOMER DATA SHEET

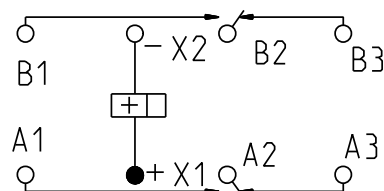

TERMINAL VIEW

CONTACT RATING: LOW LEVEL
TO 10 AMPS 28 VDC, 115 VAC 400 Hz RESISTIVE,
100,000 OPERATIONS

DR. B.D. 06MAR2008

CK. 3/7/08 J.M.B.

Tyco Electronics

©COPYRIGHT 2005

TYCO ELECTRONICS CORPORATION
ALL INTERNATIONAL RIGHTS RESERVED

CUST. NO. M83536/9-023L REV. ---

TE NUMBER
9-1617748-7

CII PART NUMBER
FCA-210-0923L

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[TE Connectivity:](#)

[9-1617748-7](#)