


REVISIONS					
P	LTR	DESCRIPTION	DATE	DWN	APVD
	A	INITIAL RELEASE	25FEB2016	N.P	X.X

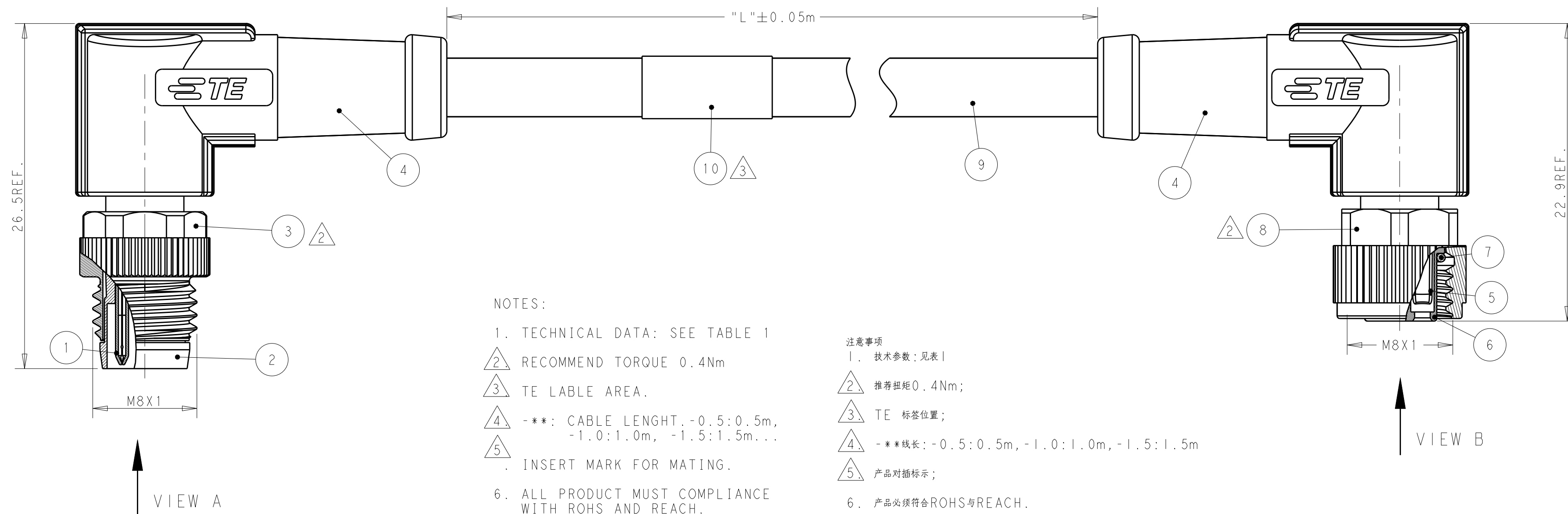

NOTES:

1. TECHNICAL DATA: SEE TABLE 1
2. RECOMMEND TORQUE 0.4Nm
3. TE LABLE AREA.
4. -**: CABLE LENGHT. -0.5:0.5m,
-1.0:1.0m, -1.5:1.5m...
5. INSERT MARK FOR MATING.
6. ALL PRODUCT MUST COMPLIANCE WITH ROHS AND REACH.

注意事项

1. 技术参数: 见表1
2. 推荐扭矩 0.4Nm;
3. TE 标签位置;
4. ***线长: -0.5:0.5m, -1.0:1.0m, -1.5:1.5m
5. 产品对插标示;
6. 产品必须符合ROHS与REACH.

TABLE 1

TECHNICAL DATA	T40522X4003-00X	T40522X4004-00
RATED VOLTAGE	60V	30V
RATED CURRENT	3A	
POLLETION DEGREE	3	
OVERVOLTAGE CATEGORY	II	
MATERIAL GROUP	II	
DEGREE OF PROTECTION	IP67	

		TE LABLE	10
		CABLE	9
	COPPER ALLOY	NUT	8
	RUBBER	O-RING	7
	PA66	HOUSING	6
	COPPER ALLOY	CONTACT	5
	POLYURETHANE	OVER-MOLDING	4
-	COPPER ALLOY	COUPLING NUT	3
BALCK COLOR	PA66	HOUSING	2
GOLD FLASH	COPPER ALLOY	CONTACT	1
COMMENTS	MATERIAL	DESCRIPTON	ITEM

WIRES: 0.25mm ² (24AWG)	-001: 0.5m	FIXED: -25°C~80°C FLXIBLE: -10°C~80°C	GRAY	PUR (UL)	RPC-M8-4MR-**-M8-4FR-PUR	4	4	T4052224004-00X
	-002: 1.0m				RPC-M8-3MR-**-M8-3FR-PUR	4	3	T4052224003-00X
	-003: 1.5m	FIXED: -10°C~80°C FLXIBLE: -5°C~80°C	BLACK	PVC (UL)	RPC-M8-4MR-**-M8-4FR-PVC	4	4	T4052214004-00X
	-004: 3.0m				RPC-M8-3MR-**-M8-3FR-PVC	4	3	T4052214003-00X
	-005: 5.0m							
	-006: 7.0m							
	-007: 10.0m							
CABLE CHARACTERISTIC	LENGTH "L"	RECOMMEND OPERATION TEMPERATURE FOR CABLE	JACKET COLOR	JACKET MATERIAL	TYPE		POS.	PART NUMBER
THIS DRAWING IS A CONTROLLED DOCUMENT.				DWN Nick Pan CHK Kobby Zhao APVD Xiang Xu	TE TE Connectivity			
DIMENSIONS: mm 		TOLERANCES UNLESS OTHERWISE SPECIFIED: 0 PLC ±- 1 PLC ±0.50 2 PLC ±0.35 3 PLC ±- 4 PLC ±- ANGLES ±- FINISH		PRODUCT SPEC 108-106140 APPLICATION SPEC - WEIGHT -		NAME M8 CABLE ASSEMBLY UNSHIELDED DOUBLE ENDED TYPE - SIZE CAGE CODE DRAWING NO A2 - C-T40522X400X00X RESTRICTED TO		
MATERIAL TBD material 2		finish spec 2		CUSTOMER DRAWING		SCALE 1:1 SHEET 1 of 1 REV A		

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[TE Connectivity:](#)

[T4052224004-007](#)