


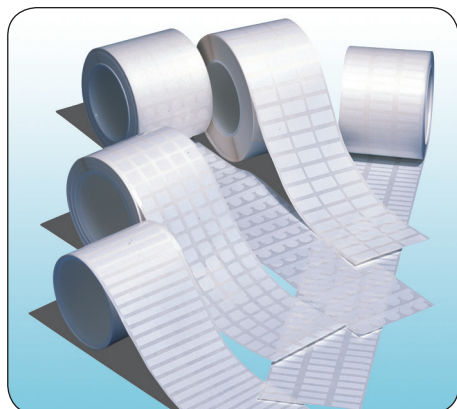

## Introducing White Polyester Chemical Resistant Labels

The white polyester chemical resistant labels are designed to provide clear identification even in the most demanding environments. The chemically resistant matte top coat ensures excellent heat resistance and dimensional stability. The aggressive permanent acrylic adhesive and high tack, high shear characteristics of the WPCR labels can be used in a number of low surface energy applications for rating plates, rack and panel or labelling electronic device and equipment. The labels are abrasion resistant and withstand exposure to commercial and military aviation fluids and solvents.

### KEY FEATURES

- Special top coat locks in thermal transfer printing without adding a laminate
- Thermal transfer print on demand
- Excellent dimensional stability at elevated temperatures
- Excellent chemical resistance
- Resists abrasion

### APPLICATIONS

- Rating plates, rack & panel
- Bar code labeling
- Electronic device and equipment labeling
- General purpose labeling

### MATERIALS

White polyester with a special chemical resistant top coat, pressure sensitive permanent acrylic adhesive

### PRODUCT DIMENSIONS

| Part Number        | Description        | Label Width |      | Label Height |      |
|--------------------|--------------------|-------------|------|--------------|------|
|                    |                    | mm          | inch | mm           | inch |
| <b>8-1899709-2</b> | WPCR-101165-0.85-9 | 101,6       | 4    | 165,1        | 6.5  |
| <b>8-1899709-3</b> | WPCR-101635-2.5-9  | 101,6       | 4    | 63,5         | 2.5  |
| <b>8-1899709-4</b> | WPCR-101762-1.8-9  | 101,6       | 4    | 76,2         | 3    |
| <b>8-1899709-5</b> | WPCR-127127-10-9   | 12,7        | 0.5  | 12,7         | 0.5  |
| <b>8-1899709-6</b> | WPCR-191114-15-9   | 19,1        | 0.75 | 11,4         | 0.45 |
| <b>8-1899709-7</b> | WPCR-254064-10-9   | 25,4        | 1    | 6,4          | 0.25 |
| <b>8-1899709-8</b> | WPCR-254097-10-9   | 25,4        | 1    | 9,7          | 0.38 |
| <b>8-1899709-9</b> | WPCR-254127-10-9   | 25,4        | 1    | 12,7         | 0.5  |
| <b>9-1899709-0</b> | WPCR-381127-5-9    | 38,1        | 1.5  | 12,7         | 0.5  |
| <b>9-1899709-1</b> | WPCR-381191-5-9    | 38,1        | 1.5  | 19,1         | 0.75 |
| <b>9-1899709-2</b> | WPCR-508254-5-9    | 50,8        | 2    | 25,4         | 1    |
| <b>9-1899709-3</b> | WPCR-508318-2.5-9  | 50,8        | 2    | 31,8         | 1.25 |
| <b>9-1899709-5</b> | WPCR-508508-3-9    | 50,8        | 2    | 50,8         | 2    |
| <b>9-1899709-7</b> | WPCR-610419-2.5-9  | 61          | 2.4  | 41,9         | 1.65 |
| <b>9-1899709-9</b> | WPCR-699254-5-9    | 69,9        | 2.75 | 25,4         | 1    |
| <b>1899710-3</b>   | WPCR-762381-2.5-9  | 76,2        | 3    | 38,1         | 1.5  |
| <b>1899710-6</b>   | WPCR-762508-2.5-9  | 76,2        | 3    | 50,8         | 2    |

While TE has made every reasonable effort to ensure the accuracy of the information in this document, TE does not guarantee that it is error-free, nor does TE make any other representation, warranty or guarantee that the information is accurate, correct, reliable or current. TE reserves the right to make any adjustments to the information contained herein at any time without notice. TE expressly disclaims all implied warranties regarding the information contained herein, including, but not limited to, any implied warranties of merchantability or fitness for a particular purpose. The dimensions in this document are for reference purposes only and are subject to change without notice. Specifications are subject to change without notice. Consult TE for the latest dimensions and design specifications.

[te.com/products/identification-labeling](http://te.com/products/identification-labeling)



# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[TE Connectivity:](#)

[CT92173001](#)