

REV. 2 11/20/97

#### COIL:

RESISTANCE 400 OHMS

NOMINAL VOLTAGE 12.0 VDC

MUST OPERATE 8.4 VDC

MUST RELEASE

#### ENVIRONMENT:

VIBRATION 10 CPS TO 500 CPS @ 10 g's


SHOCK 30 g's 6 MS. DURATION

TEMPERATURE -55 °C TO +85 °C

NOTES: OPERATE TIME 4.0 MS MAX.

RELEASE TIME 3.0 MS MAX.

#### CUSTOMER DATA SHEET

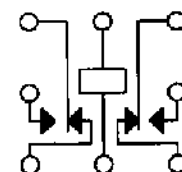

CONTACT RATING: LOW LEVEL TO 1 AMP  
28 VDC RESISTIVE 100,000 OPERATIONS MIN.

DR. R.B. 9/7/90

CK ~~10/21/97~~ 11/21/97



COMMUNICATIONS  
INSTRUMENTS, INC.

CUST. C.I.I. STD.

CUST. NO.

TYPE "HC" RELAY

HC-12B

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[TE Connectivity:](#)

[1617109-1](#)