


REV. 1 9/14/98

COIL: @ +25 °C
 RESISTANCE 700 OHMS ± 20%
 NOMINAL VOLTAGE 26.5 VDC
 MUST OPERATE 16.0 VDC
 MUST RELEASE

ENVIRONMENT:
 VIBRATION 10 CPS TO 500 CPS @ 10 g's
 SHOCK 30 g's 6 ± 1 MS. DURATION
 TEMPERATURE -55 °C TO +85 °C

NOTES: OPERATE & RELEASE 6 MS MAX.

CUSTOMER DATA SHEET

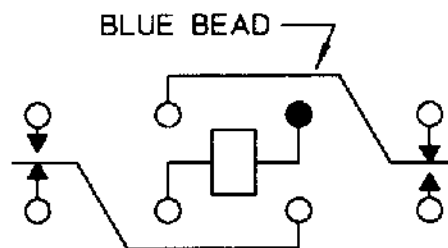

CONTACT RATING: LOW LEVEL TO 5A
 RESISTIVE 100,000 OPERATIONS

DR. R.B. 8/26/98 CK. 9/14/98

COMMUNICATIONS
 INSTRUMENTS, INC.

CUST. C. I. I. STD.
 CUST. NO.

TYPE HFC5A RELAY

HFC5A1201K00

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[TE Connectivity:](#)

[1617026-1](#)