

REV. 1 11/21/97

COIL:

RESISTANCE 390 OHMS \pm 10%

NOMINAL VOLTAGE 12.0 VDC

MUST OPERATE 8.4 VDC

MUST RELEASE

ENVIRONMENT:

VIBRATION 10 CPS TO 500 CPS @ 10 g's


SHOCK 30 g's 6 MS. DURATION

TEMPERATURE -55 °C TO +85 °C

NOTES: OPERATE TIME 4.0 MS MAX

RELEASE TIME 3.0 MS MAX

CUSTOMER DATA SHEET

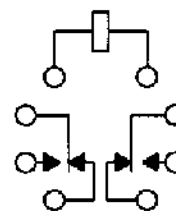

CONTACT RATING: LOW LEVEL TO 1A
28 VDC RESISTIVE 100,000 OPERATIONS

DR. R.B. 11/15/93 CK Jerry 11/21/97

**COMMUNICATIONS
INSTRUMENTS, INC.**

CUST. C. I. I. STD.

CUST. NO.

TYPE "HM" RELAY

HM-12B

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[TE Connectivity:](#)

[1-1617109-1](#)