


REV. 1 11/20/97

COIL: @ 25°C
 RESISTANCE 50 OHMS \pm 10%
 NOMINAL VOLTAGE 5.0 VDC
 MUST OPERATE 3.6 VDC
 MUST RELEASE

ENVIRONMENT:
 VIBRATION 10 CPS TO 500 CPS @ 10 g's
 SHOCK 30 g's 6 MS. DURATION
 TEMPERATURE -55 °C TO +85 °C

NOTES: OPERATE TIME 4.0 MS MAX.
 RELEASE TIME 3.0 MS MAX.

CUSTOMER DATA SHEET

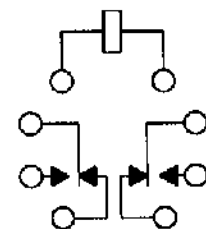

CONTACT RATING: LOW LEVEL TO 1A
 28 VDC RESISTIVE 100,000 OPERATIONS

DR. R.B. 10/29/97 *[Signature]* 11/21/97

**COMMUNICATIONS
 INSTRUMENTS, INC.**

CUST. C. I. I. STD.
 CUST. NO.

TYPE "HM" RELAY

HM-5B

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[TE Connectivity:](#)

[1-1617109-4](#)