


COIL: @ 25°C
 RESISTANCE 100 OHMS \pm 10%
 NOMINAL VOLTAGE 5.0 VDC
 MUST OPERATE 3.5 VDC
 MUST RELEASE 1.7 VDC MAX, 0.23 VDC MIN.

ENVIRONMENT:
 VIBRATION 10 CPS TO 3000 CPS @ 30 g's
 SHOCK 75 g's 6 MS. DURATION
 TEMPERATURE -65 °C TO +125 °C

NOTES: OPERATE TIME 4.0 MS MAX.
RELEASE TIME 7.5 MS MAX.
CONTACT BOUNCE 1.5 MS MAX.

CUSTOMER DATA SHEET

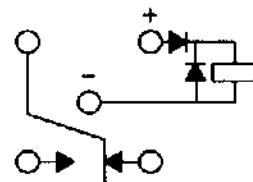

CONTACT RATING: LOW LEVEL TO 1A
28 VDC RESISTIVE 100,000 OPERATIONS

DR. R.B. 2/6/98 CK JERRY C 2/6/98

**COMMUNICATIONS
INSTRUMENTS, INC.**

CUST. QPL
 CUST. NO. M39016/26-033L

TYPE J1MSDD RELAY

J1MSCDD-5XL

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[TE Connectivity:](#)

[2-1617162-4](#)