

REV. 0


DCO 141310

COIL: @ 25°C	
RESISTANCE	1130 OHMS ±10%
NOMINAL VOLTAGE	26.5 VDC
MUST OPERATE	18.0 VDC
MUST RELEASE	1.23 VDC MIN.

ENVIRONMENT:	
VIBRATION	140 CPS TO 2000 CPS @ 100 g's
SHOCK	150 g's 11 MS. DURATION
TEMPERATURE	-65 °C TO +125 °C

NOTES:	OPERATE TIME 6.0 MS MAX
	RELEASE TIME 2.0 MS MAX
	CONTACT BOUNCE 1.5 MS MAX

CUSTOMER DATA SHEET

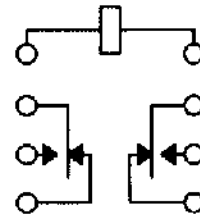

TERMINAL VIEW

CONTACT RATING: LOW LEVEL TO
1A 28 VDC RESISTIVE 100,000
OPERATIONS

DR. B.D. 8/26/99 *CKX/ERRY 8/26/99*

COMMUNICATIONS
INSTRUMENTS, INC.

CUST. C. I. I.
CUST. NO. STD REV. _____

"MAV" RELAY

MAVC-26S2

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[TE Connectivity:](#)

[3-1617594-9](#)