

REV. 1 3/23/99

DCO 140960

COIL: @ 25°C

RESISTANCE 1560 OHMS ± 10%

NOMINAL VOLTAGE 26.5 VDC

MUST OPERATE 14.2 VDC

MUST RELEASE 1.37 VDC

ENVIRONMENT:

VIBRATION 10 CPS TO 3000 CPS @ 30 g's

SHOCK 75 g's 6 MS. DURATION


TEMPERATURE -65 °C TO +125 °C

NOTES: OPERATE TIME 2.0 MS MAX

RELEASE TIME 1.5 MS MAX

CONTACT BOUNCE 1.5 MS MAX

## CUSTOMER DATA SHEET

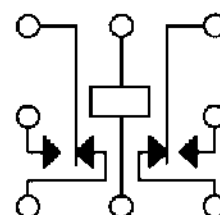

TERMINAL VIEW

CONTACT RATING: LOW LEVEL TO 1 AMP  
28 VDC RESISTIVE 100,000 OPERATIONS

DR. R.B. 4/16/97 (CK) JERRY C 3-23-99

COMMUNICATIONS  
INSTRUMENTS, INC.

CUST. C.I.I. STD.

CUST. NO.

TYPE 'MGA' RELAY

MGAP-26

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[TE Connectivity:](#)

[1617155-1](#)