


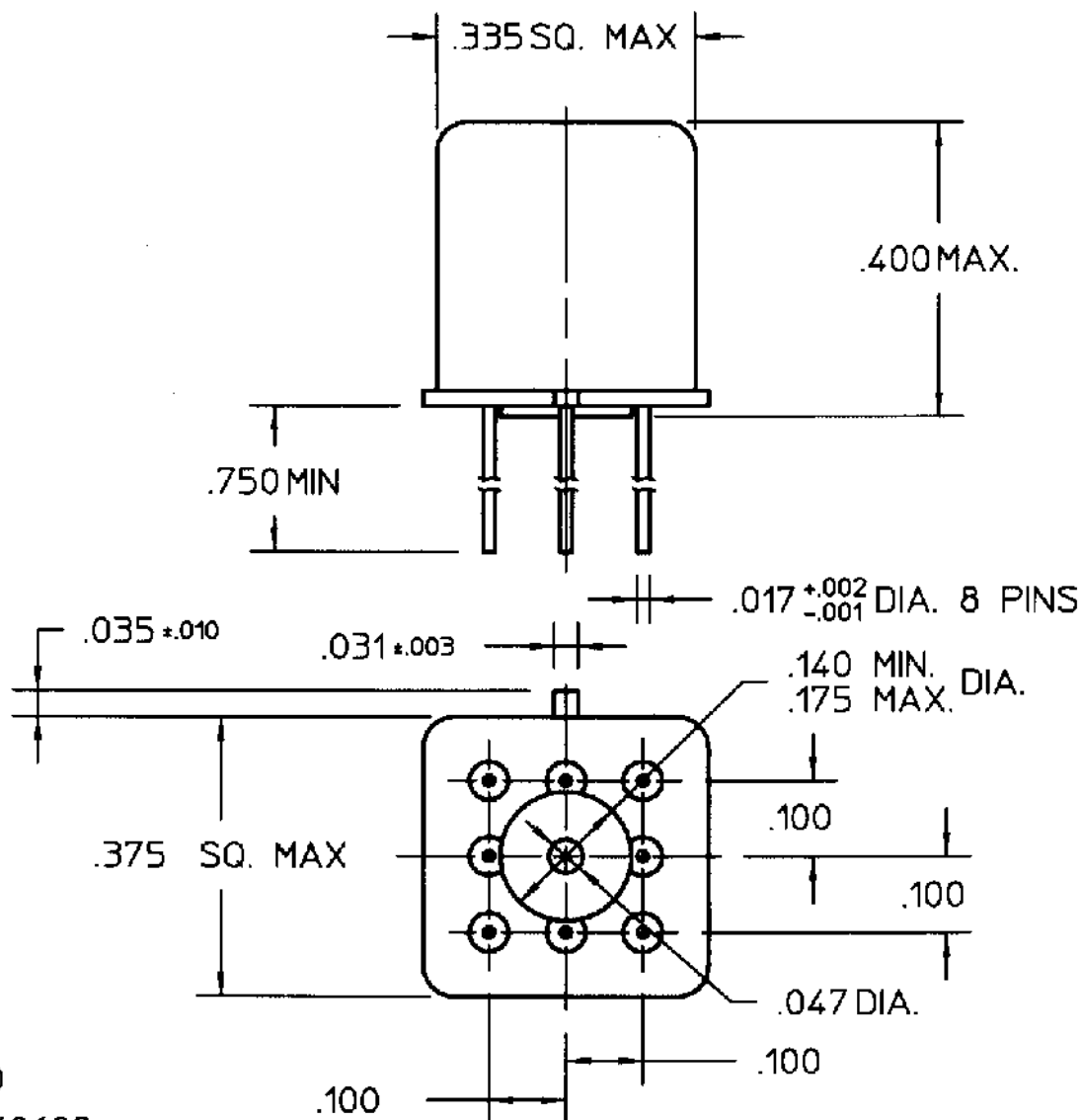

REV. 0
DCO 140689


COIL: @ 25°C
RESISTANCE 3200 OHMS ± 10%
NOMINAL VOLTAGE 26.5 VDC
MUST OPERATE 14.0 VDC
MUST RELEASE 1.4 VDC

ENVIRONMENT:

VIBRATION 10 CPS TO 3000 CPS @ 30 g's
SHOCK 75 g's 6 MS. DURATION
TEMPERATURE -65 °C TO +125 °C

NOTES: OPERATE TIME 4.0 MS MAX
RELEASE TIME 2.0 MS MAX
CONTACT BOUNCE 1.5 MS MAX

CUSTOMER DATA SHEET

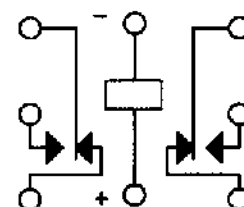

TERMINAL VIEW

CONTACT RATING: LOW LEVEL TO 1 AMP
28 VDC RESISTIVE 100,000 OPERATIONS MIN

DR. R.B. 12/7/98 *CK/JP/C* 12/7/98

COMMUNICATIONS
INSTRUMENTS, INC.

CUST. C. I. I.
CUST. NO. COTS STD.

TYPE PRMGSC RELAY

PRMGSC-26XW

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[TE Connectivity:](#)

[3-1617109-2](#)