


REV. 0  
DCO 144089

COIL: @ 25°C	
RESISTANCE	3300 OHMS ±10%
NOMINAL VOLTAGE	26.5 VDC
MUST OPERATE	14.0 VDC
MUST RELEASE	8.0 VDC MAX., 1.4 VDC MIN.

ENVIRONMENT:	
VIBRATION	10 Hz TO 3000 Hz @ 30 g's
SHOCK	75 g's 6 MS. DURATION
TEMPERATURE	-65 °C TO +125 °C
NOTES:	OPERATE TIME 4.0 MS MAX.
	RELEASE TIME 7.5 MS MAX.
	CONTACT BOUNCE 1.5 MS MAX.

## CUSTOMER DATA SHEET

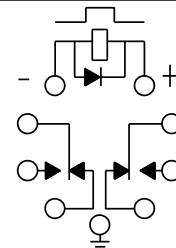

TERMINAL VIEW

CONTACT RATING: LOW LEVEL TO 1A  
28 VDC RESISTIVE 100,000 OPERATIONS

DR. B.D. 31AUG2005 CK. JERRY C. 9/2/05

**CII Technologies**  
advanced control electronic solutions

CUST. CII  
CUST. NO. COTS STD REV.

"PRMSD" RELAY

PRMSCDG-26X

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[TE Connectivity:](#)

[2-1617570-3](#)