


4

3


2

1

LOC	DIST	REVISIONS				
CM	0	P	LTR	DESCRIPTION	DATE	APVD
			AK2	ECO-06-017742	26JUL06	BSV

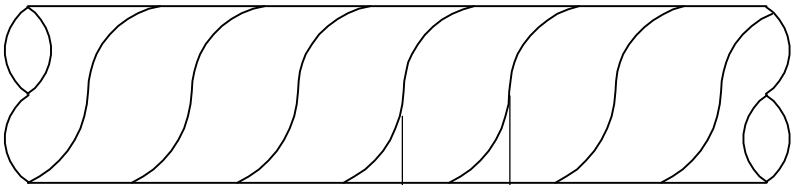

5.54±0.38
[.218±.015]

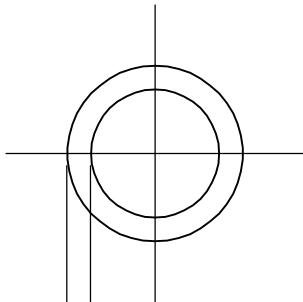

0.79±0.15
[.031±.006]

1. MAX BUNDLE RANGE: 1.60[.063] TO 12.70[.500]
2. WEIGHT PER 304.8M[1000ft]: 1.81kg[4lb].
3. OVERALL LENGTH TO BE WITHIN +1 Ft -0 Ft.
4. ONE SPLICE PER BOX IS ALLOWABLE.

SUBSIDIARY USE ONLY	76.2M [250 FT] BOX	NATURAL	500000-4
	30.48M [100 FT] BOX	NATURAL	500000-2
	15.24M [50 FT] BOX	NATURAL	500000-1
	LENGTH	COLOR	PART NUMBER

THIS DRAWING IS A CONTROLLED DOCUMENT.		DWN W.CHANDLER	14DEC93	<div><div>tyco</div><div>Electronics</div></div> <div>Tyco Electronics Corporation Harrisburg, PA 17105-3608</div>		
DIMENSIONS: mm [INCHES]		CHK W.CHANDLER	05JAN94			
	TOLERANCES UNLESS OTHERWISE SPECIFIED: 0 PLC ± - 1 PLC ± - 2 PLC ± - 3 PLC ± - 4 PLC ± - ANGLES ± -	APVD D. KAAT		NAME SPIRAP, POLYETHYLENE, 1/8 INCH DIAMETER		
		PRODUCT SPEC		SIZE A3		
		APPLICATION SPEC		CAGE CODE 00779		
MATERIAL POLYETHYLENE	FINISH -	WEIGHT -		DRAWING NO C-500000		
CUSTOMER DRAWING				SCALE 4:1	SHEET 1 OF 1	REV AK2

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[TE Connectivity:](#)

[500000-1](#)