




D

C

B

A

printed on 2 Jul 2021 11:06 (China Standard Time) from TE343646

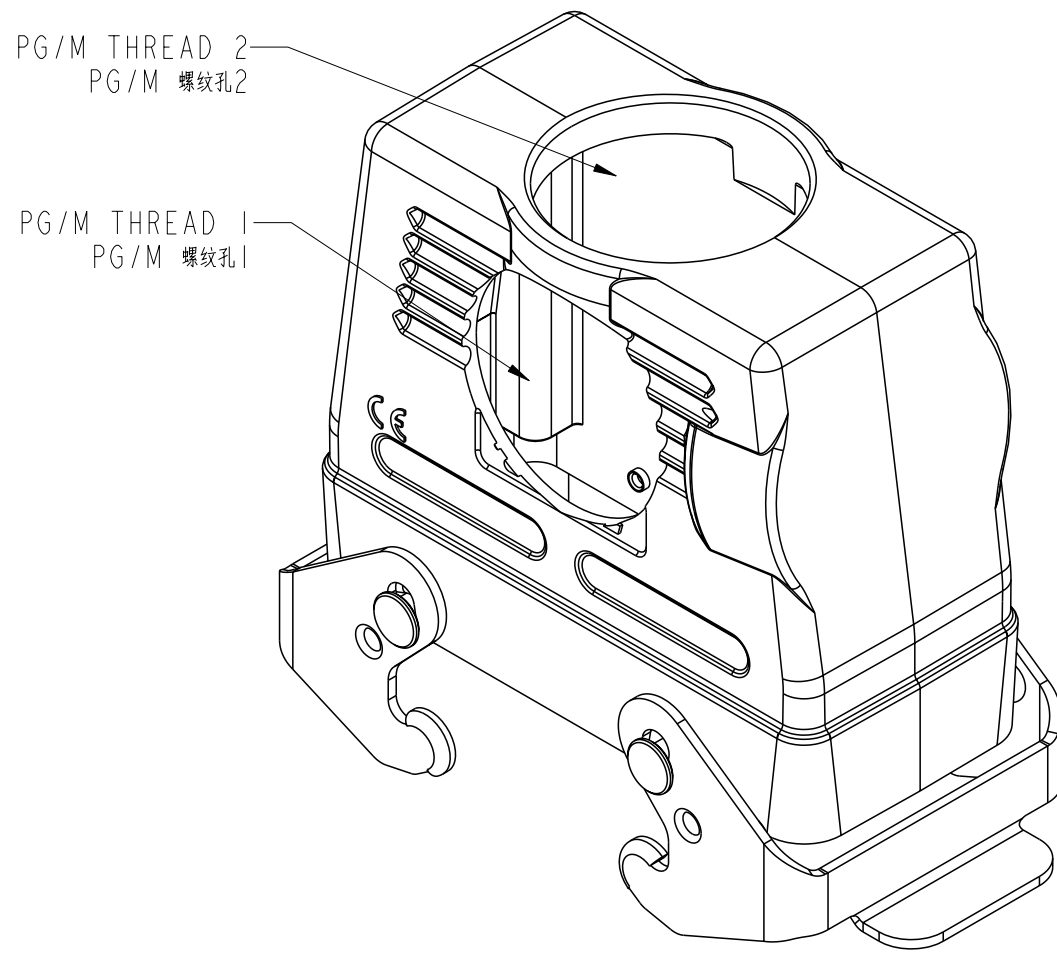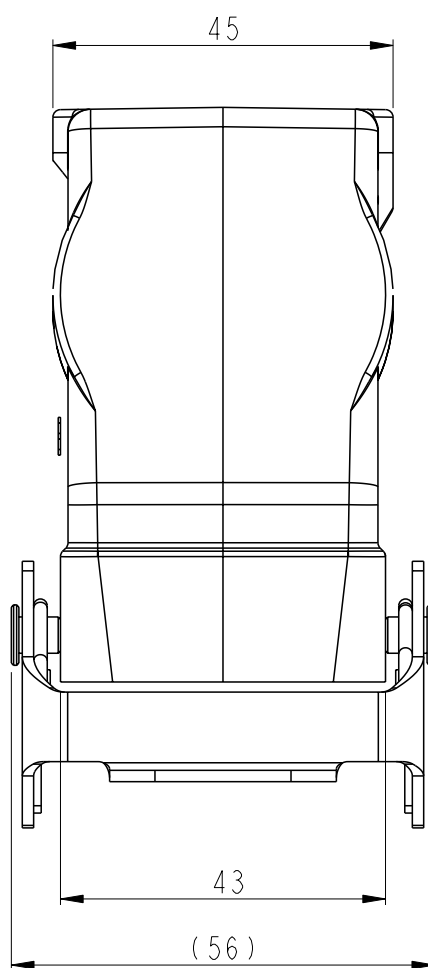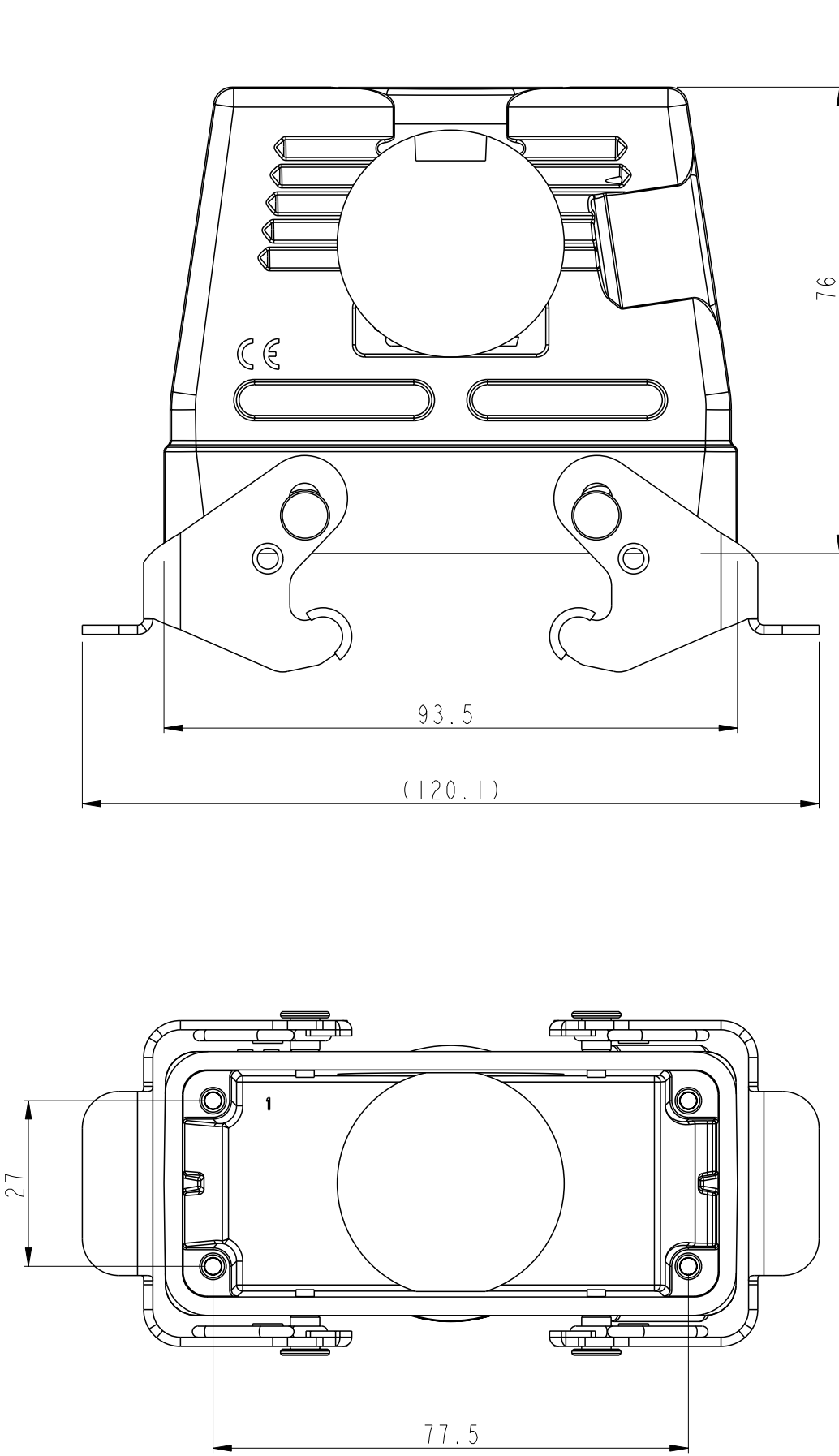

TYPE 5: HIGH CONSTRUCTION, TOP & FRONT ENTRY
WITH STEEL DOUBLE LOCKING
OTHER SPEC REFER TO TYPE 4

类型5：高结构，顶出和前出，带彩锌双扣，其它规格参照类型4

T1290162929-000	HI6B-TGBH/TFBH-PG29/PG29	HI6B HOOD, TOP AND FRONT ENTRY PG29, METAL DOUBLE LOCKING, HIGH CONSTRUCTION, POWDER COATED, GREY HI6B上壳, 顶出和前出PG29, 彩锌双扣, 高结构, 灰色粉末喷涂	PG29	PG29	TYPE5 类型5																		
PART NUMBER 料号	PART DESCRIPTION 描述		PG/M THREAD 1 PG/M 螺纹孔1	PG/M THREAD 2 PG/M 螺纹孔2	TYPE 类型																		
THIS DRAWING IS A CONTROLLED DOCUMENT. <table><tr><td>DIMENSIONS: mm</td><td>TOLERANCES UNLESS OTHERWISE SPECIFIED:</td></tr><tr><td></td><td>0 PLC ±- 1 PLC ±- 2 PLC ±- 3 PLC ±- 4 PLC ±- ANGLES ±- FINISH</td></tr><tr><td>MATERIAL</td><td></td></tr><tr><td>-</td><td>-</td></tr><tr><td>-</td><td>-</td></tr></table>		DIMENSIONS: mm	TOLERANCES UNLESS OTHERWISE SPECIFIED:		0 PLC ±- 1 PLC ±- 2 PLC ±- 3 PLC ±- 4 PLC ±- ANGLES ±- FINISH	MATERIAL		-	-	-	-	DWN01AUG2018 JEREMY.ZHANG CHK01AUG2018 GINO.WANG APVD01AUG2018 CHRIS.WANG PRODUCT SPEC 108-137013 APPLICATION SPEC 114-137013 WEIGHT - Customer Drawing TE Connectivity NAME HI6B-TSB/TGB/TGBH/TSBH/TFBH-M/PG <table><tr><td>SIZE A2</td><td>CAGE CODE 00779</td><td>DRAWING NO C-T12X01621XX000</td><td>RESTRICTED TO -</td></tr><tr><td colspan="3">SCALE 1:1</td><td>SHEET 3 OF 3</td></tr></table> REV B1				SIZE A2	CAGE CODE 00779	DRAWING NO C-T12X01621XX000	RESTRICTED TO -	SCALE 1:1			SHEET 3 OF 3
		DIMENSIONS: mm	TOLERANCES UNLESS OTHERWISE SPECIFIED:																				
			0 PLC ±- 1 PLC ±- 2 PLC ±- 3 PLC ±- 4 PLC ±- ANGLES ±- FINISH																				
		MATERIAL																					
		-	-																				
-	-																						
SIZE A2	CAGE CODE 00779	DRAWING NO C-T12X01621XX000	RESTRICTED TO -																				
SCALE 1:1			SHEET 3 OF 3																				

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[TE Connectivity:](#)

[T1280162129-000](#)