



REVISIONS					
P	LTR	DESCRIPTION	DATE	DWN	APVD
	A	NEW DRAWING	08MAY2020	GK	DB

LABEL AND LINER DESIGN

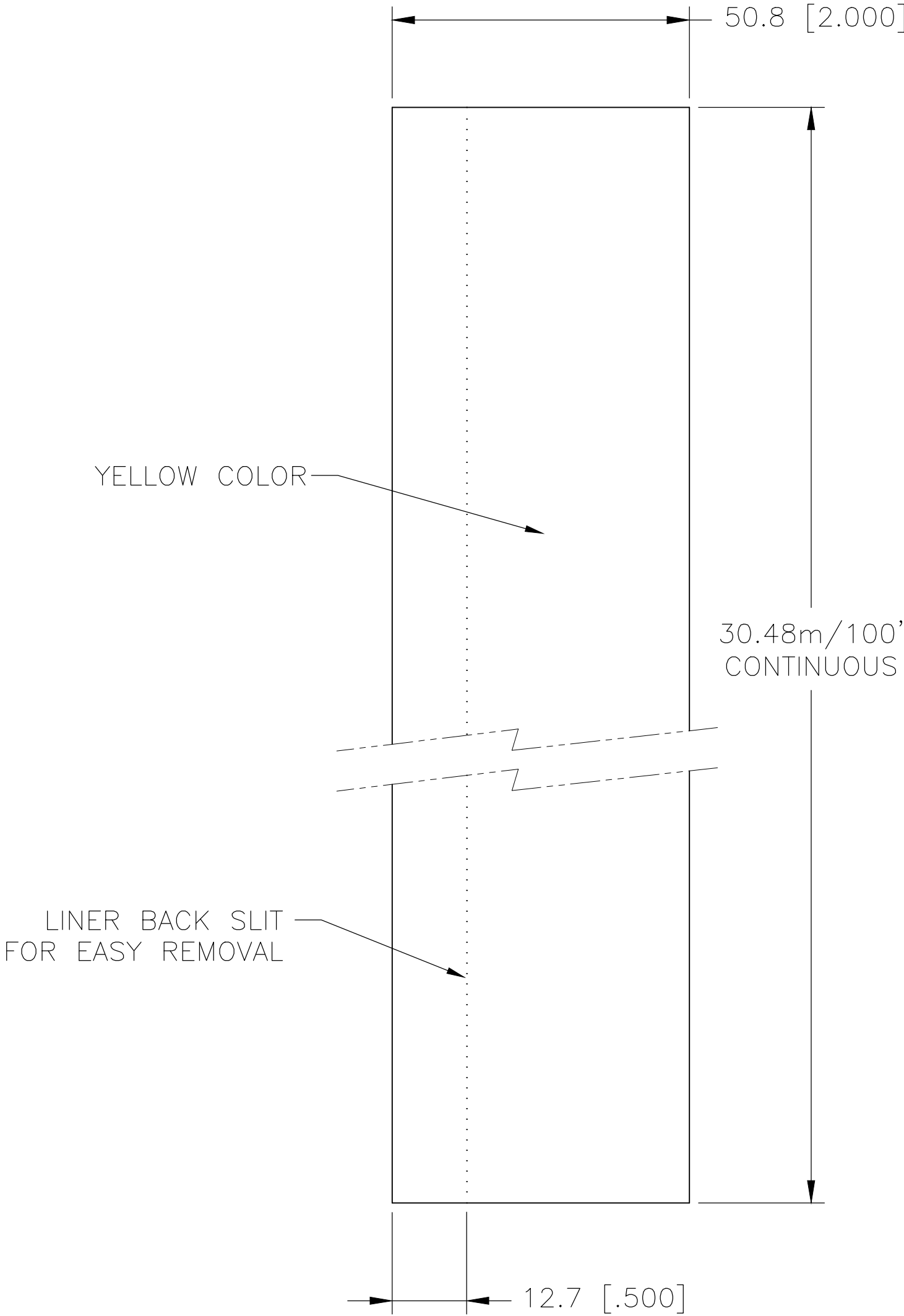

PRESENTATION

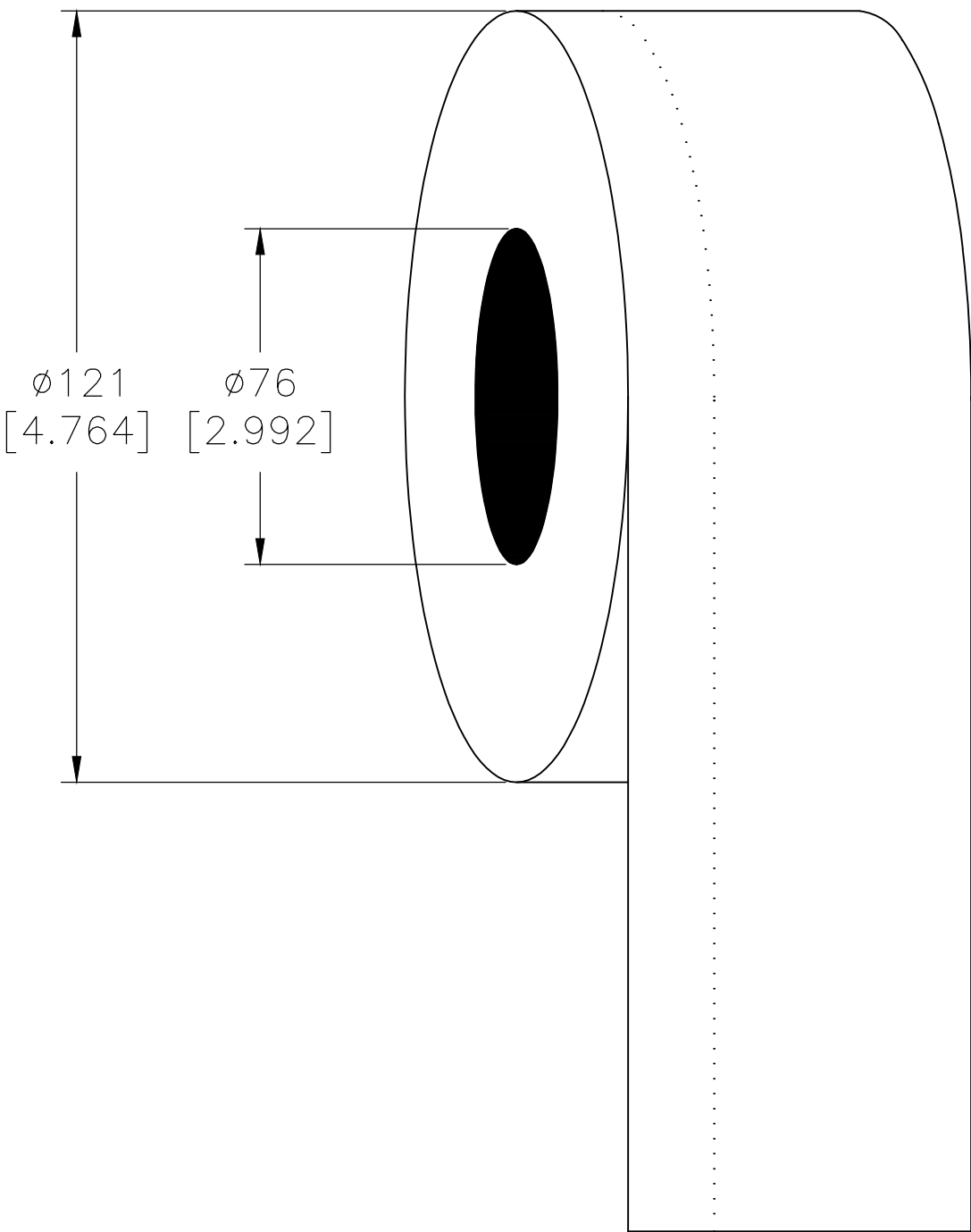

All dimensions in mm [Inch]

TE PN: 097370-000

OUTSIDE WOUND (BACK SLIT LEFT)
LABEL ACROSS: 1
PER ROLL QTY: 30.48m / 100 feet

TOLERANCES mm [INCH]	
LABEL HEIGHT:	±0.3 [.012]
LABEL WIDTH:	±0.3 [.012]
WEB WIDTH:	±0.8 [.031]
VERTICAL REPEAT:	±0.8 [.031]*
HORIZONTAL REPEAT:	±0.8 [.031]*
PRINT POSITIONING:	±0.8 [.031]*
LEFT MARGIN:	±0.4 [.016]
QUANTITY:	-0 % +2 %
*NON ACCUMULATING	

THIS DRAWING IS A CONTROLLED DOCUMENT.	
DIMENSIONS: mm [INCHES]	TOLERANCES UNLESS OTHERWISE SPECIFIED:
	0 PLC ± 1 PLC ± 2 PLC ± 3 PLC ± 4 PLC ± ANGLES ±
MATERIAL SEE TABLE	FINISH GLOSS

MATERIAL	POLYVINYL FLUORIDE (TEDLAR®)		
ADHESIVE TYPE	PERMANENT ACRYLIC		
LINEAR	BROWN KRAFT		
DWN GOPALAKRISHNA HV CHK D.BURGAT APVD D.BURGAT PRODUCT SPEC TTDS-005 APPLICATION SPEC	NAME TEDLAR® LABEL - YELLOW - CONTINUOUS 50.8mm x 30.4m (2inch x 100ft) -		
WEIGHT 212g	SIZE A2	CAGE CODE FB1U7	DRAWING NO C=TTVF200YW-100
CUSTOMER DRAWING	SCALE NTS	SHEET 1 OF 1	RESTRICTED TO REV A

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[TE Connectivity:](#)

[TTVF200YW-100](#)