

#### COIL:

RESISTANCE 90  $\Omega$   $\pm$  10%  
 NOMINAL VOLTAGE 12.0 VDC  
 MUST OPERATE 6.7 VDC  
 MUST RELEASE 1.0 VDC MIN.

#### ENVIRONMENT:


VIBRATION 10 CPS TO 2000 CPS @ 20 g's  
 SHOCK 100 g's 6 MS. DURATION  
 TEMPERATURE -65 °C TO +125 °C

NOTES: OPERATE TIME 13 MS MAX.

RELEASE TIME 5 MS MAX.

CONTACT BOUNCE 5 MS MAX. (NO)  
2 MS MAX. (NO)

#### CUSTOMER DATA SHEET

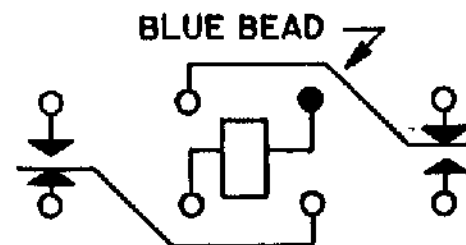

CONTACT RATING: 10A 30VDC RES  
10A 115 VAC 400 HZ, 6A 30 VDC  
INDUCTIVE 100,000 OPERATIONS

DR. R.B. 4-16-91 CK. A/16/9 10m28



Communications  
Instruments, Inc.

CUST. HI-G  
 CUST. NO. 2I-1B-112

TYPE 07 RELAY

**B07B932BZ1-8004**

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[TE Connectivity:](#)

[B07B932BZ1-8004](#)