

REV. 1 7/17/92

COIL:

RESISTANCE 700 OHMS \pm 10%

NOMINAL VOLTAGE 26.5 VDC

MUST OPERATE 13.5 VDC

MUST RELEASE 1.5 VDC

ENVIRONMENT:


VIBRATION 10 CPS TO 2000 CPS @ 20 g's

SHOCK 100 g's 6 MS. DURATION

TEMPERATURE -65 °C TO +125 °C

NOTES:

CUSTOMER DATA SHEET

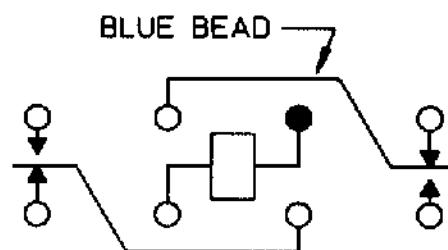

CONTACT RATING: 2A 30 VDC
RESISTIVE .75A 30 VDC INDUCTIVE
100,000 OPERATIONS

DR. R.B. 12/4/91 CK. 7/17/92

**COMMUNICATIONS
INSTRUMENTS, INC.**

CUST. Hi-G
 CUST. NO. 2K-1C-126

TYPE "HFW" RELAY

HFW1140S01

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[TE Connectivity:](#)

[HFW1140S01](#)