

Two aluminum housed resistors are shown, one above the other, connected to two black wires. The resistors have a ribbed, cylindrical body and a small notch at one end. A vertical dark blue line is positioned to the right of the resistors.

## ALUMINUM HOUSED RESISTOR TYPE HCL SERIES

TE Connectivity (TE)'s Aluminum Housed Resistor Type HCL Series are designed in a ultra slim package capable of dissipating high power where space is at a premium and heat sinking is available. The resistor is capable of absorbing high overloads in relation to its size. Aluminum Housed Resistor Type HCL Series are ideal for use in servo drives & controllers and frequency inverters. They are used for motor braking, dummy loads and in conventional power resistor applications.

### BENEFITS


- Ultra slim package 7.25mm
- High power to size ratio
- High overload capability
- UL approved

### APPLICATIONS

- Servo drives
- Controllers
- Frequency inverter


# Aluminum Housed Resistor Type HCL Series

## PART NUMBER LIST

Product Image	Base PN	TCPN	Description
	<b>2176489</b>	2176489-1	HCL130 70W 3R3 5% CABLE 150MM
		2176489-2	HCL130 70W 3R9 5% CABLE 150MM
		2176489-3	HCL130 70W 4R7 5% CABLE 150MM
		2176489-4	HCL130 70W 5R6 5% CABLE 150MM
		2176489-5	HCL130 70W 6R8 5% CABLE 150MM
		2176489-6	HCL130 70W 8R2 5% CABLE 150MM
		2176489-7	HCL130 70W 10R 5% CABLE 150MM
		2176489-8	HCL130 70W 12R 5% CABLE 150MM
		2176489-9	HCL130 70W 15R 5% CABLE 150MM
		1-2176489-0	HCL130 70W 18R 5% CABLE 150MM
		1-2176489-1	HCL130 70W 22R 5% CABLE 150MM
		1-2176489-2	HCL130 70W 27R 5% CABLE 150MM
		1-2176489-3	HCL130 70W 33R 5% CABLE 150MM
		1-2176489-4	HCL130 70W 39R 5% CABLE 150MM
		1-2176489-5	HCL130 70W 47R 5% CABLE 150MM
		1-2176489-6	HCL130 70W 56R 5% CABLE 150MM
		1-2176489-7	HCL130 70W 68R 5% CABLE 150MM
		1-2176489-8	HCL130 70W 82R 5% CABLE 150MM
		1-2176489-9	HCL130 70W 100R 5% CABLE 150MM
		2-2176489-0	HCL130 70W 120R 5% CABLE 150MM
		2-2176489-1	HCL130 70W 150R 5% CABLE 150MM
		2-2176489-2	HCL130 70W 180R 5% CABLE 150MM
		2-2176489-3	HCL130 70W 220R 5% CABLE 150MM
		2-2176489-4	HCL130 70W 270R 5% CABLE 150MM
		2-2176489-5	HCL130 70W 330R 5% CABLE 150MM
		2-2176489-6	HCL130 70W 390R 5% CABLE 150MM
		2-2176489-7	HCL130 70W 470R 5% CABLE 150MM
		2-2176489-8	HCL130 70W 560R 5% CABLE 150MM
		2-2176489-9	HCL130 70W 680R 5% CABLE 150MM
		3-2176489-0	HCL130 70W 820R 5% CABLE 150MM
		3-2176489-1	HCL130 70W 1K0 5% CABLE 150MM
		3-2176489-2	HCL130 70W 1K2 5% CABLE 150MM
		3-2176489-3	HCL130 70W 1K5 5% CABLE 150MM
		3-2176489-4	HCL130 70W 1K8 5% CABLE 150MM
		3-2176489-5	HCL130 70W 2K2 5% CABLE 150MM
		3-2176489-6	HCL130 70W 2K7 5% CABLE 150MM
		3-2176489-7	HCL130 70W 3K3 5% CABLE 150MM


# Aluminum Housed Resistor Type HCL Series

## PART NUMBER LIST

Product Image	Base PN	TCPN	Description
	2176490	2176490-1	HCL165 100W 4R7 5% CABLE 150MM
		2176490-2	HCL165 100W 5R6 5% CABLE 150MM
		2176490-3	HCL165 100W 6R8 5% CABLE 150MM
		2176490-4	HCL165 100W 8R2 5% CABLE 150MM
		2176490-5	HCL165 100W 10R 5% CABLE 150MM
		2176490-6	HCL165 100W 12R 5% CABLE 150MM
		2176490-7	HCL165 100W 15R 5% CABLE 150MM
		2176490-8	HCL165 100W 18R 5% CABLE 150MM
		2176490-9	HCL165 100W 22R 5% CABLE 150MM
		1-2176490-0	HCL165 100W 27R 5% CABLE 150MM
		1-2176490-1	HCL165 100W 33R 5% CABLE 150MM
		1-2176490-2	HCL165 100W 39R 5% CABLE 150MM
		1-2176490-3	HCL165 100W 47R 5% CABLE 150MM
		1-2176490-4	HCL165 100W 56R 5% CABLE 150MM
		1-2176490-5	HCL165 100W 68R 5% CABLE 150MM
		1-2176490-6	HCL165 100W 82R 5% CABLE 150MM
		1-2176490-7	HCL165 100W 100R 5% CABLE 150MM
		1-2176490-8	HCL165 100W 120R 5% CABLE 150MM
		1-2176490-9	HCL165 100W 150R 5% CABLE 150MM
		2-2176490-0	HCL165 100W 180R 5% CABLE 150MM
		2-2176490-1	HCL165 100W 220R 5% CABLE 150MM
		2-2176490-2	HCL165 100W 270R 5% CABLE 150MM
		2-2176490-3	HCL165 100W 330R 5% CABLE 150MM
		2-2176490-4	HCL165 100W 390R 5% CABLE 150MM
		2-2176490-5	HCL165 100W 470R 5% CABLE 150MM
		2-2176490-6	HCL165 100W 560R 5% CABLE 150MM
		2-2176490-7	HCL165 100W 680R 5% CABLE 150MM
		2-2176490-8	HCL165 100W 820R 5% CABLE 150MM
		2-2176490-9	HCL165 100W 1K0 5% CABLE 150MM
		3-2176490-0	HCL165 100W 1K2 5% CABLE 150MM
		3-2176490-1	HCL165 100W 1K5 5% CABLE 150MM
		3-2176490-2	HCL165 100W 1K8 5% CABLE 150MM
		3-2176490-3	HCL165 100W 2K2 5% CABLE 150MM
		3-2176490-4	HCL165 100W 2K7 5% CABLE 150MM
		3-2176490-5	HCL165 100W 3K3 5% CABLE 150MM
		3-2176490-6	HCL165 100W 3K9 5% CABLE 150MM
		3-2176490-7	HCL165 100W 4K7 5% CABLE 150MM
		3-2176490-8	HCL165 100W 5K6 5% CABLE 150MM

# Aluminum Housed Resistor Type HCL Series

## ORDERING INFORMATION

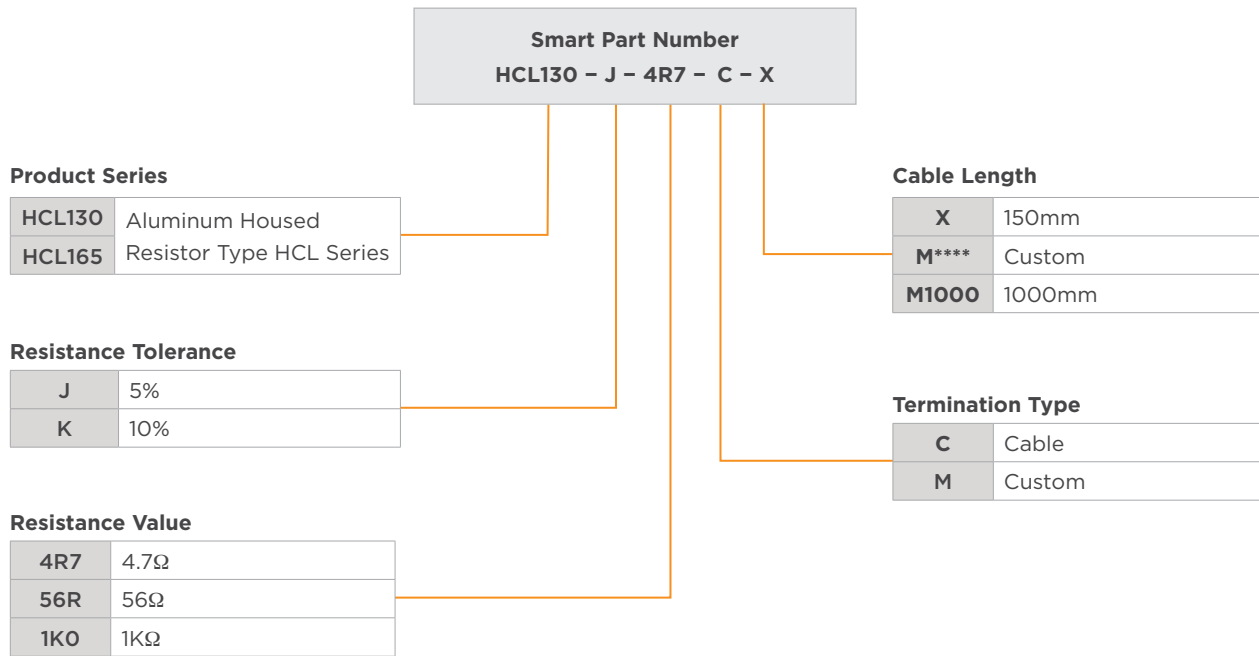

[te.com](https://www.te.com)

© 2022 TE Connectivity. All Rights Reserved.

TE Connectivity, TE connectivity (logo) and Every Connection Counts are trademarks owned or licensed by TE Connectivity. All other logos, products and/or company names referred to herein might be trademarks of their respective owners.

While TE has made every reasonable effort to ensure the accuracy of the information in this brochure, TE does not guarantee that it is error-free, nor does TE make any other representation, warranty or guarantee that the information is accurate, correct, reliable or current. TE reserves the right to make any adjustments to the information contained herein at any time without notice. TE expressly disclaims all implied warranties regarding the information contained herein, including, but not limited to, any implied warranties of merchantability or fitness for a particular purpose. The dimensions in this catalog are for reference purposes only and are subject to change without notice. Specifications are subject to change without notice. Consult TE for the latest dimensions and design specifications.

04/22 AK

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

## TE Connectivity:

[1-2176490-0](#) [1-2176490-1](#) [1-2176490-2](#) [1-2176490-3](#) [1-2176490-4](#) [1-2176490-5](#) [3-2176490-7](#) [3-2176490-8](#) [3-2176490-1](#) [3-2176490-2](#) [3-2176490-3](#) [3-2176490-4](#) [3-2176490-5](#) [3-2176490-6](#) [2-2176490-5](#) [2-2176490-6](#) [2-2176490-7](#) [2-2176490-8](#) [2-2176490-9](#) [3-2176490-0](#) [2176490-9](#) [2-2176490-0](#) [2-2176490-1](#) [2-2176490-2](#) [2-2176490-3](#) [2-2176490-4](#) [2176490-3](#) [2176490-4](#) [2176490-5](#) [2176490-6](#) [2176490-7](#) [2176490-8](#) [1-2176490-6](#) [1-2176490-7](#) [1-2176490-8](#) [1-2176490-9](#) [2176490-1](#) [2176490-2](#) [1-2176489-0](#) [1-2176489-1](#) [1-2176489-2](#) [1-2176489-3](#) [1-2176489-4](#) [1-2176489-5](#) [3-2176489-7](#) [3-2176489-1](#) [3-2176489-2](#) [3-2176489-3](#) [3-2176489-4](#) [3-2176489-5](#) [3-2176489-6](#) [2-2176489-5](#) [2-2176489-6](#) [2-2176489-7](#) [2-2176489-8](#) [2-2176489-9](#) [3-2176489-0](#) [2176489-9](#) [2-2176489-0](#) [2-2176489-1](#) [2-2176489-2](#) [2-2176489-3](#) [2-2176489-4](#) [2176489-3](#) [2176489-4](#) [2176489-5](#) [2176489-6](#) [2176489-7](#) [2176489-8](#) [1-2176489-6](#) [1-2176489-7](#) [1-2176489-8](#) [1-2176489-9](#) [2176489-1](#) [2176489-2](#) [HCL130J100RCX](#) [HCL130J10RCX](#) [HCL130J120RCX](#) [HCL130J12RCX](#) [HCL130J150RCX](#) [HCL130J15RCX](#) [HCL130J180RCX](#) [HCL130J18RCX](#) [HCL130J1K0CX](#) [HCL130J1K2CX](#) [HCL130J1K5CX](#) [HCL130J1K8CX](#) [HCL130J220RCX](#) [HCL130J22RCX](#) [HCL130J270RCX](#) [HCL130J27RCX](#) [HCL130J2K2CX](#) [HCL130J2K7CX](#) [HCL130J330RCX](#) [HCL130J33RCX](#) [HCL130J390RCX](#) [HCL130J39RCX](#) [HCL130J3K3CX](#) [HCL130J3R3CX](#) [HCL130J3R9CX](#)