


Electrical Properties:

Frequency Range: 2.4~2.5 GHz
Impedance: 50 Ω nominal
VSWR: <2.0:1
Gain: 5 dBi
Radiation: Omni
Polarization: Vertical
Wave: 5/8 wave

Mechanical Properties:

Connector: SMA Reverse Polarity Plug
Material:
Whip: Polyurethane(Black)
Swivel Mechanism: Polycarbonate(Black)
Connector: Brass with black nickel plating
Operation Temp.: -20°C to +65°C
Storage Temp.: -30°C to +75°C

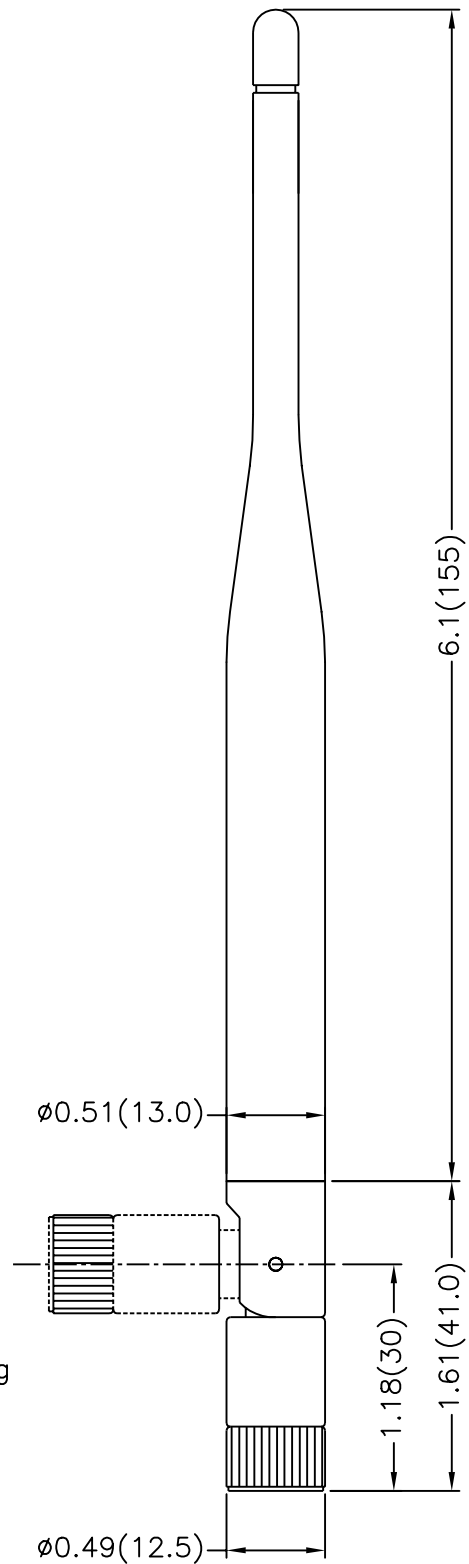

TITLE	2.4GHz Swivel Antenna 151 Model		DATE	SHEET
				1 OF 1
UNIT	DWG. NO.	S151AH-2450S		A4
in.(mm)	<div>NEARSON</div>			
SCALE				
NONE				

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[TE Connectivity:](#)

[0600-00010](#)