



Application Tooling > Portable Crimp Tools



Tool Grade: **Premium Crimp Tooling**
Die Sets Type: **Removable/Interchangeable**
Specification Type: **MIL Spec, TE Product Specification (114-)**
TE Certification: **Cannot be Certified**
Power Technology Type: **Battery, Hydraulic, Manual**

Features

Other

Crimp Form-Wire Barrel Type	Closed Barrel - W Crimp
Tool Grade	Premium Crimp Tooling
Die Sets Type	Removable/Interchangeable
Specification Type	MIL Spec, TE Product Specification (114-)
TE Certification	Cannot be Certified
Power Technology Type	Battery, Hydraulic, Manual
Tooling Type	Die Assembly

Product Compliance

[For compliance documentation, visit the product page on TE.com>](#)

EU RoHS Directive 2011/65/EU	Out of Scope
EU ELV Directive 2000/53/EC	Out of Scope
China RoHS 2 Directive MIIT Order No 32, 2016	Not reviewed for China RoHS compliance
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JAN 2021 (211) Candidate List Declared Against: JAN 2021 (211) Does not contain REACH SVHC
Halogen Content	Not Yet Reviewed for halogen content



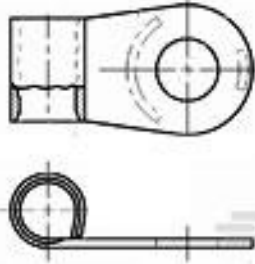
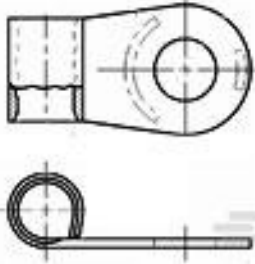
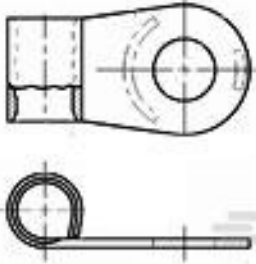
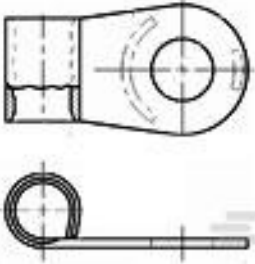
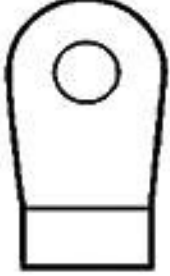
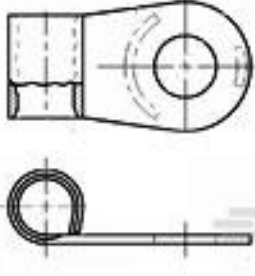
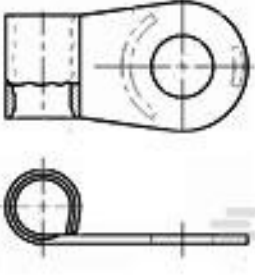
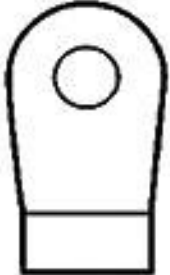
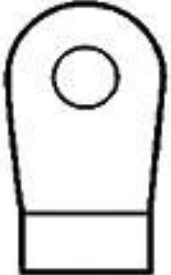
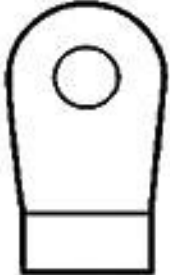
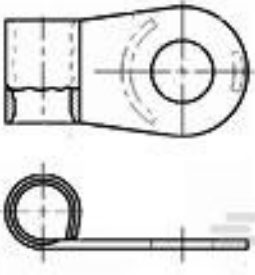
Solder Process Capability


Not reviewed for solder process capability

Product Compliance Disclaimer


This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) 'Guidance on requirements for substances in articles' posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>

Compatible Parts

 TE Part # 321201 TERMINAL,SOLIS FLAG R 2 1/4	 TE Part # 321064 TERMINAL,SOLIS FLAG R 2 5/16	 TE Part # 321275 TERMINAL,SOLIS FLAG R 4 1/4	 TE Part # 321576 TERM,SOLIS, FLAG, R, 6, 1/4
 TE Part # 321253 TERMINAL,SOLIS FLAG R 2 3/8	 TE Part # 323196 TERMINAL,SOLIS FLAG R 6 10	 TE Part # 1490749-1 HYP10 8-4/0AWG MANUAL TOOL	 TE Part # 321059 TERMINAL,SOLIS FLAG R 4 10
 TE Part # 184147-1 TERMINAL,SOLIS FLAG R 2 10.5MM	 TE Part # 322204 TERMINAL,SOLIS FLAG R 6 3/8	 TE Part # 321121 TERMINAL,SOLIS FLAG R 4 3/8	 TE Part # 321060 TERMINAL,SOLIS FLAG R 4 5/16

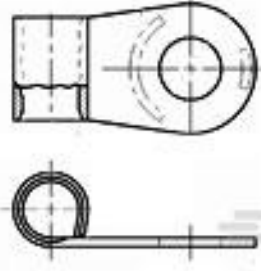

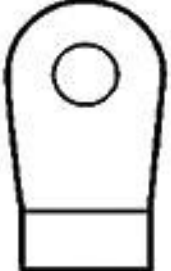TE Part # 321056
TERMINAL, SOLIS FLAG R 6 5/16




TE Part # 321063
TERMINAL, SOLIS FLAG R 2 10



TE Part # 1490746-1
HYP10 LIGHT DUTY 14T HEAD

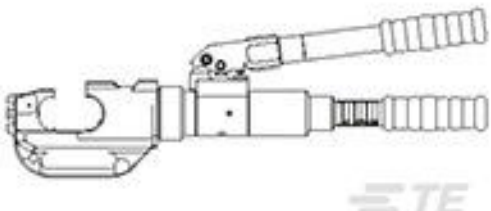Customers Also Bought




TE Part # 1490749-1
HYP10 8-4/0AWG MANUAL TOOL



TE Part # 1752680-5
HYP10 SOLIS FLAG 2AWG NEST



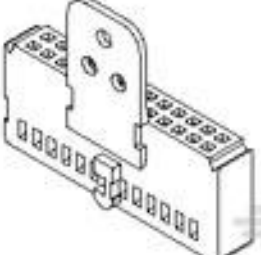TE Part # 1752680-6
HYP10 SOLIS FLAG 4AWG NEST



TE Part # 216038-1
MOD-4 HSG+PULL TAB



TE Part # 1752680-7
HYP10 SOLIS FLAG 6AWG NEST



TE Part # 1SNA105135R1100
M4/8.SF2



TE Part # 1SNA198692R2500
SCH3



TE Part # 314979-1
HYDRAULIC HAND PUMP



TE Part # NB14524001
VERSAFIT-3/8-2-FSP



TE Part # 1490746-1
HYP10 LIGHT DUTY 14T HEAD

Documents

Datasheets & Catalog Pages

AT-Hydraulic Crimp Tooling Solutions-1654519

English

Crimp Term Whitepaper-Use the Right Tool 1-1773953-1

English

CRIMPING WHERE FORM MEETS FUNCTION

English

Bottoming Dies



English

Instruction Sheets

Instruction Sheet (U.S.)

English

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[TE Connectivity:](#)

[1752681-3](#)