



AMP

TE Internal #: 1804700-2

Portable Crimp Tools, TE Certification, Hydraulic (10,000 psi, 220v),
Base Power Unit (No Crimp Tooling)

[View on TE.com >](#)

Application Tooling > Portable Crimp Tools



TE Certification: **Yes**

Power Technology Type: **Hydraulic (10,000 psi, 220v)**

Tooling Type: **Base Power Unit (No Crimp Tooling)**

Features

Other

TE Certification	Yes
Power Technology Type	Hydraulic (10,000 psi, 220v)
Tooling Type	Base Power Unit (No Crimp Tooling)

Product Compliance

[For compliance documentation, visit the product page on TE.com>](#)

EU RoHS Directive 2011/65/EU	Out of Scope
EU ELV Directive 2000/53/EC	Out of Scope
China RoHS 2 Directive MIIT Order No 32, 2016	Not reviewed for China RoHS compliance
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JUL 2021 (219) Candidate List Declared Against: JUL 2021 (219) Does not contain REACH SVHC
Halogen Content	Not Yet Reviewed for halogen content
Solder Process Capability	Not applicable for solder process capability

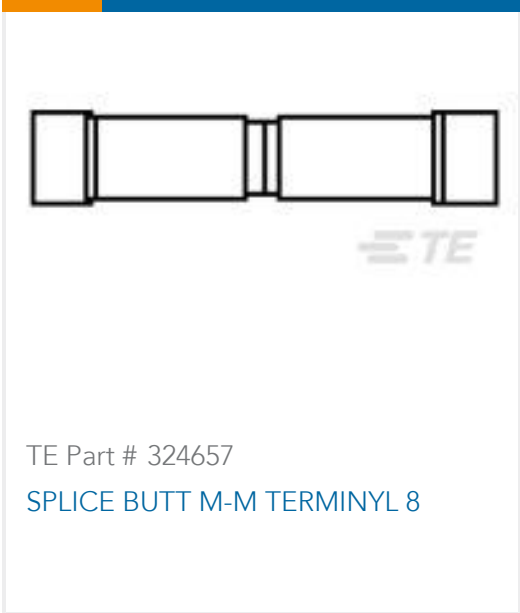
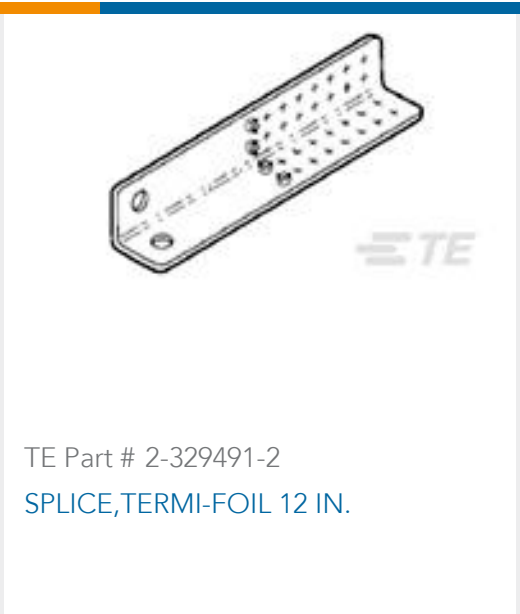
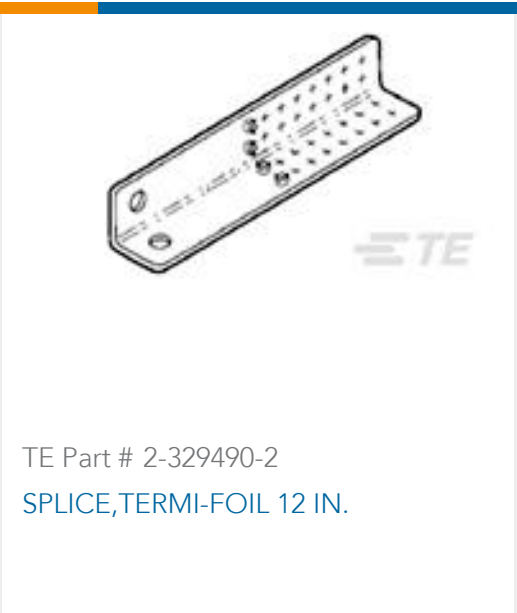
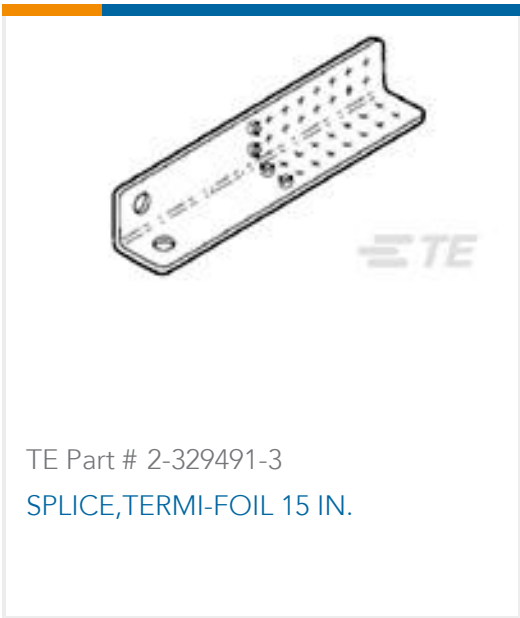
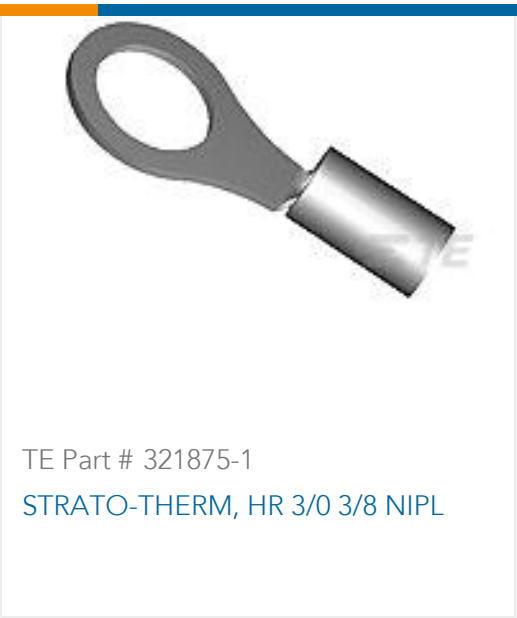
Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits



as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) 'Guidance on requirements for substances in articles' posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>


Compatible Parts

 TE Part # 324657 SPLICE BUTT M-M TERMINYL 8	 TE Part # 1490747-1 HYP10 HEAVY DUTY 12T HEAD	 TE Part # 1583662-1 HYP10 6FT HOSE	 TE Part # 1583662-3 HYP10 20FT HOSE
 TE Part # 1752786-1 HYP10 4/0-1000MCM 26T HEAD	 TE Part # 1901776-1 HYP10 15FT HAND CTRL	 TE Part # 2-329491-2 SPLICE,TERMI-FOIL 12 IN.	 TE Part # 1901777-1 HYP10 21FT HAND CTRL
 TE Part # 68284-1 HYP10 3PEDAL FOOT CTRL	 TE Part # 1583662-2 HYP10 10FT HOSE	 TE Part # 1901775-1 HYP10 7FT HAND CTRL	 TE Part # 2-329490-2 SPLICE,TERMI-FOIL 12 IN.
 TE Part # 2-329491-3 SPLICE,TERMI-FOIL 15 IN.	 TE Part # 321866-1 STRATO-THERM, HR 1/0 1/4 NIPL	 TE Part # 321874-2 STRATO-THERM, HR 3/0 5/16 NIPL	 TE Part # 321875-1 STRATO-THERM, HR 3/0 3/8 NIPL





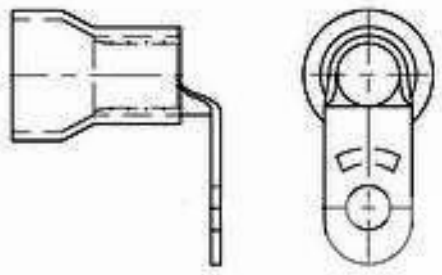TE Part # 321880-1
STRATO-THERM, HR 4/0 1/2 NIPL



TE Part # 696434-1
TERM, RING, PLASTI-GRIP, 4, #10, 90 BEND



TE Part # 1752787-1
HYP10 8-4/0AWG 33T HEAD



TE Part # 1752868-1
HYP10 12-350MCM 18T HEAD

Customers Also Bought



TE Part #68284-1
HYP10 3PEDAL FOOT CTRL



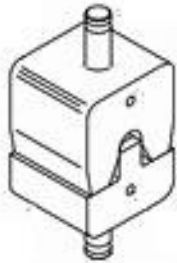
TE Part #1583662-2
HYP10 10FT HOSE




TE Part #1752681-1
HYP10 SOLIS FLAG 1/0-4/0AWG INDENTER



TE Part #1901775-1
HYP10 7FT HAND CTRL



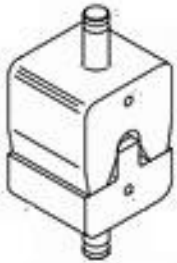TE Part #47915
HYP8/10 TERMINYL 3/0 DIE SET



TE Part #48756-1
HYP8/10 PLASTI-GRIP/10 1/0AWG DIE SET



TE Part #1752868-1
HYP10 12-350MCM 18T HEAD SET



TE Part #1490746-1
HYP10 LIGHT DUTY 14T HEAD



TE Part #3-525441-3
PLUG GAUGE, HANDTOOL

Documents

Datasheets & Catalog Pages

[AT-Hydraulic Crimp Tooling Solutions-1654519](#)

English

[Crimp Term Whitepaper-Use the Right Tool 1-1773953-1](#)

English

[CRIMPING WHERE FORM MEETS FUNCTION](#)

English

[Bottoming Dies](#)



English

Product Environmental Compliance

Safety Datasheet

English

Instruction Sheets

Heavy-Duty Electric Hydraulic Pumps 1804700-1 and 1804700-2

Heavy-Duty Electric Hydraulic Pumps 1804700-1 and 1804700-2

German

Heavy-Duty Electric Hydraulic Pumps 1804700-1 and 1804700-2

French

Heavy-Duty Electric Hydraulic Pumps 1804700-1 and 1804700-2

Hydraulic Crimping Systems

English

Hydraulic Crimping Systems

French

Agency Approvals

CE Technical File

English

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[TE Connectivity:](#)

[1804700-2](#)