


 

REVISIONS

P	LTR	DESCRIPTION	DATE	DWN	APVD
	A	NEW DRAWING	07MAR2023	BDA	DH
	A1	DRAWING CLARIFICATION	21JUL2023	BDA	DH
	A2	SPECIFICATIONS NUMBER UPDATED	28SEP2023	BDA	DH

GENERAL TOLERANCES:
0 TO 2mm = ± 0.15 mm
2.1mm AND ABOVE = ± 0.25 mm
LINEAR = ± 0.8 mm

MATERIAL SPECIFIC DATA TABLE

	SNA	FNA
RECOMMENDED OPERATING TEMPERATURE RANGE (°C)	-55 to 125	-55 to 125
SPECIFIC GRAVITY ± 13%	2.000	2.300
SHORE A HARDNESS	70±7	70±7
MAXIMUM VOLUME RESISTIVITY (Ω.CM)	0.1	0.1

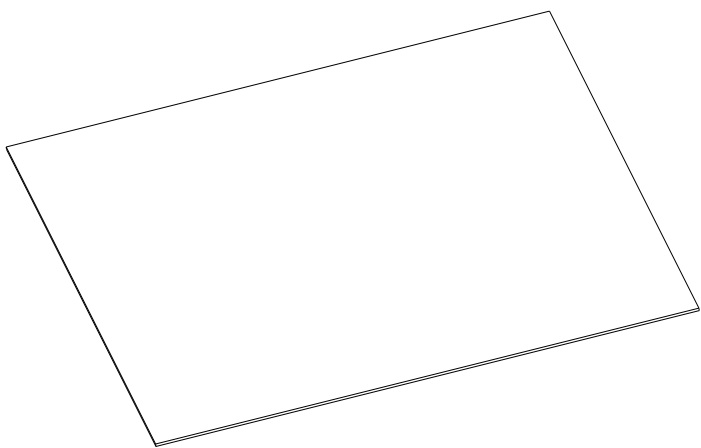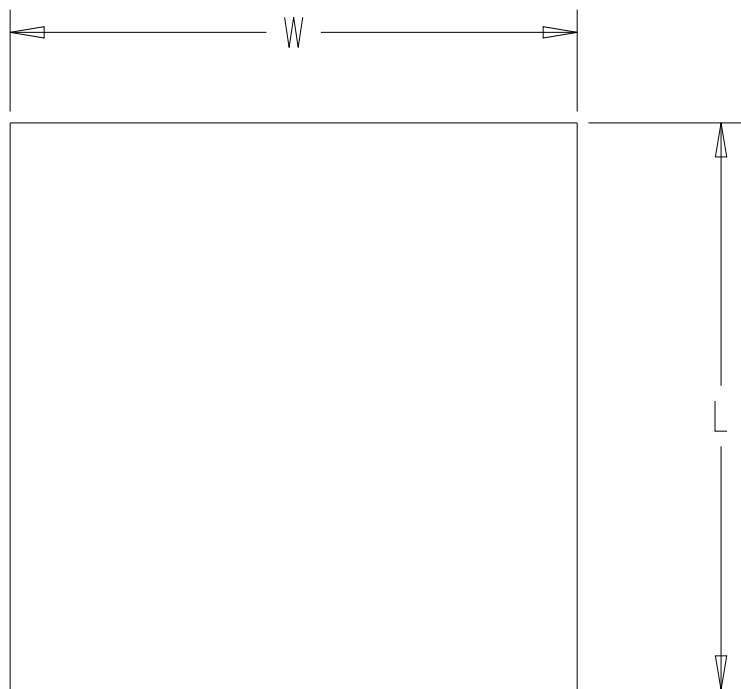

ISOMETRIC VIEW (NTS)

DARK GREEN	1.6	50	50	FLUROSILICONE NICKEL ALUMINIUM	1210-FNA-0016-S	2452685-1
DARK GREEN	1.2	50	50	FLUROSILICONE NICKEL ALUMINIUM	1210-FNA-0012-S	2452684-1
DARK GREEN	0.8	50	50	FLUROSILICONE NICKEL ALUMINIUM	1210-FNA-0008-S	2452683-1
DARK GREY	1.6	50	50	SILICONE NICKEL ALUMINIUM	1210-SNA-0016-S	2452662-1
DARK GREY	1.2	50	50	SILICONE NICKEL ALUMINIUM	1210-SNA-0012-S	2452661-1
DARK GREY	0.8	50	50	SILICONE NICKEL ALUMINIUM	1210-SNA-0008-S	2452660-1
DARK GREEN	1.6	150	150	FLUROSILICONE NICKEL ALUMINIUM	1210-FNA-0016	2452672-1
DARK GREEN	1.2	150	150	FLUROSILICONE NICKEL ALUMINIUM	1210-FNA-0012	2452671-1
DARK GREEN	0.8	150	150	FLUROSILICONE NICKEL ALUMINIUM	1210-FNA-0008	2452670-1
DARK GREY	1.6	150	150	SILICONE NICKEL ALUMINIUM	1210-SNA-0016	2452649-1
DARK GREY	1.2	150	150	SILICONE NICKEL ALUMINIUM	1210-SNA-0012	2452648-1
DARK GREY	0.8	150	150	SILICONE NICKEL ALUMINIUM	1210-SNA-0008	2452647-1
COLOUR	T	W	L	MATERIAL	ALIAS PART NUMBER	PART NUMBER

THIS DRAWING IS A CONTROLLED DOCUMENT.

DWN	07MAR2023
BASAVARAJA D A	
CHK	07MAR2023
B. SELVAPANDIAN	
APVD	07MAR2023
D. HEMMINGS	



TE Connectivity

NAME 1210-NA-ECE MOULDED SHEET-SERIES

SIZE	CAGE CODE	DRAWING NO	RESTRICTED TO
A2	00779	C-1210-NA-ECE-SHEET	-

CUSTOMER DRAWING	SCALE	1 : 2	SHEET	OF	REV	A2
------------------	-------	-------	-------	----	-----	----

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[TE Connectivity:](#)

[2452648-1](#) [2452670-1](#) [2452649-1](#) [2452671-1](#) [2452672-1](#) [2452647-1](#)