
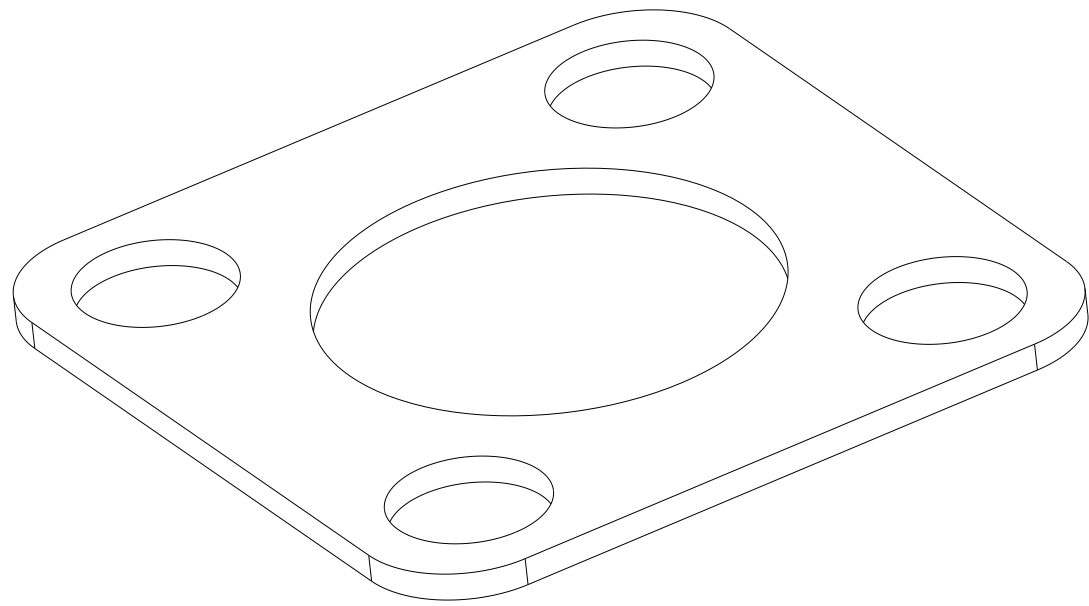
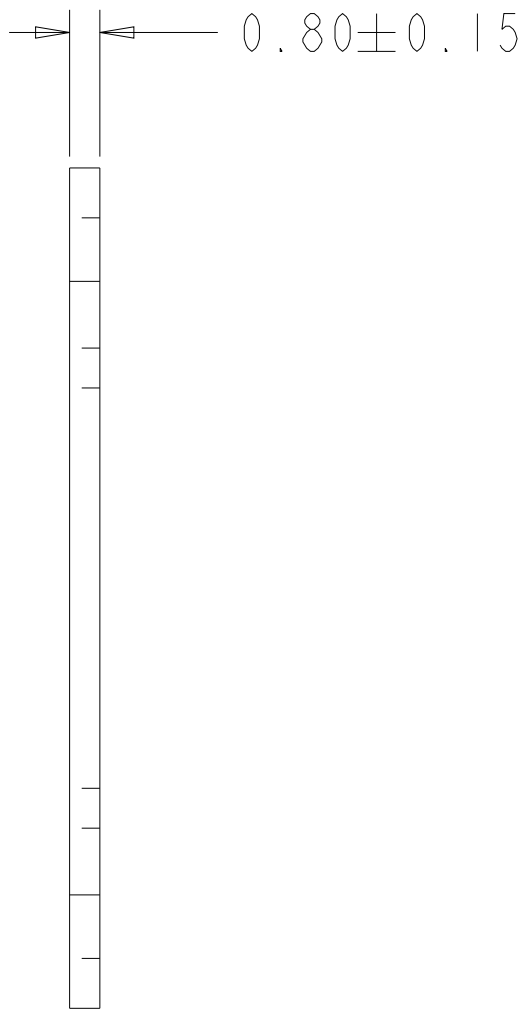


REVISIONS					
P	LTR	DESCRIPTION	DATE	DWN	APVD
	A	NEW DRAWING	23MAY2024	AN	JM

MATERIAL SPECIFIC DATA TABLE

TEST SPECIFICATION / MATERIAL CODE	SILICONE NICKEL ALUMINIUM (SNA)	FLUOROSILICONE NICKEL ALUMINIUM (FNA)
RECOMMENDED OPERATING TEMPERATURE RANGE (°C)	-55 to 125	-55 to 125
SPECIFIC GRAVITY ± 13%	2.000	2.300
SHORE A HARDNESS ± 7	70	70
MAXIMUM VOLUME RESISTIVITY (Ω.CM)	0.100	0.100

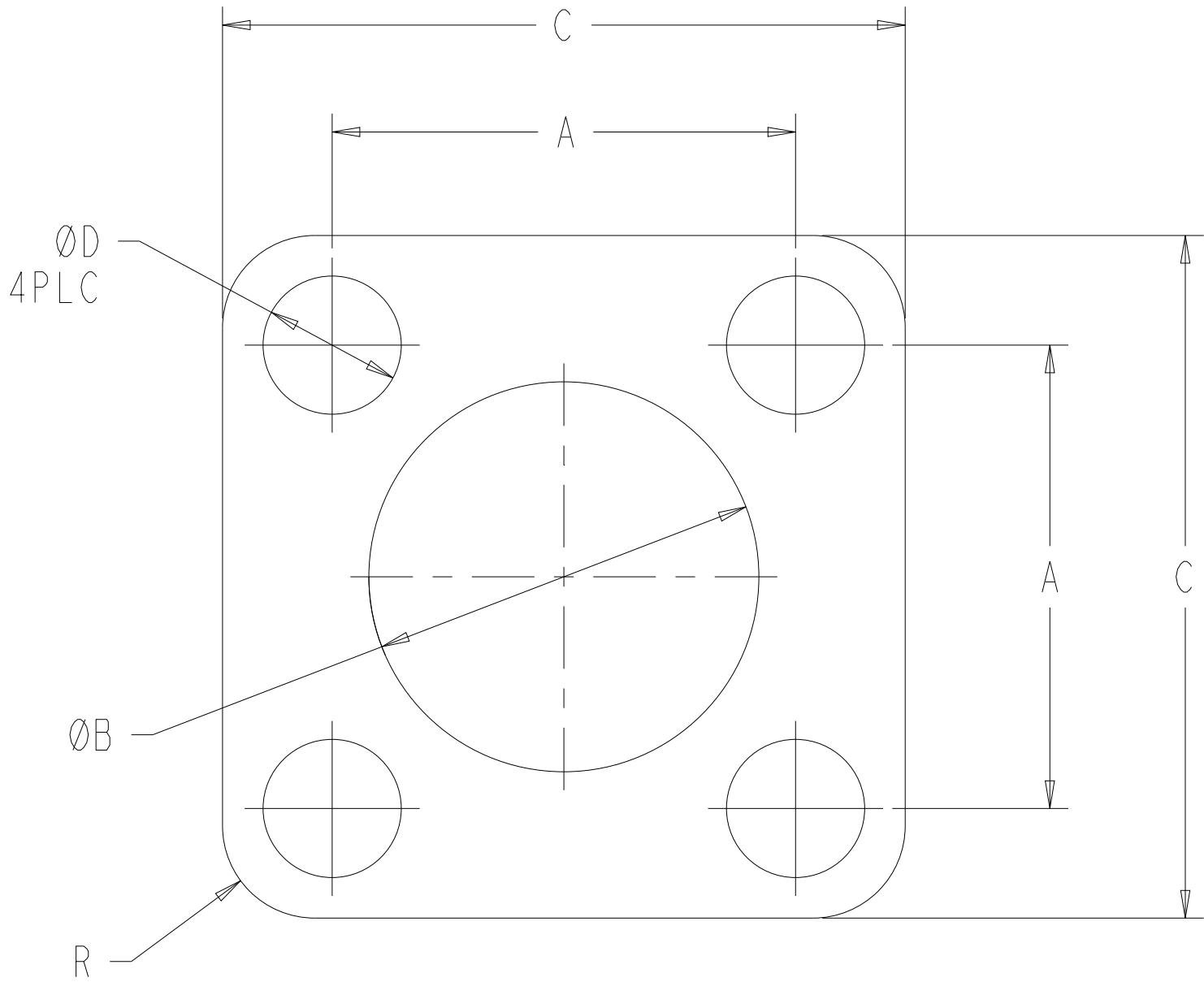

ISOMETRIC VIEW (NTS)

FNA	48	DARK GREEN	66.68	76.99	82.55	6.00	4.50	92-24030-I	2488591-I	92-24030-I0	2488561-I
FNA	44	DARK GREEN	60.33	70.64	76.20	6.00	4.50	92-24029-I	2488590-I	92-24029-I0	2488560-I
FNA	40	DARK GREEN	55.58	61.93	69.85	6.00	4.50	92-24028-I	2488589-I	92-24028-I0	2488559-I
FNA	36	DARK GREEN	49.23	55.58	63.50	6.00	4.50	92-24027-I	2488588-I	92-24027-I0	2488558-I
FNA	32	DARK GREEN	44.45	50.80	57.15	6.00	4.50	92-24026-I	2488587-I	92-24026-I0	2488557-I
FNA	28	DARK GREEN	39.67	44.45	50.80	5.50	4.50	92-24025-I	2488586-I	92-24025-I0	2488556-I
FNA	24	DARK GREEN	34.93	38.10	44.45	5.50	4.50	92-24024-I	2488585-I	92-24024-I0	2488555-I
FNA	22	DARK GREEN	31.75	34.93	41.28	5.00	4.50	92-24023-I	2488584-I	92-24023-I0	2488554-I
FNA	20	DARK GREEN	29.36	31.75	38.10	5.00	4.50	92-24022-I	2488583-I	92-24022-I0	2488553-I
FNA	18	DARK GREEN	26.97	28.58	34.93	5.00	4.50	92-24021-I	2488582-I	92-24021-I0	2488552-I
FNA	16	DARK GREEN	24.61	25.40	32.54	4.50	5.50	92-24020-I	2488581-I	92-24020-I0	2488550-I
FNA	14	DARK GREEN	23.01	22.23	30.18	4.50	5.00	92-24019-I	2488580-I	92-24019-I0	2488549-I
FNA	12	DARK GREEN	20.65	19.05	27.79	4.50	4.00	92-24018-I	2488579-I	92-24018-I0	2488548-I
FNA	10	DARK GREEN	18.26	15.88	25.40	4.50	3.00	92-24017-I	2488578-I	92-24017-I0	2488547-I
FNA	8	DARK GREEN	15.09	12.70	22.23	4.50	3.00	92-24016-I	2488577-I	92-24016-I0	2488546-I
SNA	48	DARK GREY	66.68	76.99	82.55	6.00	4.50	92-24015-I	2488576-I	92-24015-I0	2488545-I
SNA	44	DARK GREY	60.33	70.64	76.20	6.00	4.50	92-24014-I	2488575-I	92-24014-I0	2488544-I
SNA	40	DARK GREY	55.58	61.93	69.85	6.00	4.50	92-24013-I	2488574-I	92-24013-I0	2488543-I
SNA	36	DARK GREY	49.23	55.58	63.50	6.00	4.50	92-24012-I	2488573-I	92-24012-I0	2488542-I
SNA	32	DARK GREY	44.45	50.80	57.15	6.00	4.50	92-24011-I	2488572-I	92-24011-I0	2488541-I
SNA	28	DARK GREY	39.67	44.45	50.80	5.50	4.50	92-24010-I	2488571-I	92-24010-I0	2488540-I
SNA	24	DARK GREY	34.93	38.10	44.45	5.50	4.50	92-24009-I	2488570-I	92-24009-I0	2488539-I
SNA	22	DARK GREY	31.75	34.93	41.28	5.00	4.50	92-24008-I	2488569-I	92-24008-I0	2488538-I
SNA	20	DARK GREY	29.36	31.75	38.10	5.00	4.50	92-24007-I	2488568-I	92-24007-I0	2488537-I
SNA	18	DARK GREY	26.97	28.58	34.93	5.00	4.50	92-24006-I	2488567-I	92-24006-I0	2488536-I
SNA	16	DARK GREY	24.61	25.40	32.54	4.50	5.50	92-24005-I	2488566-I	92-24005-I0	2488535-I
SNA	14	DARK GREY	23.01	22.23	30.18	4.50	5.00	92-24004-I	2488565-I	92-24004-I0	2488534-I
SNA	12	DARK GREY	20.65	19.05	27.79	4.50	4.00	92-24003-I	2488564-I	92-24003-I0	2488533-I
SNA	10	DARK GREY	18.26	15.88	25.40	4.50	3.00	92-24002-I	2488563-I	92-24002-I0	2488532-I
SNA	8	DARK GREY	15.09	12.70	22.23	4.50	3.00	92-24001-I	2488562-I	92-24001-I0	2488531-I
MATERIAL	SHELL SIZE	COLOUR	A±0.4	ØB±0.2	C±0.5	ØD±0.2	R±0.5	IPK QTY PART NUMBER	IPK QTY PART NUMBER	10PK QTY ALIAS PART NUMBER	10PK QTY PART NUMBER

THIS DRAWING IS A CONTROLLED DOCUMENT.

DIMENSIONS: mm

0 PLC

1 PLC

2 PLC

3 PLC

4 PLC

±

±

±

±

±

ANGLES

FINISH

TOLERANCES UNLESS OTHERWISE SPECIFIED

±

±

±

±

±

±

±

MATERIAL SEE TABLE

-

DWN 23MAY2024
CHK AYESHABANDU N
APVD J. MARTIN 23MAY2024

PRODUCT SPEC

108-120068

APPLICATION SPEC

114-120007

WEIGHT

-

ALIAS PART NUMBER

92-NA-CONNECTOR GASKETS MIL-DTL-5015

SIZE

CAGE CODE

DRAWING NO

RESTRICTED TO

00779

92-NA-CONNECTOR-GASKETS

-

CUSTOMER DRAWING

SCALE 5:1

SHEET 1 OF 1

REV A

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[TE Connectivity:](#)

[92-24020-1](#) [92-24017-10](#) [92-24016-1](#) [92-24019-10](#) [92-24021-1](#) [92-24018-1](#) [92-24017-1](#) [92-24020-10](#) [92-24022-1](#)
[92-24022-10](#) [92-24021-10](#) [92-24018-10](#) [92-24016-10](#) [92-24019-1](#)