

REV. 0
DCO 142074

COIL: @ 25°C
RESISTANCE 1560 OHMS 10%
NOMINAL VOLTAGE 26.5 VDC
MUST OPERATE 14.2 VDC
0.13 mADC
MUST RELEASE 8.0 VDC MAX, 1.37 VDC MIN.

ENVIRONMENT:

VIBRATION 10 CPS TO 3000 CPS @ 30 g's
SHOCK 75 g's 6 MS. DURATION
TEMPERATURE -65 °C TO +125 °C


NOTES:

TURN-ON TIME 2.0 MS MAX

TURN-OFF TIME 7.5 MS MAX

CONTACT STABILIZATION 2.0 MS MAX

CUSTOMER DATA SHEET

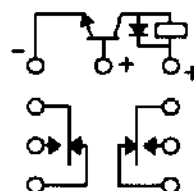

TERMINAL VIEW

CONTACT RATING: LOW LEVEL TO
1A 28 VDC RESISTIVE 100,000
OPERATIONS

DR. PBB 6/6/00

CR. 6/6/00

COMMUNICATIONS
INSTRUMENTS, INC.

CUST. OPL
CUST. NO. M28776/1-036P REV.

"JMAT" RELAY

JMACT-26XPS

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[TE Connectivity:](#)

[JMACT-26XPS](#)