


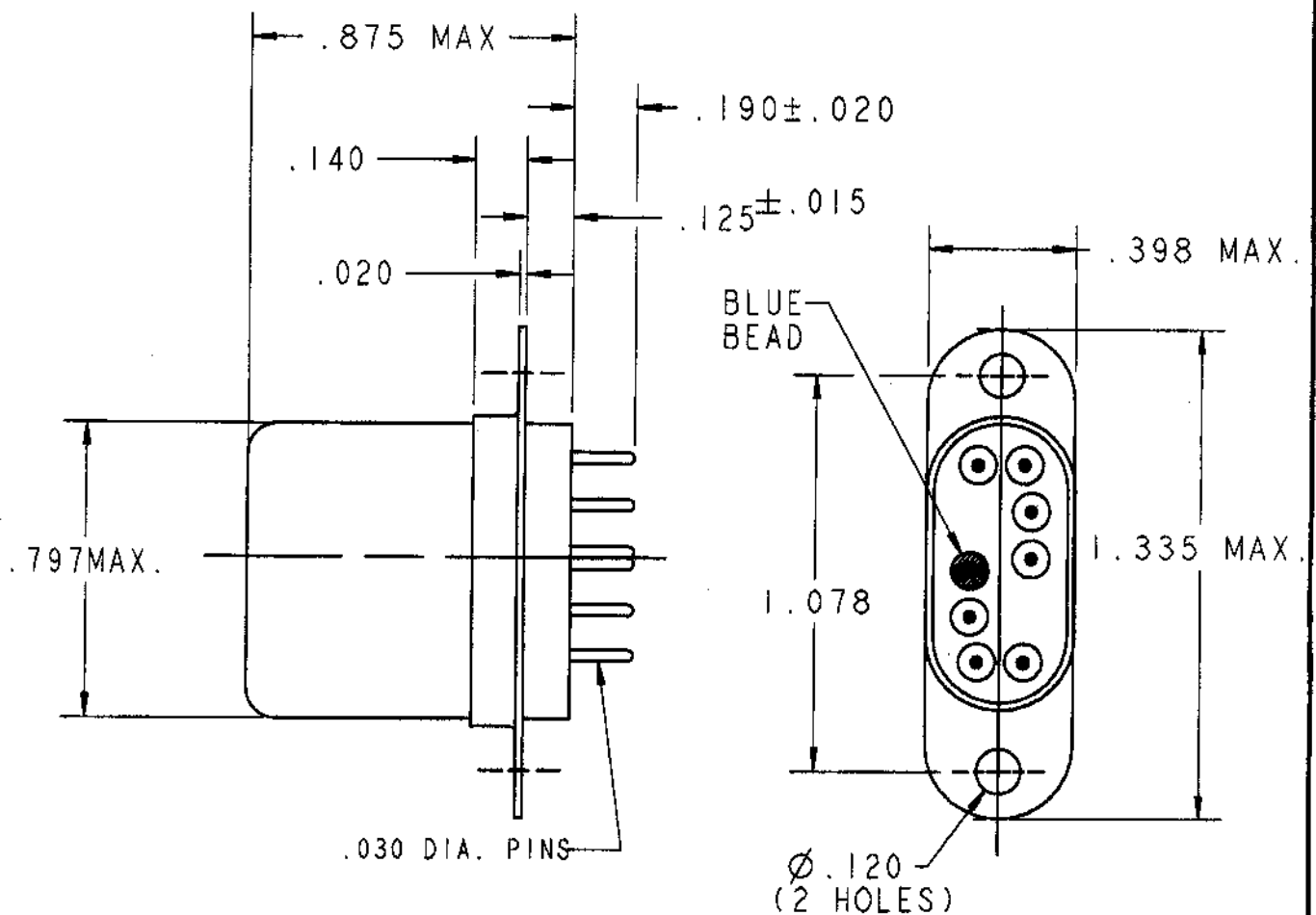

REV. 0

DCO 170519

COIL: @ 25°C	2530 OHMS ± 15 %
RESISTANCE	
NOMINAL VOLTAGE	51.0 VDC
MUST OPERATE	29.0 VDC
MUST RELEASE	15.0 VDC MAX, 3.22 VDC MIN.


ENVIRONMENT:

VIBRATION 55 CPS TO 2000 CPS @ 15 g's
 SHOCK 50 g's 11 MS. DURATION
 TEMPERATURE -65 °C TO +125 °C

NOTES: OPERATE 6 MS MAX.
 RELEASE 5 MS MAX.

DIELECTRIC 1000 VAC, BOUNCE 2.5 MS MAX.

CUSTOMER DATA SHEET

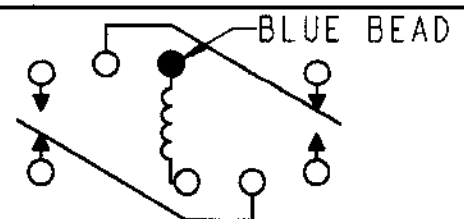

TERMINAL VIEW

CONTACT RATING: 2 AMPS @ 28 VDC, 1000,000 OPERATIONS

DR. BSH 07/03/01 CK.TLG 7-3-01

CII Technologies
 advanced control electronic solutions

CUST. CII STD.
 CUST. NO. REV.

3SAE RELAY

3SAE51B4R1

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[TE Connectivity:](#)

[3SAE5134R1](#)