

REV. 0


DCO 16677

COIL: @ 25°C	
RESISTANCE	1250 OHMS ±10%
NOMINAL VOLTAGE	26.5 - 32 VDC
MUST OPERATE	14.0 VDC
MUST RELEASE	1.5 VDC

ENVIRONMENT:

VIBRATION	20	CPS TO	2000	CPS @	20	g's
SHOCK	100	g's	6 ±1	MS. DURATION		
TEMPERATURE	-65	°C TO	+125	°C		
NOTES:	OPERATE & RELEASE 4 MS MAX.					
	CONTACT BOUNCE 2.0 MS MAX.					

CUSTOMER DATA SHEET

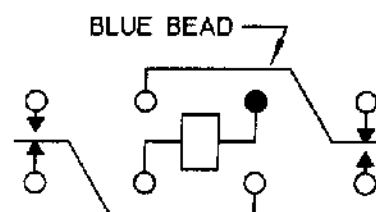

TERMINAL VIEW

CONTACT RATING: LOW LEVEL TO 4A
28 VDC RESISTIVE 100,000 OPERATIONS

DR. PBB 12/15/00 CK. TLG 12-15-00

CII Technologies
advanced control electronic solutions

CUST. C.I. CATALOG

CUST. NO. REV.

"HFW4A" RELAY

HFW4A1231D00

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[TE Connectivity:](#)

[HFW4A1231D00](#)