

COIL: @ 25°C

RESISTANCE 2500 OHMS ± 10%

NOMINAL VOLTAGE 20.0 VDC

MUST OPERATE 4.0 mADC

MUST RELEASE 2.0 mADC MAX, 0.40 mADC MIN.

ENVIRONMENT:

② VIBRATION 10 Hz TO 2000 Hz @ 20 g's

SHOCK 90 g's 11 MS DURATION

TEMPERATURE -65 °C TO +125 °C


NOTES: ② GENICOM IS 3000 Hz

OPERATE 15 MS MAX ③ (GENICOM IS 10 MS MAX)

RELEASE 10 MS MAX ④ (GENICOM IS 5 MS MAX)

BOUNCE 2 MS MAX

CUSTOMER DATA SHEET

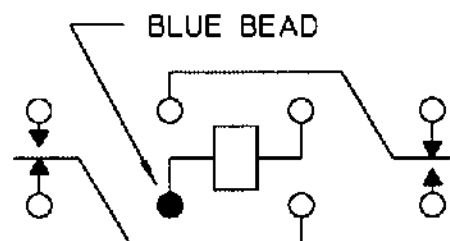

CONTACT RATING: LOW LEVEL TO 2A
28 VDC RESISTIVE 100,000 OPERATIONS

DR. R.B. 5/1/97 CK 5/1/97

COMMUNICATIONS
INSTRUMENTS, INC.

CUST. GENICOM
CUST. NO. 3SAT6004R1

TYPE 'SF' RELAY

SF5201J06

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[TE Connectivity:](#)

[SF5201J06](#)