

COIL: @ 25°C

RESISTANCE 10000 OHMS ± 10%

NOMINAL VOLTAGE 32.0 VDC

MUST OPERATE 1.6 mADC

MUST RELEASE 0.16 mADC

ENVIRONMENT:

VIBRATION 10 CPS TO 2000 CPS @ 15 g's

SHOCK 100 g's 6 MS. DURATION


TEMPERATURE -65 °C TO +125 °C

NOTES: OPERATE TIME 15 MS MAX.

RELEASE TIME 10 MS MAX.

CONTACT BOUNCE 3 MS MAX.

CUSTOMER DATA SHEET

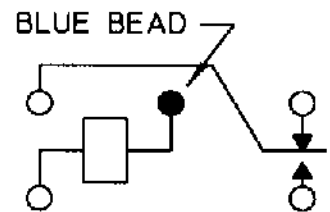

CONTACT RATING: LOW LEVEL TO 2A
30 VDC RESISTIVE 100,000 OPERATIONS

DR. R.B. 1/10/96 CK. 1/10/96

COMMUNICATIONS
INSTRUMENTS, INC.

CUST. HI-G
CUST. NO. 1BC-2A-140

TYPE 'SF' RELAY

SF5601Y01

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[TE Connectivity:](#)

[SF5601Y01](#)