

REV. 0  
DCO 64170

COIL: @ 25°C

SET	RESET
975 OHMS ±10%	975 OHMS ±10%
26.5 VDC NOMINAL VOLTAGE	26.5 VDC NOMINAL VOLTAGE
13.5 VDC MUST OPERATE	13.5 VDC MUST OPERATE

ENVIRONMENT:


VIBRATION 55 Hz 3000 Hz 30 g's

SHOCK 150 g's 11 MS. DURATION

TEMPERATURE -65 °C TO +125 °C

NOTES: SET/RESET 4 MS MAX.  
CONTACT BOUNCE 1.5 MS MAX.

CUSTOMER DATA SHEET

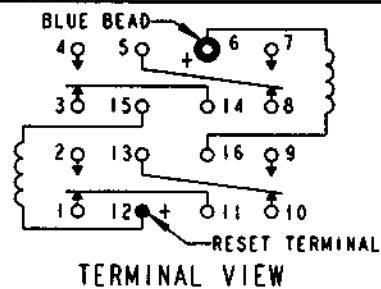

CONTACT RATING: LOW LEVEL TO  
2 AMPS 28 VDC RESISTIVE  
100,000 OPERATIONS

DR. B.D. 10/31/01

CK.

**CII Technologies**  
advanced control electronic solutions

CUST. CII STD.

CUST. NO.

TYPE "3SBM" RELAY

3SBM5004V2

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[TE Connectivity:](#)

[3SBM5004V2](#)