




# 81044/12-20-0

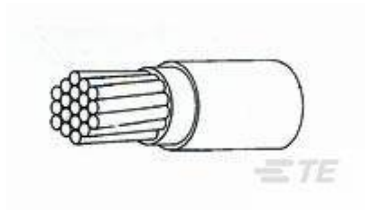

✓ ACTIVE

Raychem

TE Part # **81044/12-20-0**  
TE Internal #: **282213-003**  
Mil-Spec: **M81044/12-20-0**  
Alias #: **3-1192108-2**

Cable Type : **Spec 44**  
Voltage Rating (V): **600**  
Wire Size (AWG): **20**  
Wire Size (mm²): **.52**  
Operating Temperature Range (°C): **-65 – 150**

☰ Add to List ▾ | Similar Products

Compatible Parts & Tooling

## Features



Please review product documents or [contact us](#) for the latest agency approval information. Please Note: Use the Product Drawing for all design activity.

### Product Type Features

Cable Type : **Spec 44**  
Product Classification :  
**High Performance - Spec 44, 55 & RCW**  
Product Type : **Wire**  
Cable Style : **Primary**

### Configuration Features

Number of Conductors : **1**

### Electrical Characteristics

Voltage Rating (V): **600**

### Body Features

Wire Color : **Black**

### Dimensions

Wire Size (AWG): **20**  
Wire Size (mm²): **.52**  
Conductor Diameter : **1.01 mm [ .04 in ]**  
Wire Diameter : **1.4 mm [ .055 in ]**  
Overall Outside Diameter : **1.4 mm [ .055 in ]**

### Usage Conditions

Operating Temperature Range (°C): **-65 – 150**

### Other

Wire Source : **United States**

We are here to help!  
Get in touch with our product experts.

CHAT WITH US

EMAIL US

CALL US

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[TE Connectivity:](#)

[M81044/12-20-0](#)