


Home > Products > Wire & Cable > Product Feature Selector > Product Details

44A1111-12-9-9-US Product Details

 Share

 Print

 Email

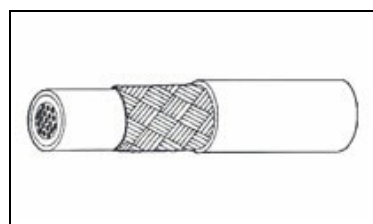

44A1111-12-9-9-US

TE Internal Number: 387071-000

 Active

Spec 44, Spec 55 and Spec RCW Wire and Cable

 Converted to EU RoHS/ELV Compliant (Statement of Compliance)

Product Highlights:

- Cable Type = Spec 44
- Wire Source = United States
- Cable Style = Jacketed, Round-Braid Shielded
- Wire Size (AWG/CM) = 12 AWG
- Voltage Rating = 600 VAC

[View all Features](#)

Quick Links

- ▶ [Pricing & Availability](#)
- ▶ [Search for Tooling](#)
- ▶ [Product Feature Selector](#)
- ▶ [Contact Us About This Product](#)

 [Add to My Part List](#)

 [Request Sample](#)

 [Find Similar Products](#)

 [Buy Product](#)

Documentation & Additional Information	
Product Drawings: • None Available Catalog Pages/Data Sheets: • None Available Product Specifications: • None Available Application Specifications: • None Available Instruction Sheets: • None Available CAD Files: • None Available	Related Products: • Tooling
List all Documents	

Product Features (Please use the Product Drawing for all design activity)	
Product Type Features: • Cable Type = Spec 44 • Cable Style = Jacketed, Round-Braid Shielded Electrical Characteristics: • Voltage Rating (VAC) = 600 Dimensions: • Conductor Outer Diameter (mm [in]) = 2.23 [0.088] • Shield (Screen) Diameter (mm [in]) = 3.30 [0.130] Body Features: • Wire Size (AWG/CM) = 12 AWG • Cable Jacket Color = White • Conductor Type = Tin-Plated Copper • Wire Color = White • Nominal Outside Diameter (mm [in]) = 3.71 [0.146] • Wire Diameter (mm [in]) = 2.74 [0.108] Configuration Features: • Number of Conductors = 1	Industry Standards: • Government/Industry Qualification = No • RoHS/ELV Compliance = RoHS compliant, ELV compliant • Lead Free Solder Processes = Not relevant for lead free process • RoHS/ELV Compliance History = Converted to comply with RoHS directive Conditions for Usage: • Temperature Range (°C) = -65 – +150 • Wire Size - Details = 12 AWG 2.98 mm², 0.0046 in², 37 x 28 AWG Operation/Application: • Application = General Purpose - Lightweight Packaging Features: • Wire Source = United States Other: • Brand = Raychem

Corporate Information

[About TE](#)
[Investors](#)
[News Room](#)
[Supplier Portal](#)
[Careers](#)

Quick Links

[Distributor Inventory](#)
[Product Cross Reference](#)
[Documents & Drawings](#)
[Product Compliance Support Center](#)
[Site Map](#)

Customer Support

[Email or Chat With Us](#)
[Find a Phone Number](#)
[Knowledge Base](#)
[Manage Your Account](#)

Keep Me Informed



[Terms & Conditions](#)

[Privacy Policy](#)

[AODA Accessibility Policy](#)

[AODA Multi-Year Accessibility
Plan](#)

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[TE Connectivity:](#)

[44A1111-12-9-9-US](#)