


Home > Products > Wire & Cable > Product Feature Selector > Product Details

44A1111-24-6-9-US Product Details

 Share

 Print

 Email

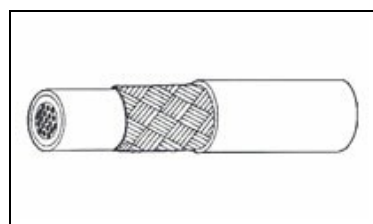

44A1111-24-6-9-US

TE Internal Number: 387092-000

 Active

Spec 44, Spec 55 and Spec RCW Wire and Cable

 [Converted to EU RoHS/ELV Compliant \(Statement of Compliance\)](#)

Product Highlights:

- Cable Type = Spec 44
- Wire Source = United States
- Cable Style = Jacketed, Round-Braid Shielded
- Wire Size (AWG/CM) = 24 AWG
- Voltage Rating = 600 VAC

[View all Features](#)

Quick Links

- ▶ [Pricing & Availability](#)
- ▶ [Search for Tooling](#)
- ▶ [Product Feature Selector](#)
- ▶ [Contact Us About This Product](#)

 [Add to My Part List](#)

 [Request Sample](#)

 [Find Similar Products](#)

 [Buy Product](#)

Documentation & Additional Information

Product Drawings:

- [ONE CONDUCTOR CABLE, SHIELDED, JACKETED, GENERAL PUR...](#) (PDF, English)

Catalog Pages/Data Sheets:

- None Available

Product Specifications:

- None Available

Application Specifications:

- None Available

Instruction Sheets:

- None Available

CAD Files:

- None Available

Related Products:

- [Tooling](#)

[List all Documents](#)

Feedback

Product Features (Please use the Product Drawing for all design activity)

Product Type Features:

- [Cable Type](#) = Spec 44
- [Cable Style](#) = Jacketed, Round-Braid Shielded

Electrical Characteristics:

- Voltage Rating (VAC) = 600

Dimensions:

- Conductor Outer Diameter (mm [in]) = 0.64 [0.025]
- Shield (Screen) Diameter (mm [in]) = 1.47 [0.058]

Body Features:

- Wire Size (AWG/CM) = 24 AWG
- Cable Jacket Color = White
- Conductor Type = Tin-Plated Copper
- Wire Color = Blue
- Nominal Outside Diameter (mm [in]) = 1.83 [0.072]
- Wire Diameter (mm [in]) = 1.02 [0.040]

Configuration Features:

- Number of Conductors = 1

Industry Standards:

- Government/Industry Qualification = No
- [RoHS/ELV Compliance](#) = RoHS compliant, ELV compliant
- [Lead Free Solder Processes](#) = Not relevant for lead free process
- RoHS/ELV Compliance History = Converted to comply with RoHS directive

Conditions for Usage:

- Temperature Range (°C) = -65 – +150
- Wire Size - Details = 24 AWG 0.24 mm², 0.00037 in², 19 x 36 AWG

Operation/Application:

- Application = General Purpose - Lightweight

Packaging Features:

- Wire Source = United States

Other:

- Brand = Raychem

Corporate Information

[About TE](#)
[Investors](#)
[News Room](#)
[Supplier Portal](#)
[Careers](#)

Quick Links

[Distributor Inventory](#)
[Product Cross Reference](#)
[Documents & Drawings](#)
[Product Compliance Support Center](#)
[Site Map](#)

Customer Support

[Email or Chat With Us](#)
[Find a Phone Number](#)
[Knowledge Base](#)
[Manage Your Account](#)

Keep Me Informed



[Terms & Conditions](#)

[Privacy Policy](#)

[AODA Accessibility Policy](#)

[AODA Multi-Year Accessibility
Plan](#)

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[TE Connectivity:](#)

[44A1111-24-6-9-US](#)