


## 2110A, 2111A, 2112A, 2113A and 2195A Series Non-Relampable Neon-Incandescent Indicator Lights

### Description and Features

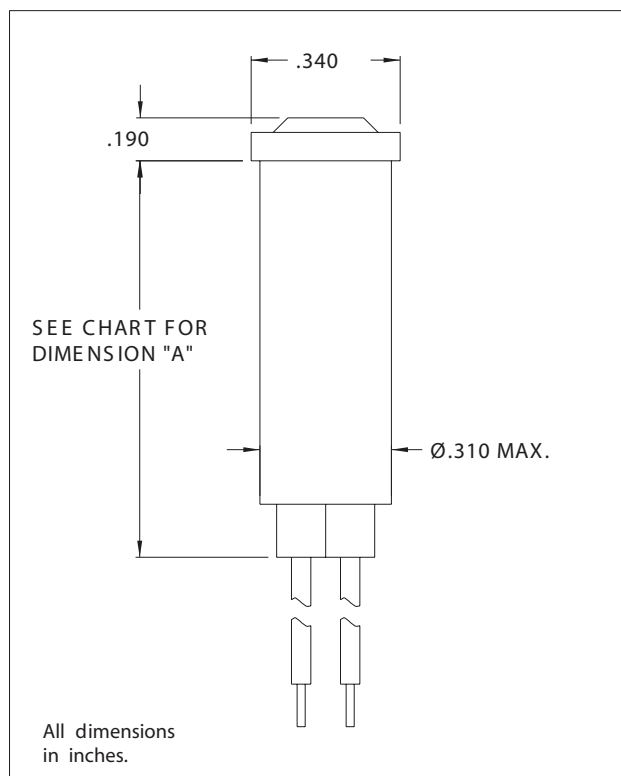

Mounting: Ø.310 MIN., supplied with push-on speednut SN1287.

Wire Leads: No. 22 AWG (105°C) 4.40/4.80 long, stripped .430/.570

Lens: Polycarbonate-neon transparent, incandescent-translucent

Bezel: White nylon.

Housing: White Nylon

| Lens Color | Neon                      |                           | Incandescent       |                    |
|------------|---------------------------|---------------------------|--------------------|--------------------|
|            | Model No.<br>(105-125VAC) | Model No.<br>(208-250VAC) | Model No.<br>(12V) | Model No.<br>(28V) |
| Red        | 2110A1                    | 2111A1                    | 2195A1-12V         | 2195A1-28V         |
| Clear      | 2110A2                    | 2111A2                    | -                  | -                  |
| Amber      | 2110A3                    | 2111A3                    | 2195A3-12V         | 2195A3-28V         |
| White      | 2110A4                    | -                         | -                  | -                  |
| Green      | 2112A5*                   | 2113A5*                   | 2195A5-12V         | 2195A5-28V         |
| Blue       | 2112A6**                  | 2113A6**                  | -                  | -                  |
| Lamp used  | C 2A+Resistor             | C 2A+Resistor             | #2162              | #2187              |
| Lead Color | Black                     | Black/Red                 | Yellow             | Purple             |
| "A" DIM    | 1.480                     | 1.480                     | .740               | .740               |

\* Incorporates G2B lamp and resistor.

\*\* Incorporates T2B lamp and resistor.

Underwriters Laboratories (UL) File No. E20356

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

VCC:

[2195A5-12V](#)