


3990A Series Panel Mounted LED Indicator

Description and Features

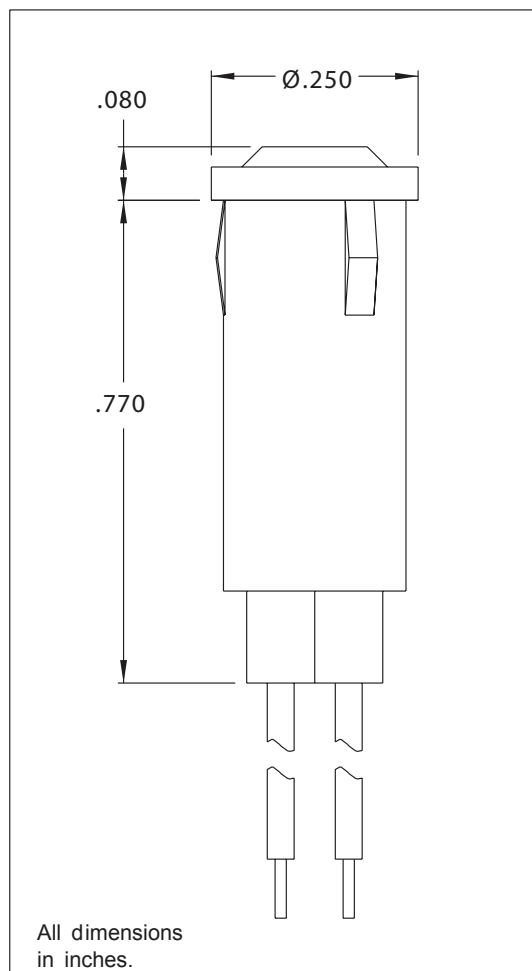

Features

Mounting: Will snap-fit into $\varnothing .217/.221$ hole in panels
.031/.062 thick

Wire leads: No. 24 AWG, 4.4/4.8 long, stripped .430/.570

Anode(+): Red lead

Housing: White nylon

Lens: Polycarbonate

Electro-optical Characteristics

Part Number	Color	Typ. Intensity (mcd)	Rated Current (mA)	Continuous Forward Current Max. (mA)	Forward Voltage Typ. (V)	Forward Voltage Max. (V)	Peak Forward Current @1ms-300pps (A)	Reverse Break-down Voltage Min. (V)
3990A1	Red	10	10	30	2.0	3.0	1.0	5
3990A3	Amber	7	10	30	2.2	3.0	.09	5
3990A5	Green	16	10	30	2.2	3.0	.09	5
3990A7	Yellow	6.3	10	30	2.1	3.0	1.0	5

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

VCC:

[3990A7](#) [3990A5](#) [3990A1](#)