


5332 Series T-1 3/4 Vertical LED Assembly

Description and Features

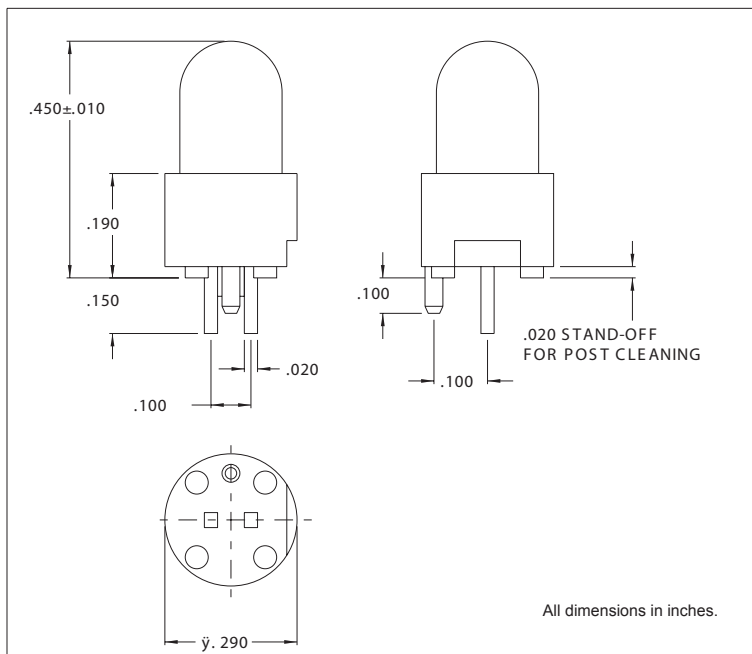

Features

- Block mounting design assures height and side-by-side spacing-alignment saves assembly costs.
- Ultra Brite T-1 3/4 LED lamp-non-diffused high intensity light.
- Press-in mounting pin secures assembly to PC board while being soldered.
- Standoffs prevent flux entrapment.
- RoHS Compliant

Housing: Black Nylon, UL94V-O

Note: Alternate LEDs are also available in this package as a standard variation.

Refer to "Mounting Hole Pattern 3.pdf"

Electro-Optical Characteristics and Ratings

Part Number	Emitted Color	Typical Intensity (mcd)	Rated Current (mA)	Continuous Forward CurrentMax. (mA)	Forward Voltage		Reverse Breakdown VoltageMin. (V)	Peak Wavelength (nm)	Peak Forward Current at 1MS-300PPS (A)
					Typ. (V)	Max. (V)			
5332H1	Red	68	20	60	2.1	3.0	5	650	1.0
5332H5	Green	100	20	60	2.2	3.0	5	563	.09
5332H7	Yellow	160	20	60	2.2	3.0	5	585	1.0

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

VCC:

[5332H7](#) [5332H1](#) [5332H5](#)