



## G-6 1/2 Contact Bayonet Base

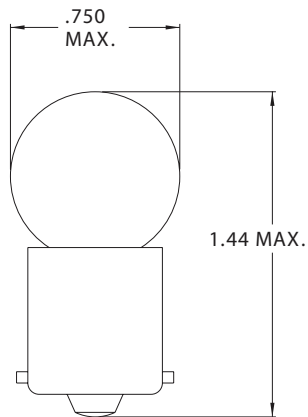

| Part Number | Design Voltage | Amps | MSCP | Life Hours | Filament Type |
|-------------|----------------|------|------|------------|---------------|
| CM81        | 6.5            | 1.02 | 6.0  | 500        | C-2R          |
| CM63        | 7.0            | .63  | 3.0  | 1,000      | C-2R          |
| CM89        | 13.0           | .58  | 6.0  | 750        | C-2R          |
| CM98        | 13.0           | .62  | 6.0  | 800        | C-2V          |
| CM67        | 13.5           | .59  | 4.0  | 5,000      | C-2R          |
| CM69        | 13.5           | .59  | 4.0  | 5,000      | C-2F          |
| CM97        | 13.5           | .69  | 4.0  | 5,000      | C-2V          |
| CM1155      | 13.5           | .59  | 4.0  | 5,000      | C-2R          |
| CM631       | 14.0           | .63  | 6.0  | 1,000      | C-2R          |
| CM1247      | 14.0           | .43  | 3.0  | 1,000      | C-2R          |
| CM71        | 22.0           | .18  | 3.0  | 200        | C-2V          |
| CM509       | 24.0           | .18  | 2.6  | 1,000      | C-2V          |
| CM303       | 28.0           | .30  | 6.0  | 500        | C-2F          |
| CM623       | 28.0           | .37  | 6.0  | 1,000      | 2C-2V         |
| CM1251      | 28.0           | .23  | 3.0  | 2,000      | 2C-2V         |
| CM1223      | 32.0           | .16  | 3.8  | 200        | C-2V          |

## G-6 1/2 Double Contact Bayonet Base

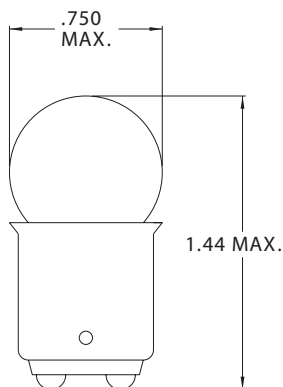

| Part Number | Design Voltage | Amps | MSCP | Life Hours | Filament Type |
|-------------|----------------|------|------|------------|---------------|
| CM82        | 6.5            | 1.02 | 6.0  | 500        | C-2R          |
| CM83        | 6.5            | 1.15 | 6.0  | 1,200      | C-2R          |
| CM1314      | 6.5            | 1.02 | 6.0  | 500        | C-2R          |
| CM64        | 7.0            | .63  | 3.0  | 1,000      | C-2R          |
| CM90        | 13.0           | .58  | 6.0  | 750        | C-2R          |
| CM99        | 13.0           | .62  | 6.0  | 800        | C-2V          |
| CM68        | 13.5           | .59  | 4.0  | 5,000      | C-2R          |
| CM96        | 13.5           | .69  | 4.0  | 5,000      | C-2V          |
| CM1178      | 13.5           | .69  | 4.0  | 5,000      | C-2V          |
| CM632       | 14.0           | .63  | 6.0  | 1,000      | 2C-2R         |
| CM72        | 22.0           | .18  | 3.0  | 200        | C-2V          |
| CM304       | 28.0           | .30  | 6.0  | 500        | C-2F          |
| CM624       | 28.0           | .37  | 6.0  | 1,000      | 2C-2V         |
| CM1252      | 28.0           | .23  | 3.0  | 2,000      | 2C-2V         |
| CM1224      | 32.0           | .16  | 3.8  | 200        | C-2F          |

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

VCC:

[623](#) [CM1251](#) [1252](#) [303](#) [67](#) [CM68](#) [81](#) [304](#)