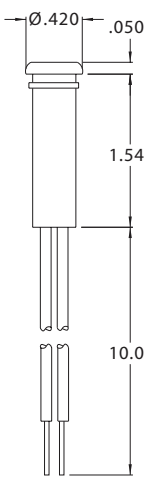
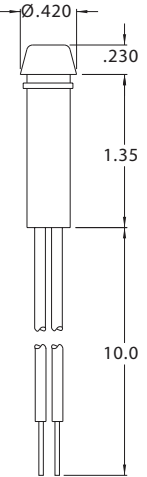
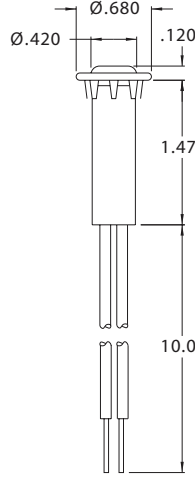
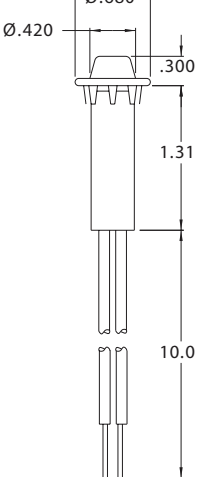


## Glo-Lite Neon Indicator Lights

### Description and Features

6063 Series		6073 Series	
Flat Face	Conical Face	Flat face	Conical Face
			

All dimensions in inches.

The Chicago Miniature Lamp Glo-Lite Indicator Lights are designed for applications requiring a low cost, line voltage, power-on indicator. These indicator lights utilize a high brightness C2A neon lamp providing good visibility and a long life. These indicator lights are constructed with a one-piece body and lens and are available in two face configurations, flat or conical, with or without a chrome bezel.

## Specifications

Part Number:	Description
6063-001-534R	Red, Flat Face, No Bezel
6063-001-634R	Red, Conical Face, No Bezel
6073-001-534R	Red, Flat Face, Chrome Bezel
6073-001-634R	Red, Conical Face, Chrome Bezel
As special order, these indicator lights are available with white, amber or green lenses	

Mounting Hole:	.375 for 6063 Series, .500 for 6073 Series
Mounting Centers:	.500 for 6063 Series, .688 for 6073 Series
Maximum Panel Thickness:	1.25 for 6063 Series, .078 for 6073 Series
Housing/Lens Material:	Nylon
Bezel (6073 Series only):	Chrome Plated Brass
Wire Leads:	22 AWG, black 105°C PVC Insulation, stranded
Electrical:	125 Volts AC, Built-in 30K ohm 1/4 Watt resistor
Approvals:	UL recognized, CSA certified

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

VCC:

[6073-001-634G](#)