



## T-1 3/4 Wedge Base

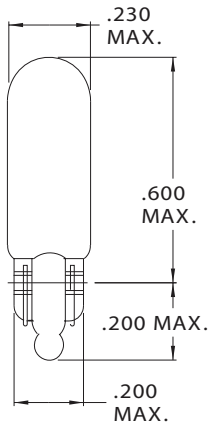

| Part Number | Design Voltage | Amps | MSCP | Life Hours | Filament Type |
|-------------|----------------|------|------|------------|---------------|
| CM11        | 2.5            | .200 | .200 | 1,000      | C-2R          |
| CM111       | 2.7            | .100 | .230 | 5          | S-2           |
| CM56        | 5.0            | .115 | .150 | 20,000     | C-2R          |
| CM79        | 6.0            | .200 | .600 | 1,000      | C-2R          |
| CM16        | 6.3            | .150 | .340 | 5,000      | C-2F          |
| CM84        | 6.3            | .040 | .030 | 20,000     | C-2R          |
| CM86        | 6.3            | .200 | .400 | 20,000     | C-2F          |
| CM18        | 14.0           | .040 | .130 | 5,000      | C-2F          |
| CM37        | 14.0           | .090 | .500 | 1,500      | C-2F          |
| CM70        | 14.0           | .150 | 1.50 | 100        | C-2F          |
| CM73        | 14.0           | .080 | .300 | 15,000     | C-2F          |
| CM74        | 14.0           | .100 | .700 | 500        | C-2F          |
| CM17        | 28.0           | .065 | .650 | 5,000      | C-2F          |
| CM85        | 28.0           | .040 | .300 | 7,000      | C-2F          |

## T-1 3/4 Midget Screw Base

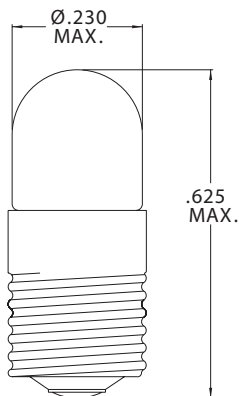

| Part Number | Design Voltage | Amps | MSCP | Life Hours | Filament Type |
|-------------|----------------|------|------|------------|---------------|
| CM8669      | 1.35           | .060 | .010 | 500        | C-6           |
| CM1767      | 2.50           | .200 | .200 | 500        | C-2R          |
| CM1769      | 2.50           | .200 | .200 | 500        | C-2R          |
| CM8693      | 2.70           | .060 | .040 | 6,000      | C-2R          |
| CM3153      | 5.00           | .060 | .150 | 5,000      | C-2R          |
| CM342       | 6.00           | .040 | .030 | 10,000     | C-2V          |
| CM1768      | 6.00           | .200 | .600 | 1,000      | C-2R          |
| CM7323      | 6.00           | .200 | .550 | 5,000      | C-2R          |
| CM378       | 6.30           | .200 | .400 | 20,000     | C-2F          |
| CM1775      | 6.30           | .075 | .230 | 1,000      | C-2R          |
| CM389       | 10.0           | .040 | .080 | 5,000      | C-2F          |
| CM373       | 14.0           | .080 | .500 | 1,500      | C-2F          |
| CM383       | 14.0           | .080 | .500 | 750        | C-2F          |
| CM8162      | 14.0           | .100 | .500 | 10,000     | C-2F          |
| CM8362      | 14.0           | .080 | .300 | 15,000     | C-2F          |
| CM8536      | 18.0           | .040 | .150 | 10,000     | C-2F          |
| CM335       | 28.0           | .040 | .340 | 4,000      | C-2F          |
| CM335LSV    | 28.0           | .060 | .340 | 25,000     | C-2F          |
| CM369       | 28.0           | .040 | .340 | 4,000      | C-2F          |
| CM399       | 28.0           | .040 | .300 | 7,000      | C-2F          |
| CM8369      | 28.0           | .065 | .650 | 15,000     | C-2F          |
| CM8384      | 28.0           | .040 | .150 | 10,000     | C-2F          |

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

VCC:

85 335LSV 18 73-10PK 86-10PK