



T-2 Telephone Slide Base - Type 5 (short)

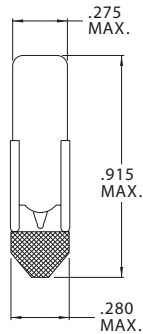


Part Number	Design Voltage	Amps	MSCP	Life Hours	Filament Type
CM18ESB	18.0	.040	850	5,000	C-2F
CM24CSB	24.0	.017	100	15,000	C-2F
CM24ESB	24.0	.040	850	8,000	C-2F
CM28ESB	28.0	.040	1,500	6,000	C-2F
CM48ESB	48.0	.040	3,000	5,000	CC-2F

T-2 Telephone Slide Base - Type 5 (standard)

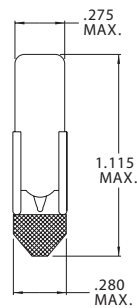

Part Number	Design Voltage	Amps	MSCP	Life Hours	Filament Type
CM6PSB	6.0	.140	550	20,000	C-2V
CM12PSB	12.0	.170	2,000	12,000	C-2F
CM24PSB	24.0	.073	3,000	10,000	C-2F
CM28PSB	28.0	.040	1,600	5,000	C-2F
CM48PSB	48.0	.053	1,800	10,000	C-7A
CM60PSB	60.0	.050	2,200	7,500	C-7A
CM120PSB	120.0	.025	1,200	5,000	CC-7A

T-2 Telephone Slide Base - Type 3

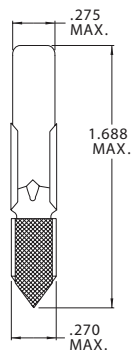

Part Number	Design Voltage	Amps	MSCP	Life Hours	Filament Type
CM4A	4.0	.190	450	5,000	C-2
CM6A	6.0	.140	510	15,000	C-2V
CM6B	6.0	.290	270	15,000	C-2F
CM6C	6.0	.040	180	4,000	C-2
CM8A	8.0	.090	600	1,000	C-2
CM10A	10.0	.110	600	5,000	C-2V
CM10B	10.0	.250	900	5,000	C-2F
CM10EX	10.0	.035	100	10,000	C-6
CM12A	12.0	.100	1,200	8,000	C-2F
CM12B	12.0	.035	650	2,000	C-6
CM12C	12.0	.170	1,500	5,000	C-2V
CM15A	15.0	.100	720	1,000	C-2F
CM16A	16.0	.100	720	5,000	C-2F
CM18A	18.0	.040	800	1,000	C-2F
CM18B	18.0	.100	600	10,000	C-2F
CM24A	24.0	.030	600	1,000	C-2F
CM24B	24.0	.040	1,000	4,000	C-2F
CM24C	24.0	.072	1,400	6,000	C-2F

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

VCC:

[24X](#) [48ESB-](#) [120PSB-](#) [12ESB-](#) [12PSB-](#) [16ESB-](#) [24PSB-](#) [28ESB-](#) [28PSB-](#) [48PSB-](#) [60PSB-](#) [12PSB--10PK](#)
[6PSB-](#)