



T-2 Telephone Slide Base - Type 3

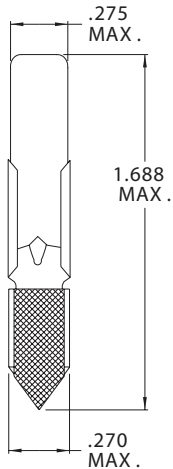

Part Number	Design Voltage	Amps	MSCP	Life Hours	Filament Type
CM24D	24.0	.100	1,500	5,000	C-7A
CM24E	24.0	.035	600	7,000	C-2F
CM24F	24.0	.090	1,120	7,000	C-2F
CM24H	24.0	.020	100	10,000	C-2F
CM24X	24.0	.035	600	8,000	C-2F
CM30A	30.0	.072	2,000	3,000	C-7A
CM30C	30.0	.038	1,000	4,000	C-2F
CM32B	32.0	.040	1,600	3,500	C-2F
CM30B	35.0	.100	3,000	4,000	C-7A
CM35A	35.0	.040	1,000	7,500	C-2F
CM35B	35.0	.072	700	5,000	C-7A
CM35C	35.0	.100	750	5,000	C-7A
CM40A	40.0	.072	480	5,000	C-7A
CM44A	44.0	.072	1,250	1,000	C-7A
CM48A	48.0	.072	2,000	5,000	C-7A
CM48B	48.0	.100	2,200	10,000	C-7A
CM48C	48.0	.035	400	7,000	C-7A
CM48D	48.0	.021	100	20,000	C-7A
CM48G	48.0	.052	800	5,000	C-7A
CM48H	48.0	.045	1,000	5,000	C-7A
CM55B	55.0	.100	1,800	5,000	C-7A
CM55C	55.0	.050	1,400	5,000	C-7A
CM60A	60.0	.050	1,600	5,000	C-7A

T-2 Miniature Bayonet Base

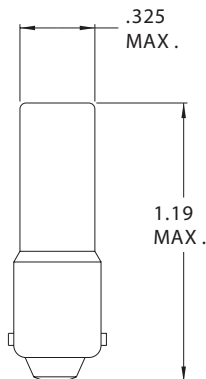

Part Number	Design Voltage	Amps	MSCP	Life Hours	Filament Type
CM6MB	6.0	.140	550	20,000	C-2V
CM12MB	12.0	.170	2,000	12,000	C-2F
CM24MB	24.0	.073	3,000	10,000	C-2F
CM28MB	28.0	.040	1,600	5,000	C-2F
CM48MB	48.0	.053	1,800	10,000	C-7A
CM60MB	60.0	.050	2,200	7,500	C-7A
CM120MB	120.0	.025	1,200	5,000	CC-7A
CM8-967	120.0	.025	1,200	5,000	CC-7A

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

VCC:

[60MB](#) [120MB](#) [28MB](#) [8-967](#) [24MB](#) [120MB-10PK](#) [24MB-10PK](#) [120MBLS-R-CR](#) [120MB-SD](#) [120MBL-A-CA](#)
[120MBLS-A-CA](#) [120MBLS-G-CG](#) [120MBLS-B-CB](#) [120MBL-L-CW](#) [120MBL-B-CW](#) [120MBL-CWA](#) [120MBL-CWB](#)
[120MBLS-W-CW](#) [120MBL-W-CW](#) [120MBL-G-CW](#) [120MBL-G-CG-R-](#) [120MBLS-L-CW](#) [120MBL-A-CA-R-](#) [120MBLS-](#)
[B-CW](#) [120MBLS-O-CA](#) [120MBL-B-CB-R-](#) [120MBLS-CWW-R-](#) [120MBL-A-CW](#) [120MBL-R-CW](#) [120MBLS-CWW](#)
[120MBL-NWR](#) [120MBL-R-CR-R-](#) [120MBL-CWW](#) [120MBL-CWG](#) [120MBLS-R-CW](#) [120MBL-CWR](#) [120MBL-B-CB](#)
[120MBL-G-CG](#) [120MBL-O-CA](#) [120MBL-R-CR](#) [120MBLS-W-CW-R-](#) [120MBL-W-CW-R-](#)