



## T-1 1/2 Wedge Base

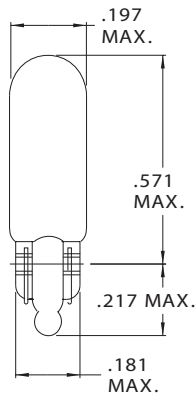



| Part Number | Design Voltage | Amps | MSCP | Life Hours | Filament Type |
|-------------|----------------|------|------|------------|---------------|
| CM6502      | 4.0            | .250 | .200 | 1,000      | C-2V          |
| CM1103      | 6.0            | .030 | .024 | 1,000      | C-2R          |
| CM1104      | 6.0            | .080 | .070 | 5,000      | C-2V          |
| CM3105      | 6.0            | .167 | .300 | 5,000      | C-2R          |
| CM6516      | 6.0            | .178 | .720 | 1,000      | C-2R          |
| CM6521      | 6.0            | .167 | .480 | 1,000      | C-2R          |
| CM6522      | 6.0            | .030 | .040 | 1,000      | C-2V          |
| CM6515      | 7.0            | .035 | .040 | 1,000      | C-2V          |
| CM1107      | 12.0           | .030 | .080 | 1,000      | C-2V          |
| CM1108      | 12.0           | .080 | .240 | 5,000      | C-2R          |
| CM286       | 13.5           | .090 | .570 | 200        | C-2V          |
| CM1111      | 24.0           | .040 | .240 | 5,000      | C-2F          |
| CM3110      | 24.0           | .030 | .100 | 5,000      | C-2F          |

## T-1 3/4 Wire Terminal

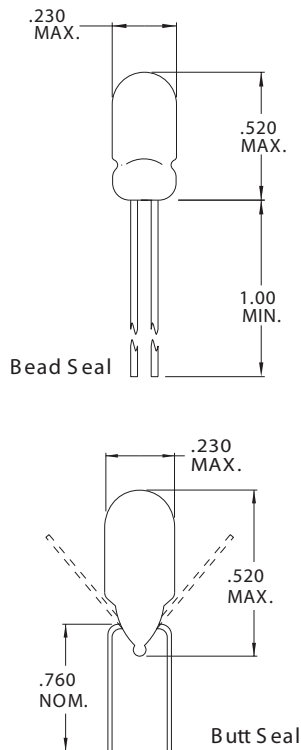

| Part Number | Design Voltage | Amps | MSCP | Life Hours | Filament Type |
|-------------|----------------|------|------|------------|---------------|
| CM2184      | 1.30           | .050 | .020 | 30         | S-2           |
| CM1728      | 1.35           | .060 | .010 | 500        | C-6           |
| CM2119      | 2.00           | .060 | .001 | 5,000      | C-2R          |
| CM1783      | 2.50           | .200 | .220 | 500        | C-2R          |
| CM2169      | 2.50           | .350 | .200 | 10,000     | C-2R          |
| CM2264      | 2.50           | .400 | .280 | 5,000      | C-2R          |
| CM1738      | 2.70           | .060 | .040 | 6,000      | C-2R          |
| CM2129      | 3.00           | .300 | .340 | 1,500      | C-2R          |
| CM2156      | 3.00           | .030 | .020 | 1,800      | C-6           |
| CM2158      | 3.00           | .015 | .004 | 10,000     | C-6           |
| CM8847      | 3.00           | .350 | .300 | 10,000     | C-2R          |
| CM2171      | 4.50           | .120 | .040 | 25,000     | C-2F          |
| CM2200      | 5.00           | .060 | .050 | 25,000     | C-2R          |
| CM2203      | 5.00           | .115 | .150 | 40,000     | C-2R          |
| CM3151      | 5.00           | .060 | .150 | 5,000      | C-2R          |
| CM3626      | 5.00           | .060 | .050 | 25,000     | C-2R          |
| CM3627      | 5.00           | .220 | .600 | 30,000     | C-2R          |
| CM3628      | 5.00           | .220 | .600 | 30,000     | C-2R          |
| CM3950      | 5.00           | .017 | .018 | 2,000      | C-2R          |
| CM8784      | 5.00           | .190 | .450 | 1,000      | C-2R          |
| CM8805      | 5.00           | .060 | .030 | 60,000     | C-2R          |
| CM1730      | 6.00           | .040 | .030 | 10,000     | C-2V          |
| CM1784      | 6.00           | .200 | .600 | 1,000      | C-2R          |
| CM2191      | 6.00           | .036 | .010 | 40,000     | C-2V          |
| CM8664      | 6.00           | .200 | .100 | 50,000     | C-2F          |

## T-1 3/4 Wire Terminal (standard)

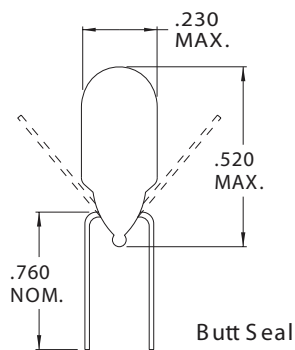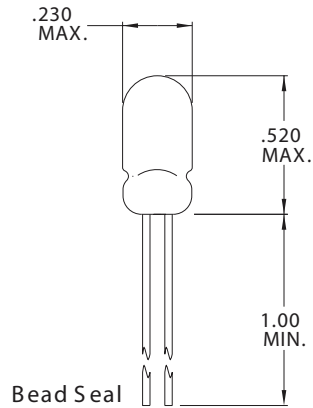

| Part Number | Design Voltage | Amps | MSCP | Life Hours | Filament Type |
|-------------|----------------|------|------|------------|---------------|
| CM1739      | 6.30           | .070 | .230 | 1,000      | C-2R          |
| CM2037      | 6.30           | .200 | .400 | 20,000     | C-2R          |
| CM2039      | 6.30           | .075 | .230 | 1,000      | C-2R          |
| CM2112      | 6.30           | .200 | .550 | 5,000      | C-2R          |
| CM2179      | 6.30           | .040 | .030 | 20,000     | C-2V          |
| CM2180      | 6.30           | .040 | .020 | 20,000     | C-2V          |
| CM2181      | 6.30           | .200 | .400 | 20,000     | C-2F          |
| CM8350      | 6.30           | .150 | .450 | 3,000      | C-2R          |
| CM2178      | 8.00           | .085 | .150 | 25,000     | C-2F          |
| CM1869      | 10.00          | .014 | .002 | 50,000     | C-2F          |
| CM2107      | 10.00          | .040 | .080 | 5,000      | C-2F          |
| CM2149      | 10.00          | .014 | .002 | 50,000     | C-2F          |
| CM8946      | 11.00          | .022 | .030 | 10,000     | C-2F          |
| CM2174      | 12.00          | .040 | .100 | 10,000     | C-2F          |
| CM1705      | 14.00          | .080 | .500 | 1,500      | C-2F          |
| CM2162      | 14.00          | .100 | .500 | 10,000     | C-2F          |
| CM2182      | 14.00          | .080 | .300 | 40,000     | C-2F          |
| CM2382      | 14.00          | .080 | .300 | 40,000     | C-2F          |
| CM2102      | 18.00          | .040 | .150 | 10,000     | C-2F          |
| CM8425      | 22.00          | .040 | .300 | 2,000      | C-2F          |
| CM2041      | 24.00          | .060 | .500 | 5,000      | C-2F          |
| CM2176      | 24.00          | .050 | .500 | 1,000      | C-2F          |
| CM476       | 28.00          | .060 | .340 | 25,000     | C-2F          |
| CM1749      | 28.00          | .060 | .340 | 25,000     | C-2F          |
| CM1762      | 28.00          | .040 | .340 | 4,000      | C-2F          |
| CM1764      | 28.00          | .040 | .340 | 4,000      | C-2F          |
| CM2185      | 28.00          | .040 | .150 | 10,000     | C-2F          |
| CM2187      | 28.00          | .040 | .300 | 7,000      | C-2F          |
| CM2287      | 28.00          | .040 | .300 | 7,000      | C-2F          |
| CM2370      | 28.00          | .050 | .700 | 1,000      | C-2F          |
| CM6033      | 28.00          | .024 | .150 | 4,000      | CC-2F         |
| CM8361      | 28.00          | .065 | .650 | 5,000      | C-2F          |
| CM8461      | 28.00          | .050 | .500 | 5,000      | C-2F          |
| CM1918      | 32.00          | .040 | .300 | 7,000      | C-2F          |
| CM6748      | 48.00          | .025 | .200 | 5,000      | CC-2F         |

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

VCC:

[1111](#) [2200](#) [2107](#) [1705](#) [1764](#) [1738](#) [2171](#) [2176](#) [1728](#) [2158](#) [1784](#) [1783](#) [2119](#) [2112](#) [CM1918](#)