

T-1 3/4 SUB-MINIATURE LAMP



Data Display Products®

Socket and Fresnel Lens

- Flange Base Socket for Model MF200

TO ORDER, FOLLOW THE EXAMPLE:

Select one **BOLD** component from each SHADED column in the tables below.

1 Socket		
MFS1-B		
1 Model	2 Lens Diffusion	3 Lens Color
MF61	-C	R


→Part Number **MFS1-B** (Socket)
MF61-CR (Model MF61, Clear Red Lens)

SOCKET	
1 Part #	Description
MFS1-B ^[1]	For Use With Model MF200 and MF61 lens


Lens (For Use With MFS1-B Socket)		
1 MODEL	2 Lens Diffusion	3 Lens Color
MF61	-C Clear	R Red
	-N Diffused	A Amber
		Y Yellow
		G Green
		B Blue
		W Water Clear
		-S ^[2] Smoke



MFS-1

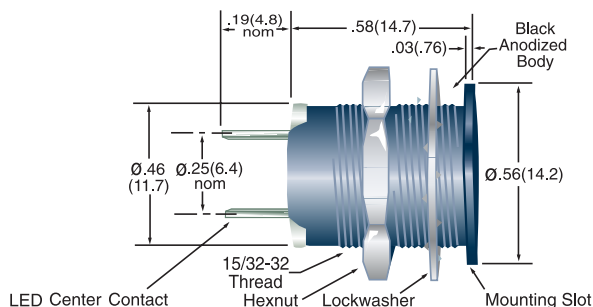

MF61

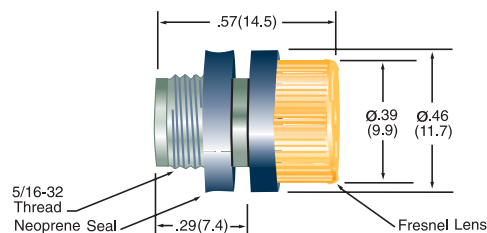

[1] For Mounting Diameter .470" +/- .005"; Panel Thickness 1/16" to 5/16".

[2] Do not select a Diffusion Code (e.g. MF61-S).

All dimensions are in inches (mm)

Tolerances: .xx(.x) ±.025"(.63) / .xxx(.xx)±.010"(.25)
 Specifications are subject to change without notice.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

VCC:

[MF61-CB](#) [MF61-NG](#) [MF61-NW](#) [MF61-NA](#) [MF61-CW](#) [MF61-CR](#) [MF61-CA](#) [MF61-CY](#) [MF61-CG](#) [MF61-NY](#) [MF61-NR](#) [MF61-NB](#)