





- Candelabra Screw Base
- Double-Contact Bayonet Base
- Built-in shunt resistor (optional)
- Bi-Polar
- High-Intensity
- Up to 100,000-hour life
- Shock and vibration resistant

INCANDESCENT LAMP #	PowerLine® PART # STANDARD	PowerLine® PART # WITH SHUNT RESISTOR	APPLIED VOLTAGE	MAXIMUM VOLTAGE	FIG #
3S6/120V	6S6L120-CWX	6S6LS120-CWX	120AC/DC	130	1
6S6/30V	6S6L30-CWX	6S6LS30-CWX	30AC/DC	33	1
6S6/120V	6S6L120-CWX	6S6LS120-CWX	120AC/DC	130	1
6S6DC/120V	6S6DCL120-CWX	6S6DCLS120-CWX	120AC/DC	130	2
6S6/130V	6S6L130-CWX	6S6LS130-CWX	130AC/DC	140	1
6S6DC/130	6S6DCL130-CWX	6S6DCLS130-CWX	130AC/DC	140	2
6S6/155V	6S6L155-CWX	6S6LS155-CWX	155AC/DC	165	1

LED COLOR CODE	EMITTED COLOR	Used to illuminate the following lenses							
		Red	Orange	Amber	Yellow	Green	Blue	White	Clear
-CWR	Red	*						*	*
-CWO	Orange		*	*				*	*
-CWA	Amber			*	*			*	*
-CWG	Green					*		*	*
-CWB	Blue						*	*	*
-CWW	White							*	*

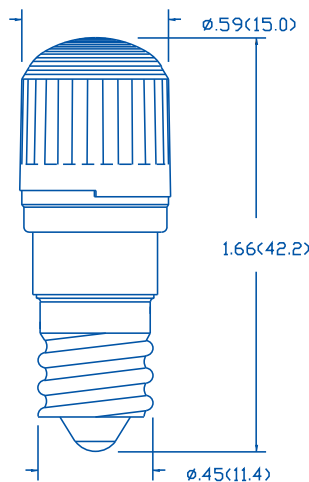

6S6L
Figure 1

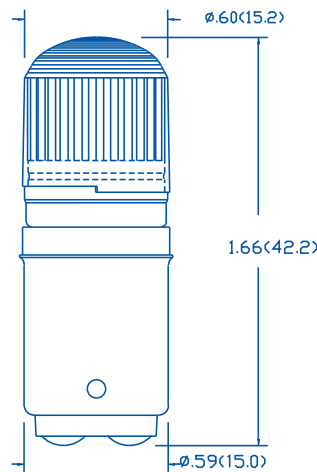

6S6DCL
Figure 2

All dimensions are in inches (mm) Tolerances: .xx"(.x) ±.025"(.63)/ .xxx"(.xx)±.010"(.25) Specifications are subject to change without notice.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

VCC:

[6S6L130-CWR](#) [6S6DCLS130-CWR](#) [6S6L155-CWB](#) [6S6DCLS120-CWB](#) [6S6L30-CWA](#) [6S6LS155-CWW](#) [6S6L155-CWR](#) [6S6L120-CWR](#) [6S6L130-CWB](#) [6S6L30-CWR](#) [6S6LS155-CWA](#) [6S6DCL120-CWB](#) [6S6LS30-CWW](#) [6S6DCL130-CWW](#) [6S6LS155-CWG](#) [6S6L130-CWG](#) [6S6LS120-CWO](#) [6S6L30-CWO](#) [6S6L120-CWW](#) [6S6L30-CWB](#) [6S6L120-CWG](#) [6S6LS155-CWO](#) [6S6LS130-CWO](#) [6S6DCL130-CWA](#) [6S6L155-CWG](#) [6S6DCLS130-CWA](#) [6S6LS30-CWG](#) [6S6L130-CWA](#) [6S6L130-CWW](#) [6S6L130-CWO](#) [6S6DCL120-CWA](#) [6S6DCLS120-CWO](#) [6S6L120-CWO](#) [6S6LS30-CWA](#) [6S6L155-CWA](#) [6S6LS155-CWB](#) [6S6L120-CWA](#) [6S6DCLS130-CWW](#) [6S6L155-CWW](#) [6S6DCLS120-CWA](#) [6S6DCLS130-CWB](#) [6S6LS30-CWR](#) [6S6L155-CWO](#) [6S6DCLS130-CWO](#) [6S6DCL130-CWO](#) [6S6DCL120-CWO](#) [6S6DCL130-CWB](#) [6S6L30-CWW](#) [6S6DCLS130-CWG](#) [6S6L30-CWG](#) [6S6DCL120-CWG](#) [6S6LS120-CWB](#)