


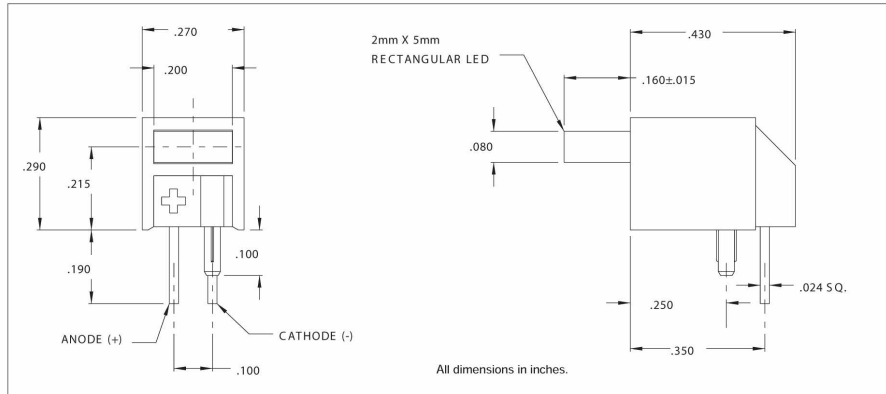

Emitted color	Green
Lens color	Green
Lum in min (mcd)	1
Lum in type (mcd)	4
Rated current (mA)	20
Cont forward current max	30
Fwd volts type	2,2
Forward volt max.	3
Reverse breakdown V	7
Viewing angle (°)	100
Peak Wave Lenght (mA)	565
Housing type	UL94V-0
ROHS Status	Yes

Drawn : VG	Ch'd : VG	Datasheet : 6310D	Print date : 06/09/06
Revision :	Revision date : 2006-03-06	Name : VG	Scale :

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

VCC:

6310D5