 




Lamp Sockets and Accessories

Low Cost Pin Socket for Bi-Pin Lamps (Recommended for .100" or wider lead spacing)

Part Number: CM21-16






Mounting Hole: .038"


CM21-16 Pin Socket may be pre-assembled to your bi-pin lamp by specifying the following options.
(Example: CM7387-299)

Option - 298

 
Option - 299

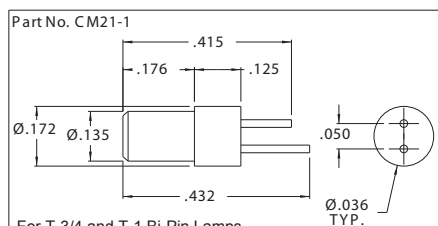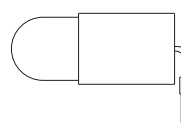

For T-3/4 and T-1 Bi-Pin Lamps
Recommended mounting hole .130" nominal,
maximum panel thickness .125".

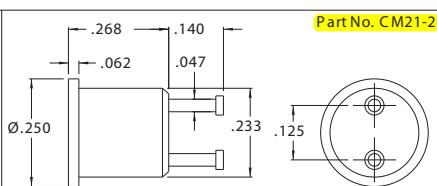


For T-1 3/4 Bi-Pin Lamps
Recommended mounting hole .221" nominal,
maximum panel thickness .250".

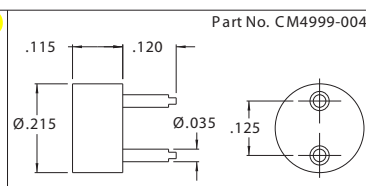

For T-1 3/4 Bi-Pin Lamps

CM39 Series Colored Silicone Filter Boots

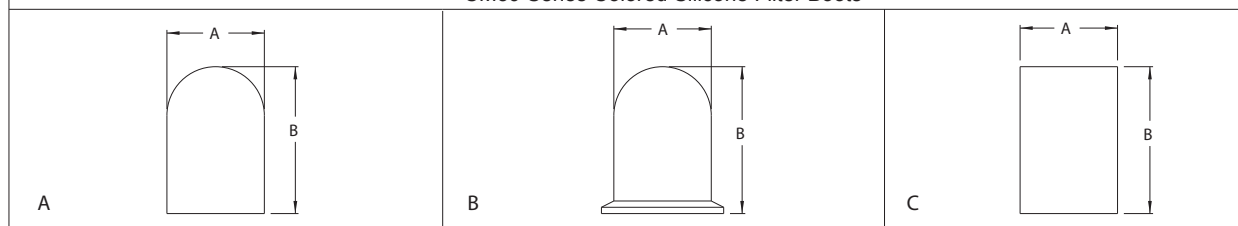

Part Number: CM39 - XX - X

Type Designation	Lamp Size	Configuration	Dimensions		Color Designation	Color
			A	B		
02	T-3/4	A	.090	.230□	1	Red
03	T-1	A	.096□	.312□	2	Blue/White
04	T-1	A	.096	.219□	3	Clear
05	T-1 1/4	A	.175	.265□	4	Amber
06	T-1 3/4	A	.214	.375□	5	Green
07	T-1 3/4	B	.218	.312□	6	Blue
08	T-1 3/4	B	.218	.279□	7	Yellow
09	T-2	C	.250	.522□		
10	T-2	C	.250	.272□		
11	T-3 1/4	A	.370	.672		

Chicago Miniature Lamp reserves the right to make specification revisions that enhance the design and/or performance of the product

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

VCC:

CM39-06-6