


- Current Rating : 3 amp
- Hole Diameter on PCB : 0.055"
- Brass alloy shell, sleeve and post
- Accepts 0.015" to 0.025" diameter leads
- Three level wire wrap tail
- 0.025" square post
- 10 micron gold flash over nickel plating on contacts and shell/sleeve/posts
- R31, R52, R53 with male pin/lead depth of 0.170"
- R32 with male pin/lead depth of 0.130"
- Four finger contacts : R31, R32, R52
- Six finger contacts : R53

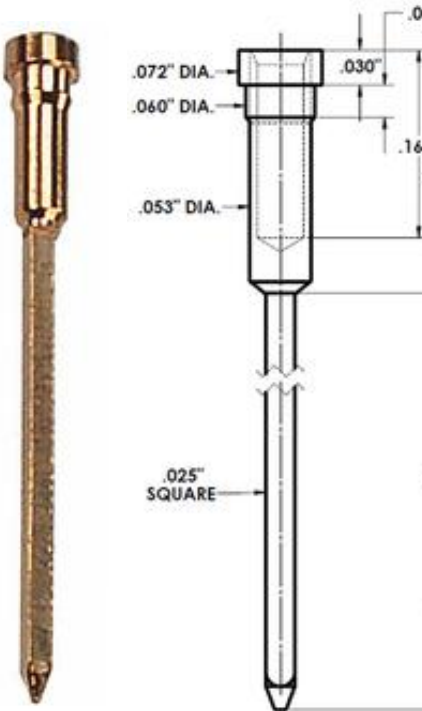

R31

Ordering Info

Part Number	Qty/Pack	Contacts	Male pin depth	Insertion Tool
R31/C	100	Four-Finger	0.170"	-
R31/M	1000	Four-Finger	0.170"	-
R32/C	100	Four-Finger	0.130"	P158 with D9 die point
R32/M	1000	Four-Finger	0.130"	P158 with D9 die point
R52/C	100	Four-Finger	0.170"	-
R52/M	1000	Four-Finger	0.170"	-
R53/C	100	Six-Finger	0.170"	-
R53/M	1000	Six-Finger	0.170"	-

Tools sold separately



Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Vector:](#)

[R31/C](#)