


Fixing Accessories for Wirewound Resistors Equipped with AN Collars Suitable for RW - RA - RSSD - RSO

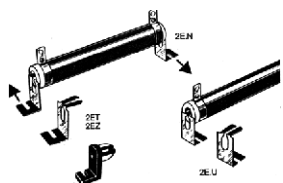

These 2E double right-angle brackets are designed to fix resistors without providing electrical contact. As they are fitted to resistors with fixing insulated connections, they can be mounted on uninsulated panels.

FEATURES


- They are available in three versions:
 - Bracket 2E N Shape 
 - Bracket 2E U Shape  (restricted space)
 - Brackets 2E T or 2E Z shape  designed for models of Ø 40 mm and 50 mm
- The brackets are metal, and are corrosion-resistant
- Material categorization: For definitions of compliance please see www.vishay.com/doc?99912




RoHS
COMPLIANT

DIMENSIONS in millimeters

DOUBLE RIGHT-ANGLE BRACKET 2E N

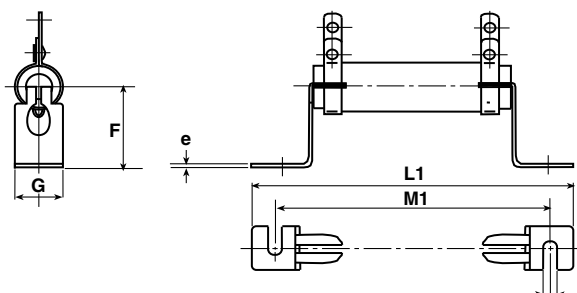

DOUBLE RIGHT-ANGLE BRACKET 2E U

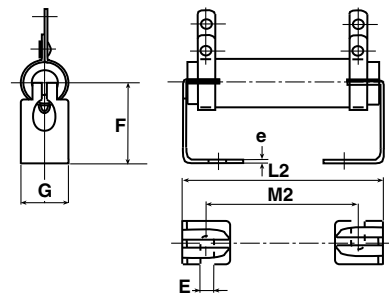

DIMENSIONS in millimeters											
SERIES		BRACKET	E ± 0.1	F ± 1	G ± 0.5	L1 - 0 - 4	M1 - 1 - 4	L2 - 0 - 4	M2 - 0 - 4	E	AVERAGE UNIT WEIGHT IN g
RW RSO RA	RSSD										
8 x 34	8 x 34	2E BN or 2E BU	3.2	21.5	8	58	48	38	26	1	1.8
10 x 50	10 x 50	2E DN or 2E DU	3.2	21.5	10	74	64	54	42	1	2.2
13 x 70		2E DN or 2E DU	3.2	21.5	10	94	84	74	62	1	2.2
	13 x 70	2E FN or 2E FU	4	26.5	14	102.5	88.5	74.5	58	1.2	4.5
16 x 94	16 x 94	2E HN or 2E HU	5	29.5	20	132.5	115.5	98.5	79	1.2	8
20 x 117		2E HN or 2E HU	5	29.5	20	155.5	138.5	121.5	102	1.2	8
	20 x 117	2E KN or 2E KU	5.5	37.5	22	161.5	141.5	121.5	99	1.2	13
25 x 138		2E KN or 2E KU	5.5	37.5	22	182.5	162.5	142.5	120	1.2	13
25 x 168		2E KN or 2E KU	5.5	37.5	22	212.5	192.5	172.5	150	1.2	13
	25 x 138	2E MN or 2E MU	5.5	37.5	22	182.5	162.5	142.5	120	1.2	13
	25 x 168	2E MN or 2E MU	5.5	37.5	22	212.5	192.5	172.5	150	1.2	13
30 x 250		2E PN or 2E PU	8	44.2	30	311	283	255	224	1.5	28
	30 x 250	2E SN or 2E SU	8	44.2	30	311	283	255	224	1.5	28
40 x 370	40 x 370	2E T	9	40	40	448	418	-	-	6	65
50 x 373	50 x 373	2E Z	9	40	40	451	421	-	-	6	65



ORDERING INFORMATION

MODEL	TYPE	PAIR	LEAD (PB)-FREE
2E	BN	...	e
Fixing accessories for RW 8 x 34 AN resistor			

Note

- Brackets are sold in pairs

SAP PART NUMBERING GUIDELINES

ACCRF	2E	BN
MODEL	STYLE	TYPE

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Vishay:](#)

[ACCRF2EMN](#) [ACCRF2ESN](#) [ACCRF2EPN](#) [ACCRF2EKN](#) [ACCRF2EHN](#)