


VOLEX

GROUP

Standard Cord Details: 17567 10 C3




Specifications	
Certifications	
Part Number	17567 10 C3
Connector Type	C13
Plug Type	6-15P
Category	Plastic
Application	Detachable
Plug Catalog No.	VS205S
Connector Catalog No.	386A
Cable	SVT AWG 18x3
Jacket Color	black
Length in Feet	9'10"
Length in Meters	3
Temperature Rating	60 C
Packaging Units Per Carton	H-25
Color Coding	International
Nominal OD in Inches	0.246
Nominal OD in Millimeters	6.25
Notes	See 17569 for SJT version.

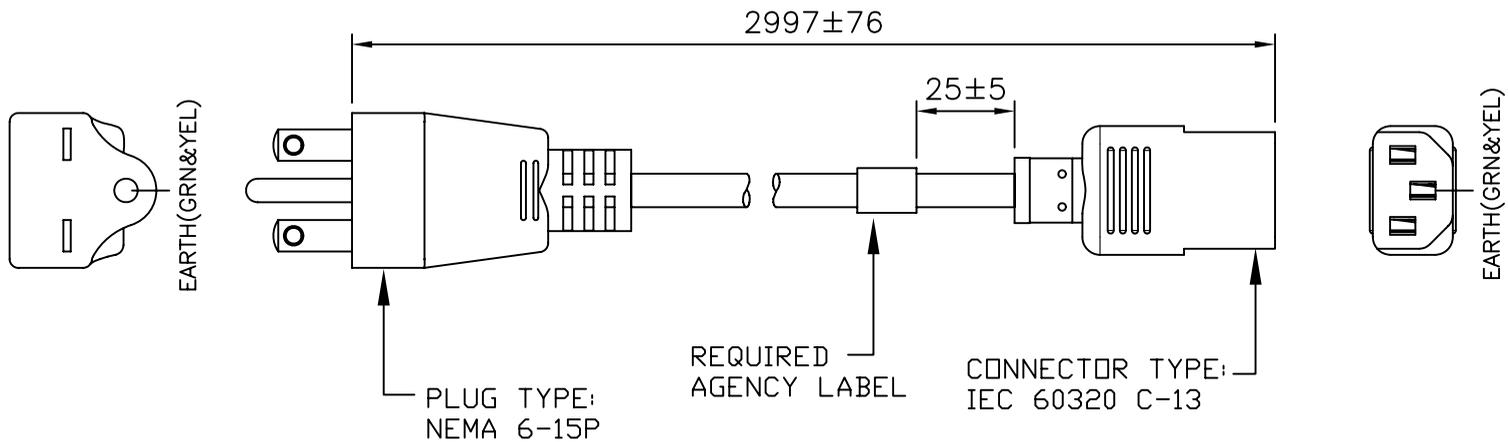

VOLEX RESERVES THE RIGHT TO ALTER NON-CRITICAL DIMENSIONS WITHOUT NOTICE.

PACKAGING: FOLD & TIE

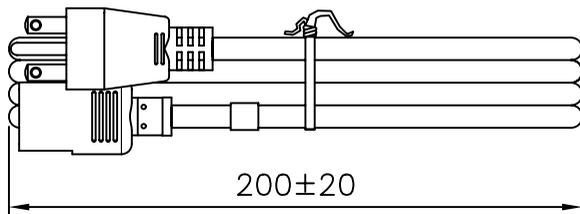

NOTES:

- 1) CORDAGE: 18/3 SVT, 60°C, BLACK
- 2) CONDUCTOR INSULATION COLORS ARE BLUE, BROWN AND GREEN/YELLOW. POLARITY NOT REQUIRED FOR 250V APPLICATION.
- 3) APPROVALS: UL/CSA
- 4) RATING: 10 AMP/250 VOLTS
- 5) FLAME RATING : FT2
- 6) PACKAGING: 25 PIECES/CARTON
- 7) ALL DIMENSIONS IN MILLIMETERS.

1	REVISED AND REDRAWN	11/26/07
1	C.U.D - NEW RELEASE	8/25/04
REV	DESCRIPTION	DATE



FORM IN71-07 REV.A

- Indianapolis, IN
- Conover, N.C.
- Fremont, CA
- Aguascalientes, MX
- Tijuana, Mexico
- Hermosillo, MX
- Clinton, AR
- Kanata, Canada

Proprietary Notice:

This document is the property of Volex Incorporated. The information contained herein is not to be disclosed to anyone without the express written consent of Volex Inc.

MATERIAL:
PLUG: PVC, BLACK
JACKET: PVC, BLACK

FINISH:
JACKET: SMOOTH

SCALE:
NOT TO SCALE

ECD:
N/A

ITEM DESCRIPTION
CORDSET - NORTH AMERICAN
DETACHABLE POWER SUPPLY CORD (9'10")

TOLERANCE
UNLESS OTHERWISE
SPECIFIED
.XXX ± .005
.XX ± .02
.X ± .03
FRACT. ± 1/32
ANGULAR ± 1/2°

APPROVED STC	DRAWN BY ARK	DATE: 8/25/04
-----------------	-----------------	------------------

PART NO. 17567 10 C3

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Volex:](#)

[17567 10 C3](#)