


VOLEX RESERVES THE RIGHT TO ALTER NON-CRITICAL DIMENSIONS WITHOUT NOTICE.

NOTES

- 1) 23 AWG, 4 CONDUCTOR WITH 21 STRANDS OF 36AWG TINNED COPPER.
- 2) CONDUCTORS: RUBBER INSULATED
- 3) CONDUCTOR COLOR CODE: BLACK, WHITE, GREEN, AND RED.
- 4) JACKET INSULATION TO BE NEOPRENE.
- 5) CORDAGE D.D.: .250" NDM.
- 6) APPROVALS: NONE
- 7) RATING: 60°C / 300 VOLTS MAX.
- 8) PACKAGING: 50 CORDS/CARTON
- 9) ALL DIMENSIONS IN INCHES UNLESS OTHERWISE SPECIFIED.

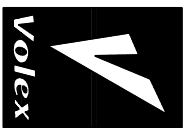

CUD

FORM IN71-07 REV.A

- ☒ Indianapolis, IN
- ☐ Conover, N.C.
- ☐ Freemont, CA
- ☐ Aguascalientes, MX
- ☐ Tijuana, Mexico
- ☐ Hermosillo, MX
- ☐ Clinton, AR
- ☐ Kanata, Canada

Proprietary Notice:

This document is the property of Volex Incorporated. The information contained herein is not to be disclosed to anyone without the express written consent of Volex Inc.

MUST BE RDHS COMPLIANT

FINISH: JACKET: SMOOTH

SCALE: NDT TO SCALE		ECD: N/A		ITEM DESCRIPTION		
TOLERANCE UNLESS OTHERWISE SPECIFIED		.XXX ± .005		RETRACTILE CORD - NORTH AMERICAN		
.XX ± .02		.X ± .03		APPROVED		
FRACT. ± 1/32°		ANGULAR ± 1/2°		STC		
PART NO.		DRAWN BY		DATE:		
7415		STC		9/6/07		

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Volex:](#)

[7415](#)