



Aluminum Flatback


- Dimensions: Inches
- Thermal Resistance based on 3 Inch Length in Natural Convection Setting

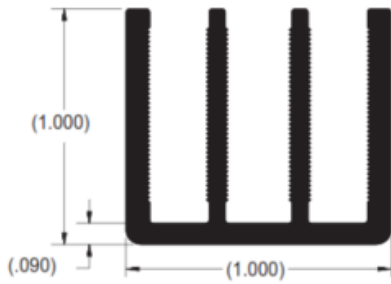


WKV Part Number	Description	Width	Height	Length	Thermal Resistance °C/w/3
127697	1.26" x 12" Flatback heatsink extrusion 14240	1	1	12	6.4
127747	1.26" x 36" Flatback heatsink extrusion 14240	1	1	36	6.4

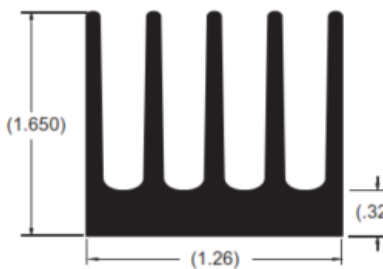


WKV Part Number	Description	Width	Height	Length	Thermal Resistance °C/w/3
127698	1.26" x 12" Flatback heatsink extrusion 10979	1.26	1.65	12	4.4
127748	1.26" x 36" Flatback heatsink extrusion 10979	1.26	1.65	36	4.4

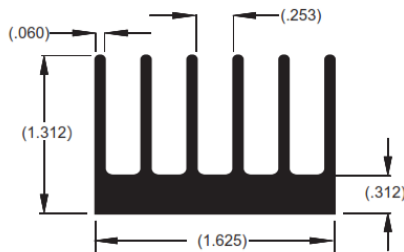

WKV Part Number	Description	Width	Height	Length	Thermal Resistance °C/w/3"
125295	1.625" Wide x 12" Flatback heatsink 16079 xx2014	1.625	1.312	12	3.2
125296	1.625" Wide x 36" Flatback heatsink 16079 xx2014	1.625	1.312	36	3.2

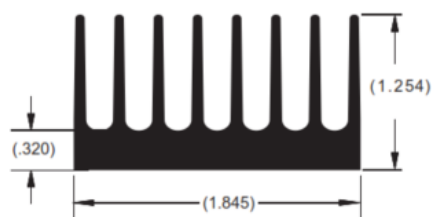


WKV Part Number	Description	Width	Height	Length	Thermal Resistance °C/w/3
127699	1.845" wide x 12" flatback heatsink xx7293 16387	1.845	1.254	12	3.4
127749	1.845" wide x 36" flatback heatsink xx7293 16387	1.845	1.254	36	3.4

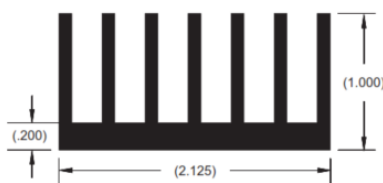


WKV Part Number	Description	Width	Height	Length	Thermal Resistance °C/w/3
127700	2.125" wide x 12" flatback heatsink 14249	2.125	1	12	4.4
127750	2.125" wide x 36" flatback heatsink 14249	2.125	1	36	4.4

Aluminum Flatback


- Dimensions: Inches
- Thermal Resistance based on 3 Inch Length in Natural Convection Setting

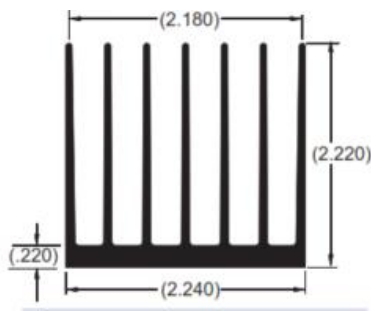


WKV Part Number	Description	Width	Height	Length	Thermal Resistance °C/w/3"
127701	2.24" wide x 12" Flatback Heatsink 13107	2.24	2.22	12	2.4
127751	2.24" wide x 36" Flatback Heatsink 13107	2.24	2.22	36	2.4

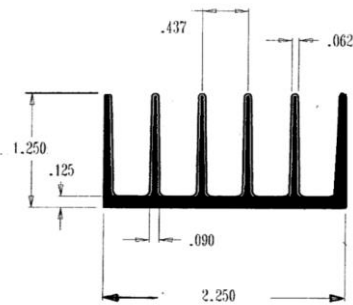


WKV Part Number	Description	Width	Height	Length	Thermal Resistance °C/w/3"
127702	2.25" wide x 12" Flatback Heatsink 6469	2.25	1.25	12	3.8
127752	2.25" wide x 36" Flatback Heatsink 6469	2.25	1.25	36	3.8

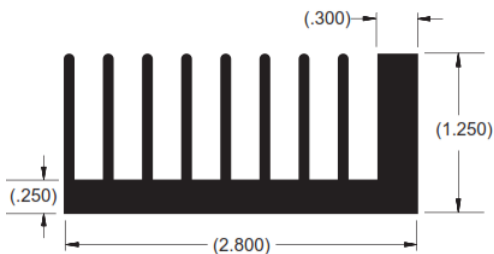

WKV Part Number	Description	Width	Height	Length	Thermal Resistance °C/w/3"
125301	2.80" Wide x 12" Flatback Heatsink 11201 XX6998	2.8	1.25	12	2.9
125302	2.80" Wide x 36" Flatback Heatsink 11201 XX6998	2.8	1.25	36	2.9

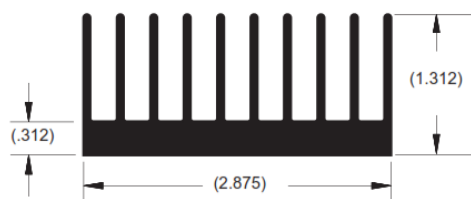


WKV Part Number	Description	Width	Height	Length	Thermal Resistance °C/w/3"
125313	2.875" Wide x 12" Flatback heatsink 16078 xx2013	2.875	1.312	12	2.3
125314	2.875" Wide x 36" Flatback heatsink 16078 xx2013	2.875	1.312	36	2.3

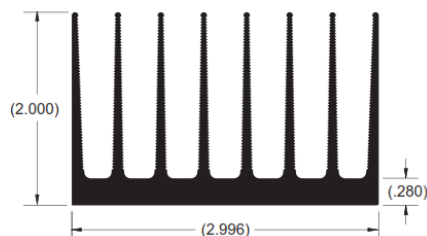


WKV Part Number	Description	Width	Height	Length	Thermal Resistance °C/w/3"
125319	3" Wide x 12" Flatback Heatsink 9099	3	2	12	1.5
125320	3" Wide x 36" Flatback Heatsink 9099	3	2	36	1.5

Aluminum Flatback


- Dimensions: Inches
- Thermal Resistance based on 3 Inch Length in Natural Convection Setting

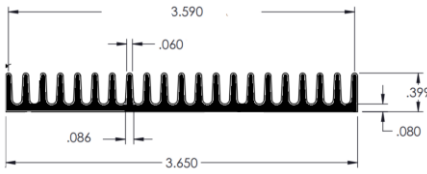


WKV Part Number	Description	Width	Height	Length	Thermal Resistance °C/w/3
127707	3.65" Wide x 12" Flatback Heatsink 13240	3.65	0.399	12	3.6
127753	3.65" Wide x 36" Flatback Heatsink 13240	3.65	0.399	36	3.6

 


WKV Part Number	Description	Width	Height	Length	Thermal Resistance °C/w/3
127708	3.66" Wide x 12" Flatback Heatsink xx2019 9797	3.66	0.774	12	2.2
127754	3.66" Wide x 36" Flatback Heatsink xx2019 9797	3.66	0.774	36	2.2

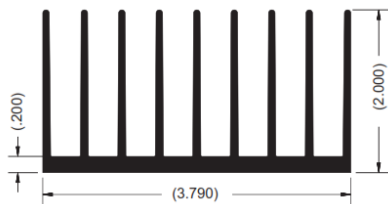


WKV Part Number	Description	Width	Height	Length	Thermal Resistance °C/w/3"
125325	3.79" Wide x 12" Flatback heatsink 16304 xx5079	3.79	2	12	1.5
125326	3.79" Wide x 36" Flatback heatsink 16304 xx5079	3.79	2	36	1.5

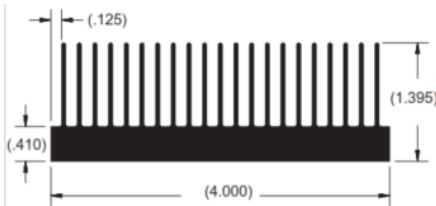

WKV Part Number	Description	Width	Height	Length	Thermal Resistance °C/w/3
127709	4.00" Wide x 12" Flatback Heatsink 16403	4	1.395	12	3.4
127755	4.00" Wide x 36" Flatback Heatsink 16403	4	1.395	36	3.4

 

WKV Part Number	Description	Width	Height	Length	Thermal Resistance °C/w/3
127710	4.00" Wide x 12" Flatback Heatsink 16573	4	0.75	12	3.7
127756	4.00" Wide x 36" Flatback Heatsink 16573	4	0.75	36	3.7

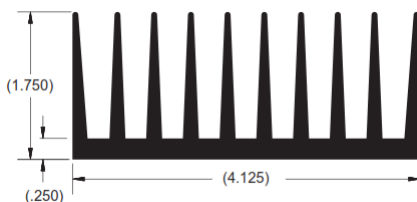


WKV Part Number	Description	Width	Height	Length	Thermal Resistance °C/w/3"
125367	4.125" x 12" Flatback Heatsink 2656 xx5138	4.125	1.75	12	1.9
125368	4.125" x 36" Flatback Heatsink 2656 xx5138	4.125	1.75	36	1.9

Aluminum Flatback


- Dimensions: Inches
- Thermal Resistance based on 3 Inch Length in Natural Convection Setting




WKV Part Number	Description	Width	Height	Length	Thermal Resistance °C/w/3"
125373	4.375" Wide x 12" Flatback heatsink 16296 xx1527	4.375	1.29	12	1.4
125374	4.375" Wide x 36" Flatback heatsink 16296 xx1527	4.375	1.29	36	1.4

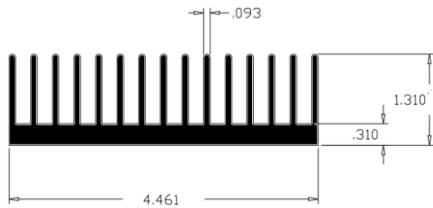


WKV Part Number	Description	Width	Height	Length	Thermal Resistance °C/w/3"
127711	4.461" Wide x 12" Flatback Heatsink 16365	4.461	1.31	12	1.8
127757	4.461" Wide x 36" Flatback Heatsink 16365	4.461	1.31	36	1.8

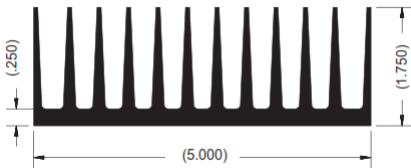


WKV Part Number	Description	Width	Height	Length	Thermal Resistance °C/w/3"
125397	5.00" Wide x 12" Flatback Heatsink 16338 xx2065	5	1.75	12	1.6
125398	5.00" Wide x 36" Flatback Heatsink 16338 xx2065	5	1.75	36	1.6

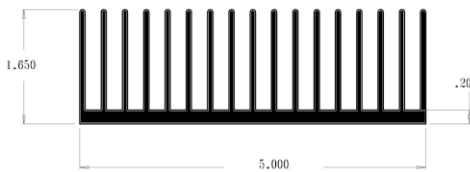

WKV Part Number	Description	Width	Height	Length	Thermal Resistance °C/w/3"
127712	5.00" Wide x 12" Flatback Heatsink 16107	5	1.65	12	1.1
127758	5.00" Wide x 36" Flatback Heatsink 16107	5	1.65	36	1.1

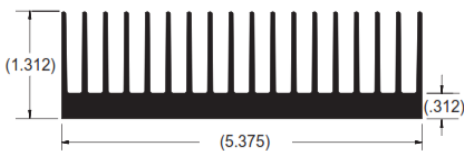

WKV Part Number	Description	Width	Height	Length	Thermal Resistance °C/w/3"
125403	5.375" x 12" Flatback Heatsink 6037 xx5045	5.375	1.312	12	1.8
125404	5.375" x 36" Flatback Heatsink 6037 xx5045	5.375	1.312	36	1.8

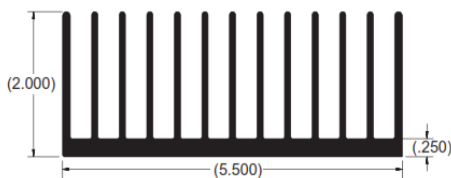


WKV Part Number	Description	Width	Height	Length	Thermal Resistance °C/w/3"
125409	5.50" x 12" Flatback Heatsink 13760 xx2199	5.5	2	12	1.2
125410	5.50" x 36" Flatback Heatsink 13760 xx2199	5.5	2	36	1.2

Aluminum Flatback


- Dimensions: Inches
- Thermal Resistance based on 3 Inch Length in Natural Convection Setting




WKV Part Number	Description	Width	Height	Length	Thermal Resistance °C/w/3
127713	5.53" x 12" Flatback Heatsink 19810	5.53	0.325	12	2.82
127759	5.53" x 36" Flatback Heatsink 19810	5.53	0.325	36	2.82

 


WKV Part Number	Description	Width	Height	Length	Thermal Resistance °C/w/3
127714	5.748" Wide x 12" Flatback Heatsink xx8867 19155	5.748	0.905	12	1.57
127760	5.748" Wide x 12" Flatback Heatsink xx8867 19155	5.748	0.905	36	1.57

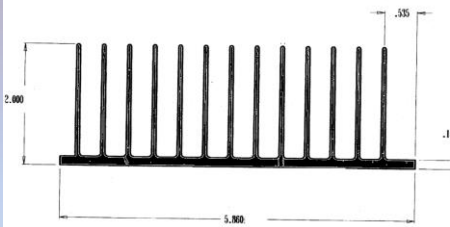


WKV Part Number	Description	Width	Height	Length	Thermal Resistance °C/w/3
127715	5.86" x 12" Flatback Heatsink 14461	5.86	2	12	1.1
127761	5.86" x 36" Flatback Heatsink 14461	5.86	2	36	1.1

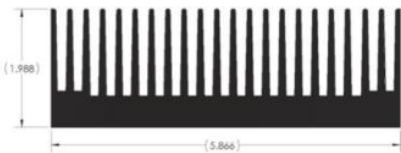

WKV Part Number	Description	Width	Height	Length	Thermal Resistance °C/w/3
127716	5.86" x 12" Flatback Heatsink 19343	5.86	1.988	12	0.94
127762	5.86" x 36" Flatback Heatsink 19343	5.86	1.988	36	0.94

 


WKV Part Number	Description	Width	Height	Length	Thermal Resistance °C/w/3
127717	6.00" Wide x 12" Flatback Heatsink 12054	6	0.124	12	2.8
127763	6.00" Wide x 36" Flatback Heatsink 12054	6	0.124	36	2.8

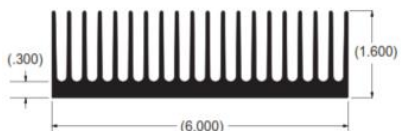


WKV Part Number	Description	Width	Height	Length	Thermal Resistance °C/w/3
127718	6.00" Wide x 12" Flatback Heatsink 13796	6	1.6	12	1.1
127764	6.00" Wide x 36" Flatback Heatsink 17396	6	1.6	36	1.1

Aluminum Flatback

 
- Dimensions: Inches
- Thermal Resistance based on 3 Inch Length in Natural Convection Setting




WKV Part Number	Description	Width	Height	Length	Thermal Resistance °C/w/3
127719	6.39" Wide x 12" Flatback Heatsink 21848	6.39	0.875	12	1.75
127765	6.39" Wide x 36" Flatback Heatsink 21848	6.39	0.875	36	1.75

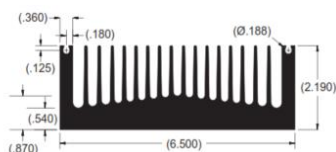


WKV Part Number	Description	Width	Height	Length	Thermal Resistance °C/w/3
127720	6.50" x 12" Flatback Heatsink 16222	6.5	2.19	12	1.4
127766	6.50" x 36" Flatback Heatsink 16222	6.5	2.19	36	1.4

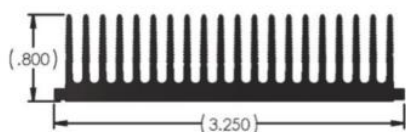

WKV Part Number	Description	Width	Height	Length	Thermal Resistance °C/w/3
127721	6.50" x 12" Flatback Heatsink xx8403 16499	6.5	0.8	12	2.15
127767	6.50" x 36" Flatback Heatsink xx8403 16499	6.5	0.8	36	2.15

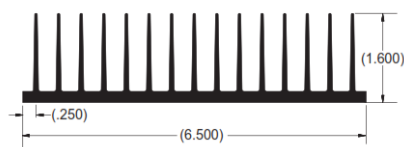


WKV Part Number	Description	Width	Height	Length	Thermal Resistance °C/w/3"
125415	6.50" x 12" Flatback Heatsink 6664 xx4509	6.5	1.6	12	1.3
125416	6.50" x 36" Flatback Heatsink 6664 xx4509	6.5	1.6	36	1.3

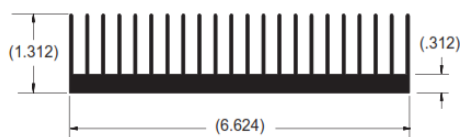

WKV Part Number	Description	Width	Height	Length	Thermal Resistance °C/w/3"
125421	6.624" Wide x 12" Flatback heatsink 16524 xx7031	6.624	1.312	12	1.3
125422	6.624" Wide x 36" Flatback heatsink 16524 xx7031	6.624	1.312	36	1.3

Aluminum Flatback

 
- Dimensions: Inches
- Thermal Resistance based on 3 Inch Length in Natural Convection Setting




WKV Part Number	Description	Width	Height	Length	Thermal Resistance °C/w/3
127722	6.75" Wide x 12" Flatback Heatsink 4955	6.75	1.185	12	1.37
127768	6.75" Wide x 36" Flatback Heatsink 4955	6.75	1.185	36	1.37




WKV Part Number	Description	Width	Height	Length	Thermal Resistance °C/w/3
127723	6.75" Wide x 12" Flatback Heatsink xx7029 12116	6.75	1.63	12	1.3
127771	6.75" Wide x 36" Flatback Heatsink xx7029 12116	6.75	1.63	36	1.3

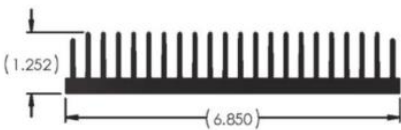


WKV Part Number	Description	Width	Height	Length	Thermal Resistance °C/w/3
127724	6.85" Wide x 12" Flatback Heatsink 16335	6.85	1.252	12	1.31
127772	6.85" Wide x 36" Flatback Heatsink 16355	6.85	1.252	36	1.31

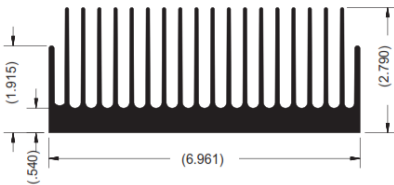

WKV Part Number	Description	Width	Height	Length	Thermal Resistance °C/w/3"
122255	6.961" Wide x 12" Flatback Heatsink 13694 xx6274	6.961	2.79	12	0.8
125643	6.961" Wide x 36" Flatback Heatsink 13694 xx6274	6.961	2.79	36	0.8

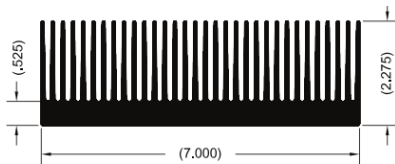


WKV Part Number	Description	Width	Height	Length	Thermal Resistance °C/w/3"
122256	7.00" Wide x 12" Flatback heatsink 15837	7	2.275	12	0.3
125645	7.00" Wide x 36" Flatback heatsink 15837	7	2.275	36	0.3

 


WKV Part Number	Description	Width	Height	Length	Thermal Resistance °C/w/3
127725	7.00" Wide x 12" Flatback heatsink 19493	7	0.36	12	2.69
127773	7.00" Wide x 36" Flatback heatsink 19493	7	0.36	36	2.69

Aluminum Flatback


- Dimensions: Inches
- Thermal Resistance based on 3 Inch Length in Natural Convection Setting

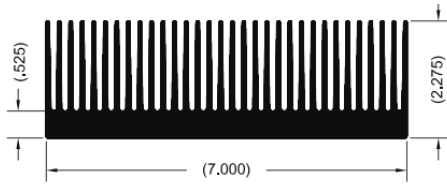

WKV Part Number	Description	Width	Height	Length	Thermal Resistance °C/w/3"
122256	7.00" Wide x 12" Flatback heatsink 15837	7	2.275	12	0.3
125645	7.00" Wide x 36" Flatback heatsink 15837	7	2.275	36	0.3

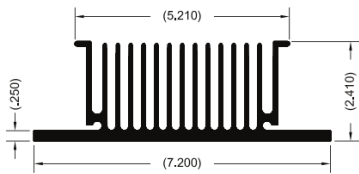


WKV Part Number	Description	Width	Height	Length	Thermal Resistance °C/w/3"
125512	7.20" Wide x 36" Flatback heatsink 16316 xx6438-2	7.2	2.41	36	0.9

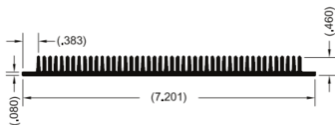


WKV Part Number	Description	Width	Height	Length	Thermal Resistance °C/w/3"
127726	7.201" Wide x 12" Flatback heatsink 12414	7.201	0.46	12	1.5
127774	7.201" wide x 36" Flatback heatsink 12414	7.201	0.46	36	1.5



WKV Part Number	Description	Width	Height	Length	Thermal Resistance °C/w/3"
127727	7.34" Wide x 12" Flatback Heatsink xx5523 14433	7.34	0.875	12	1.8
127775	7.34" Wide x 36" Flatback Heatsink xx5523 14433	7.34	0.875	36	1.8

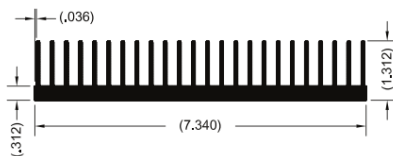

WKV Part Number	Description	Width	Height	Length	Thermal Resistance °C/w/3"
125430	7.343" Wide x 12" Flatback Heatsink 13454 xx4771	7.343	1.312	12	1.1
125431	7.343" Wide x 36" Flatback Heatsink 13454 xx4771	7.343	1.312	36	1.1

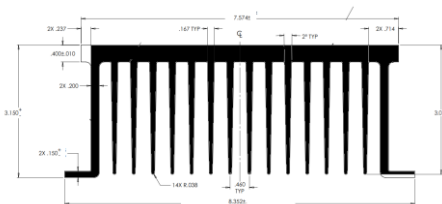


WKV Part Number	Description	Width	Height	Length	Thermal Resistance °C/w/3"
125601	7.574" Wide x 12" Flatback Heatsink 21910	7.574	3.15	12	0.65
125602	7.574" Wide x 36" Flatback Heatsink 21910	7.574	3.15	36	0.65

Aluminum Flatback


- Dimensions: Inches
- Thermal Resistance based on 3 Inch Length in Natural Convection Setting




WKV Part Number	Description	Width	Height	Length	Thermal Resistance °C/w/3"
127728	7.875" Wide x 12" Flatback Heatsink xx2009 16639	7.875	1.31	12	1.2
127776	7.875" Wide x 12" Flatback Heatsink xx2009 16639	7.875	1.31	36	1.2

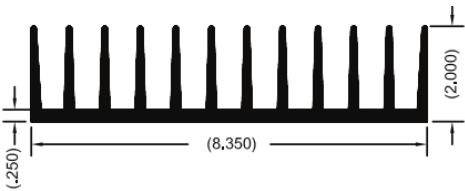


WKV Part Number	Description	Width	Height	Length	Thermal Resistance °C/w/3"
125436	8.35" Wide x 12" Flatback Heatsink 13668 xx4937	8.35	2	12	0.9
125437	8.35" Wide x 36" Flatback Heatsink 13668 xx4937	8.35	2	36	0.9

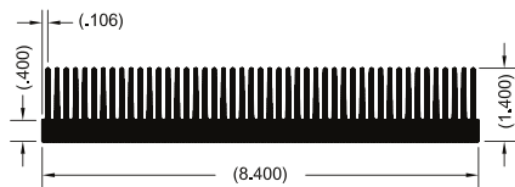


WKV Part Number	Description	Width	Height	Length	Thermal Resistance °C/w/3"
122263	8.40" Wide x 12" Flatback heatsink 16681	8.4	1.4	12	0.65
125657	8.40" Wide x 36" Flatback heatsink 16681	8.4	1.4	36	0.65

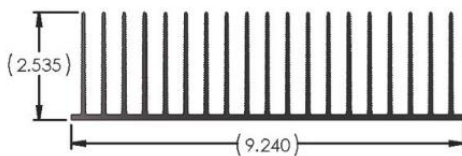

WKV Part Number	Description	Width	Height	Length	Thermal Resistance °C/w/3"
122260	9.24" Wide x 12" Flatback Heatsink 19035	9.24	2.535	12	0.62
125651	9.24" Wide x 36" Flatback Heatsink 19035	9.24	2.535	36	0.62

 


WKV Part Number	Description	Width	Height	Length	Thermal Resistance °C/w/3"
127684	9.333" Wide x 12" Flatback Heatsink 16386	9.333	0.905	12	1.04
127777	9.333" Wide x 12" Flatback Heatsink 16386	9.333	0.905	36	1.04

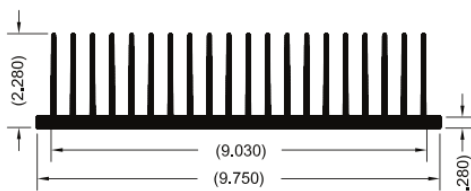


WKV Part Number	Description	Width	Height	Length	Thermal Resistance °C/w/3"
125520	9.75" Wide x 12" Flatback heatsink 16473 xx5384	9.75	2.28	12	0.75
125521	9.75" Wide x 36" Flatback heatsink 16473 xx5384	9.75	2.28	36	0.75

Aluminum Flatback


- Dimensions: Inches
- Thermal Resistance based on 3 Inch Length in Natural Convection Setting

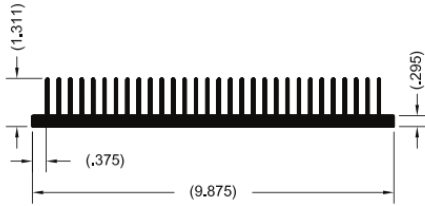


WKV Part Number	Description	Width	Height	Length	Thermal Resistance °C/w/3"
125442	9.875" Wide x 12" Flatback heatsink 16329 xx1703	9.875	1.31	12	0.91
125443	9.875" Wide x 36" Flatback heatsink 16329 xx1703	9.875	1.31	36	0.91

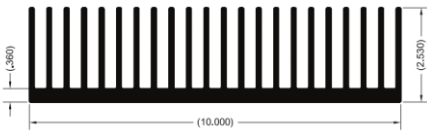


WKV Part Number	Description	Width	Height	Length	Thermal Resistance °C/w/3"
125592	10" Wide x 12" Flatback heatsink 13953 sf1002	10	2.53	12	0.6

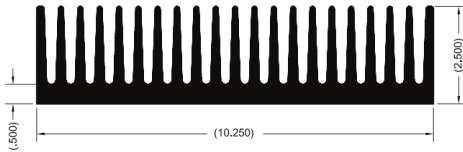


WKV Part Number	Description	Width	Height	Length	Thermal Resistance °C/w/3"
125448	10.25" Wide x 12" Flatback heatsink 14236 xx5772	10.25	2.5	12	0.71
125449	10.25" Wide x 36" Flatback heatsink 14236 xx5772	10.25	2.5	36	0.71

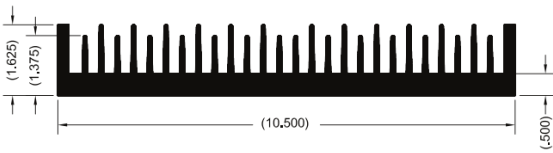

WKV Part Number	Description	Width	Height	Length	Thermal Resistance °C/w/3"
125454	10.50" Wide x 12" Flatback Heatsink 16990 xx2904	10.5	1.265	12	1.3
125455	10.50" Wide x 36" Flatback Heatsink 16990 xx2904	10.5	1.265	36	1.3

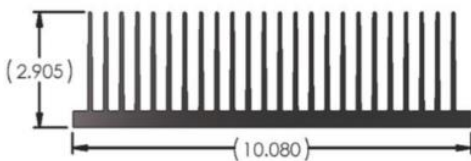

WKV Part Number	Description	Width	Height	Length	Thermal Resistance °C/w/3"
127685	10.08" Wide x 12" Flatback heatsink 21052	10.08	2.905	12	0.51
127778	10.08" Wide x 36" Flatback heatsink 21052	10.08	2.905	36	0.51

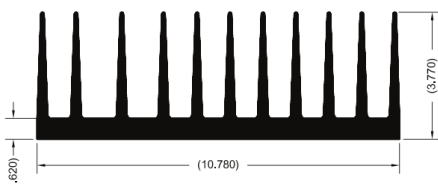


WKV Part Number	Description	Width	Height	Length	Thermal Resistance °C/w/3"
125460	10.78" Wide x 12" Flatback Heatsink xx4559	10.78	3.77	12	0.5
125461	10.78" Wide x 36" Flatback Heatsink xx4559	10.78	3.77	36	0.5

Aluminum Flatback


- Dimensions: Inches
- Thermal Resistance based on 3 Inch Length in Natural Convection Setting




WKV Part Number	Description	Width	Height	Length	Thermal Resistance °C/w/3"
125577	10.827" Wide x 12" Flatback Heatsink 19572	10.827	1.221	12	0.83
125578	10.827" Wide x 36" Flatback Heatsink 19572	10.827	1.221	36	0.83

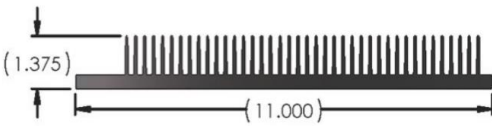


WKV Part Number	Description	Width	Height	Length	Thermal Resistance °C/w/3"
122261	11.00" Wide x 12" Flatback Heatsink 19584	11	1.375	12	1.43
125653	11.00" Wide x 36" Flatback Heatsink 19584	11	1.375	36	1.43

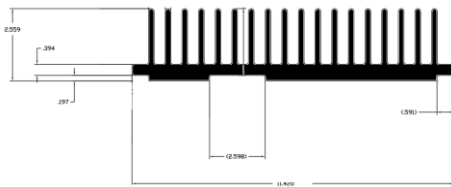


WKV Part Number	Description	Width	Height	Length	Thermal Resistance °C/w/3"
127686	11.420" Wide x 12" Flatback Heatsink xx10178	11.42	2.559	12	0.76
127779	11.578" Wide x 36" Flatback Heatsink xx10178	11.42	2.559	36	0.76

 

WKV Part Number	Description	Width	Height	Length	Thermal Resistance °C/w/3"
127687	11.578" Wide x 12" Flatback Heatsink xx82266	11.578	1.32	12	0.83
127780	11.578" Wide x 36" Flatback Heatsink xx82266	11.578	1.32	36	0.83

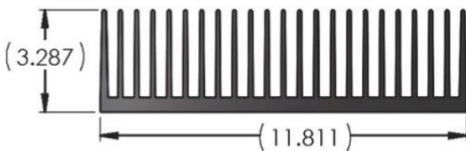


WKV Part Number	Description	Width	Height	Length	Thermal Resistance °C/w/3"
125625	11.811" Wide x 12" Flatback Heatsink 19740	11.811	3.287	12	0.46
125626	11.811" Wide x 36" Flatback Heatsink 19740	11.811	3.287	36	0.46

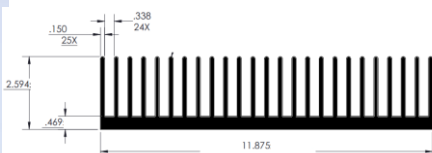


WKV Part Number	Description	Width	Height	Length	Thermal Resistance °C/w/3"
125619	11.875" Wide x 12" Flatback Heatsink 17099	11.875	2.594	12	0.4
125620	11.875" Wide x 36" Flatback Heatsink 17099	11.875	2.594	36	0.4

Aluminum Flatback

 
- Dimensions: Inches
- Thermal Resistance based on 3 Inch Length in Natural Convection Setting




WKV Part Number	Description	Width	Height	Length	Thermal Resistance °C/w/3"
127688	12.203" Wide x 12" Flatback Heatsink 16632	12.203	2.87	12	0.7
127781	12.203" Wide x 36" Flatback Heatsink 16632	12.203	2.87	36	0.7

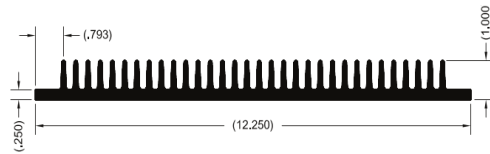

WKV Part Number	Description	Width	Height	Length	Thermal Resistance °C/w/3"
122262	12.25" Wide x 12" Flatback Heatsink 19152 xx4471	12.25	1	12	1.3
125655	12.25" Wide x 36" Flatback Heatsink 19152 xx4471	12.25	1	36	1.3

 


WKV Part Number	Description	Width	Height	Length	Thermal Resistance °C/w/3"
125631	12.75" Wide x 12" Flatback Heatsink xx2170	12.75	1.35	12	0.6
125632	12.75" Wide x 36" Flatback Heatsink xx2170	12.75	1.35	36	0.6

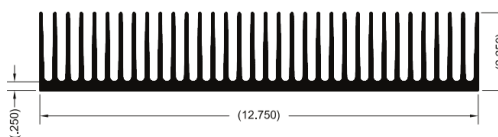

WKV Part Number	Description	Width	Height	Length	Thermal Resistance °C/w/3"
125469	12.75" Wide x 12" Flatback Heatsink xx2044	12.75	2.25	12	0.56
125470	12.75" Wide x 36" Flatback Heatsink xx2044	12.75	2.25	36	0.56




WKV Part Number	Description	Width	Height	Length	Thermal Resistance °C/w/3"
125475	13.381" Wide x 12" Flatback Heatsink xx5429	13.381	1.312	12	0.65
125476	13.381" Wide x 36" Flatback Heatsink xx5429	13.381	1.312	36	0.65

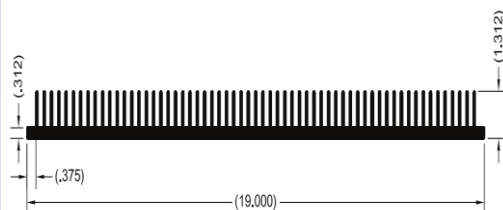


WKV Part Number	Description	Width	Height	Length	Thermal Resistance °C/w/3"
125481	19.00" Wide x 36" Flatback Heatsink xx2016	19	1.32	12	0.65
125482	19.00" Wide x 36" Flatback Heatsink xx2016	19	1.32	36	0.65

High Aspect


- Dimensions: Inches
- Thermal Resistance based on 3 Inch Length in Natural Convection Setting

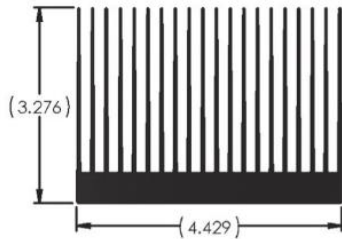


WKV Part Number	Description	Width	Height	Length	Thermal Resistance °C/w/3"
125562	4.429" Wide x 11.81" High Aspect Heatsink 17080-11.81	4.429	3.276	11.81	0.59

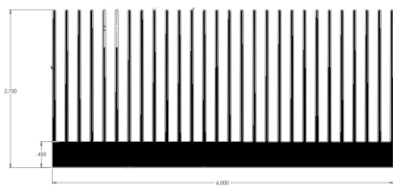


WKV Part Number	Description	Width	Height	Length	Thermal Resistance °C/w/3"
127691	6.00" Wide x 12" Long High Aspect Heatsink 19767	6	2.75	12	0.49
127786	6.00" Wide x 36" Long High Aspect Heatsink 19767	6	2.75	36	0.49

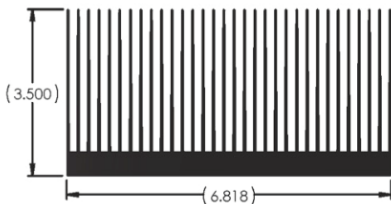


WKV Part Number	Description	Width	Height	Length	Thermal Resistance °C/w/3"
125565	6.818" Wide x 11.81" High Aspect Heatsink 19333-12	4.429	3.5	12	0.34

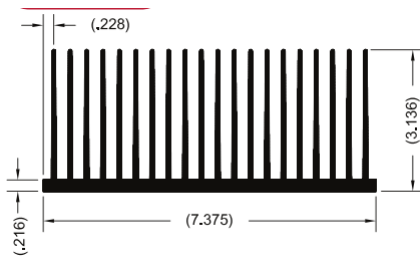

WKV Part Number	Description	Width	Height	Length	Thermal Resistance °C/w/3"
122258	7.375" Wide x 12" High Aspect Extrusion 15817 xx5113	7.375	3.136	12	0.68
125649	7.375" Wide x 36" High Aspect Extrusion 15817 xx5113	7.375	3.136	36	0.68

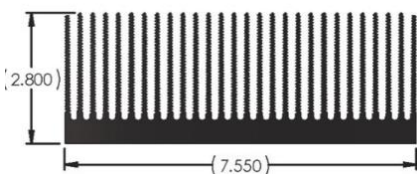


WKV Part Number	Description	Width	Height	Length	Thermal Resistance °C/w/3"
122264	7.55" Wide x 12" High Aspect Extrusion 19832	7.55	2.8	12	0.34
125659	7.55" Wide x 36" High Aspect Extrusion 19832	7.55	2.8	36	0.34

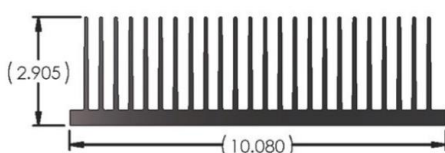


WKV Part Number	Description	Width	Height	Length	Thermal Resistance °C/w/3"
125571	10.08" Wide x 12" High Aspect Extrusion 21052	10.08	2.905	12	0.51
125572	10.08" Wide x 36" High Aspect Extrusion 21052	10.08	2.905	36	0.51

SCR Press Pack Extrusions


- Dimensions: Inches
- Thermal Resistance based on 3 Inch Length in Natural Convection Setting

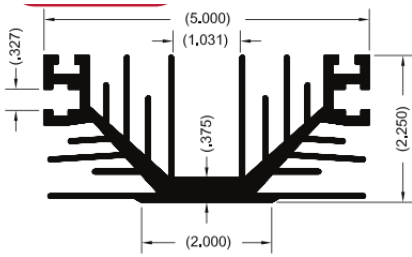


WKV Part Number	Description	Width	Height	Length	Thermal Resistance °C/w/3"
125526	5.00" Wide x 12" Presspack SCR Extrusion 16082 xx3560-2	5	2.25	12	1.4
125527	5.00" Wide x 36" Presspack SCR Extrusion 16082 xx3560-2	5	2.25	36	1.4

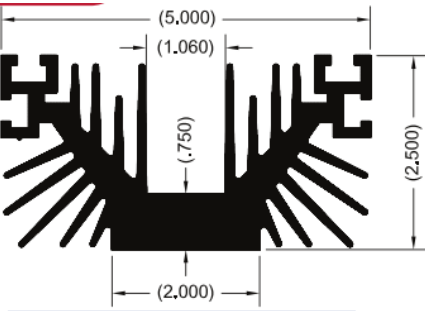


WKV Part Number	Description	Width	Height	Length	Thermal Resistance °C/w/3"
125532	5.00" Wide x 12" Presspack SCR Extrusion 16565 xx5732	5	2.5	12	1.39
125533	5.00" Wide x 12" Presspack SCR Extrusion 16565 xx5732	5	2.5	36	1.39

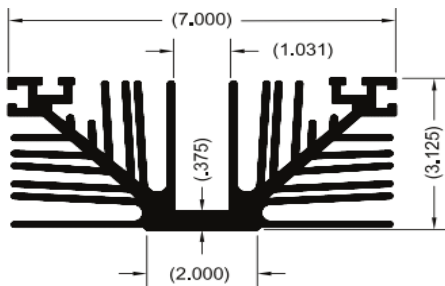

WKV Part Number	Description	Width	Height	Length	Thermal Resistance °C/w/3"
125538	7.00" Wide x 12" Presspack SCR Extrusion 16348 xx3559-2	7	3.125	12	0.85
125539	7.00" Wide x 36" Presspack SCR Extrusion 16348 xx3559-2	7	3.125	36	0.85

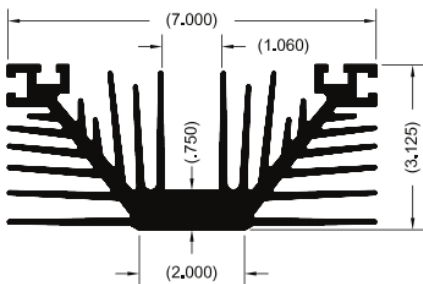


WKV Part Number	Description	Width	Height	Length	Thermal Resistance °C/w/3"
125544	7.00" Wide x 12" Presspack SCR Extrusion 16235 xx5733	7	3.125	12	0.88
125545	7.00" Wide x 36" Presspack SCR Extrusion 16235 xx5733	7	3.125	36	0.88

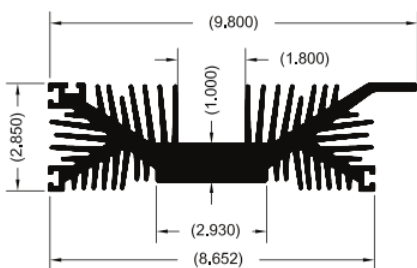


WKV Part Number	Description	Width	Height	Length	Thermal Resistance °C/w/3"
125550	9.80" Wide x 12" Presspack SCR Extrusion xx5735	9.8	2.85	12	0.71
125551	9.80" Wide x 36" Presspack SCR Extrusion xx5735	9.8	2.85	36	0.71

Power Modules


- Dimensions: Inches
- Thermal Resistance based on 3 Inch Length in Natural Convection Setting

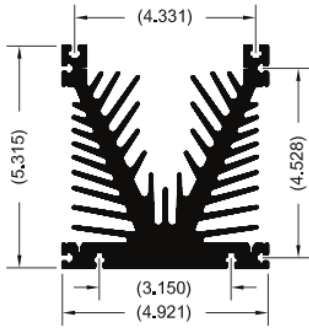


WKV Part Number	Description	Width	Height	Length	Thermal Resistance °C/w/3"
125556	4.921" Wide x 12" Power Module Extrusion 13698 xx5658	4.921	4.528	12	0.8
125557	4.921" Wide x 36" Power Module Extrusion 13698 xx5658	4.921	4.528	36	0.8

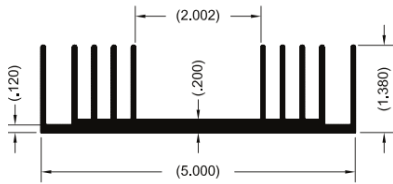


WKV Part Number	Description	Width	Height	Length	Thermal Resistance °C/w/3"
125391	5.00" Wide x 12" Power Module Extrusion 19589 xx7331	5	1.38	12	3
125392	5.00" Wide x 36" Power Module Extrusion 19589 xx7331	5	1.38	36	3

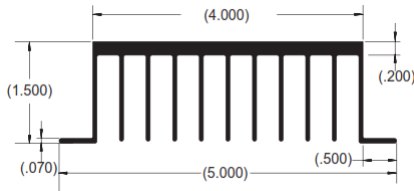

WKV Part Number	Description	Width	Height	Length	Thermal Resistance °C/w/3"
125379	5.00" Wide x 12" Power Module Extrusion 16414 xx7332	5	1.5	12	2.5
125380	5.00" Wide x 36" Power Module Extrusion 16414 xx7332	5	1.5	36	2.5

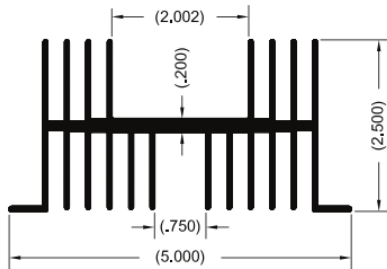


WKV Part Number	Description	Width	Height	Length	Thermal Resistance °C/w/3"
125385	5.00" Wide x 12" Power Module Extrusion 16936 xx7330	5	2.5	12	1.7
125386	5.00" Wide x 36" Power Module Extrusion 16936 xx7330	5	2.5	36	1.7

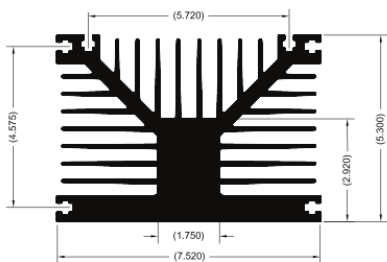


WKV Part Number	Description	Width	Height	Length	Thermal Resistance °C/w/3"
125613	7.52" Wide x 12" Power Module Extrusion 17003	7.52	5.3	12	0.65
125614	7.52" Wide x 36" Power Module Extrusion 17003	7.52	5.3	36	0.65

DC/DC Heat Sink


- Dimensions: Inches
- Thermal Resistance based on 3 Inch Length in Natural Convection Setting

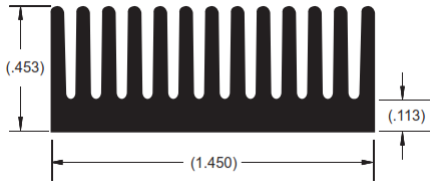


WKV Part Number	Description	Width	Height	Length	Thermal Resistance °C/w/3"
125361	1.45" Wide x 36" DC/DC Heatsink Extrusion 14363	1.45	0.768	12	4.2
125362	1.45" Wide x 36" DC/DC Heatsink Extrusion 14363	1.45	0.768	36	4.2

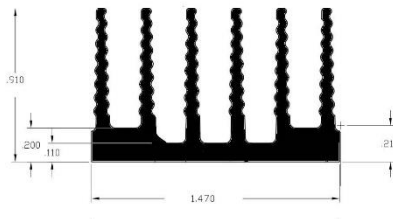


WKV Part Number	Description	Width	Height	Length	Thermal Resistance °C/w/3"
127694	1.47" Wide x 12" DC/DC Heatsink Extrusion 14193	1.47	0.91	12	5.4
127744	1.47" Wide x 36" DC/DC Heatsink Extrusion 14913	1.47	0.91	36	5.4

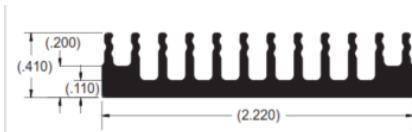

WKV Part Number	Description	Width	Height	Length	Thermal Resistance °C/w/3"
127695	2.22" Wide x 12" DC/DC Heatsink Extrusion 14722	2.22	0.41	12	7
127745	2.22" Wide x 36" DC/DC Heatsink Extrusion 14722	2.222	0.41	36	7

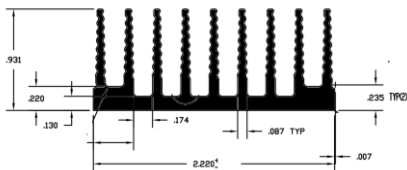


WKV Part Number	Description	Width	Height	Length	Thermal Resistance °C/w/3"
125343	2.22" Wide x 12" DC/DC Heatsink Extrusion 14192	2.22	2.53	12	0.6
125344	2.22" Wide x 36" DC/DC Heatsink Extrusion 14192	2.22	2.53	36	0.6

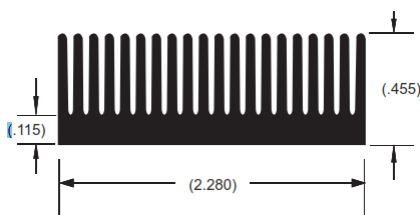


WKV Part Number	Description	Width	Height	Length	Thermal Resistance °C/w/3"
125355	2.28" Wide x 36" DC/DC Heatsink Extrusion 14362	2.28	0.455	12	4
125356	2.28" Wide x 12" DC/DC Heatsink Extrusion 14362	2.28	0.455	36	4

DC/DC Heat Sink


- Dimensions: Inches
- Thermal Resistance based on 3 Inch Length in Natural Convection Setting

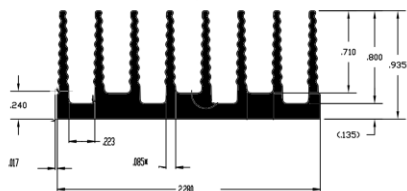


WKV Part Number	Description	Width	Height	Length	Thermal Resistance °C/w/3"
125349	2.28" Wide x 12" DC/DC Heatsink Extrusion 14228	2.28	9.35	12	0.28
125350	2.28" Wide x 36" DC/DC Heatsink Extrusion 14228	2.28	9.35	36	0.28

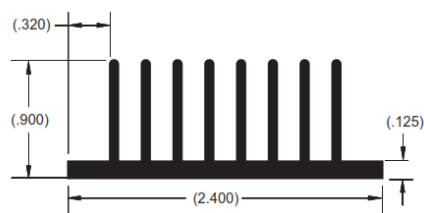

WKV Part Number	Description	Width	Height	Length	Thermal Resistance °C/w/3"
125331	2.40" Wide x 12" DC/DC Heatsink Extrusion 12613	2.4	0.9	12	4.1
125332	2.40" Wide x 36" DC/DC Heatsink Extrusion 12613	2.4	0.9	36	4.1

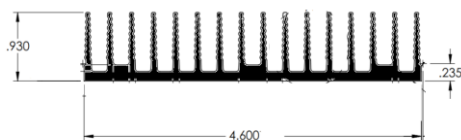


WKV Part Number	Description	Width	Height	Length	Thermal Resistance °C/w/3"
127696	4.60" Wide x 12" DC/DC Heatsink Extrusion 14229	4.6	0.93	12	1.9
127746	4.60" Wide x 36" DC/DC Heatsink Extrusion 14229	4.6	0.93	36	1.9

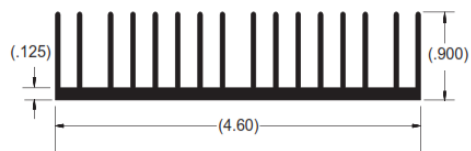


WKV Part Number	Description	Width	Height	Length	Thermal Resistance °C/w/3"
125337	4.60" Wide x 12" DC/DC Heatsink Extrusion 12614	4.6	0.9	12	2.1
125338	4.60" Wide x 36" DC/DC Heatsink Extrusion 12614	4.6	0.9	36	2.1

H & T Style/Mounting Shelf Heat Sinks


- Dimensions: Inches
- Thermal Resistance based on 3 Inch Length in Natural Convection Setting

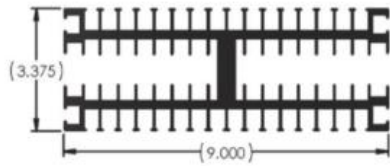


WKV Part Number	Description	Width	Height	Length	Thermal Resistance °C/w/3
127689	3.375" x 12" H Style Heatsink 17086	3.75	9	12	0.59
127782	3.375" x 36" H Style Heatsink 17086	3.75	9	36	0.59

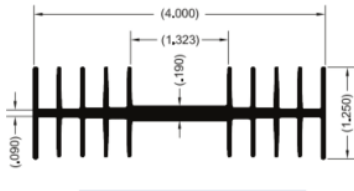


WKV Part Number	Description	Width	Height	Length	Thermal Resistance °C/w/3
127690	4.000" x 12" H Style Heatsink xx4101 16299	4	1.25	12	2.3
127783	4.000" x 36" H Style Heatsink xx4101 16299	4	1.25	36	2.3

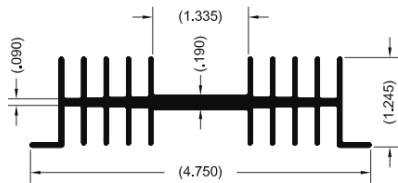

WKV Part Number	Description	Width	Height	Length	Thermal Resistance °C/w/3"
125487	4.75" x 12" H Style Heatsink 4530 xx1024	4.75	1.245	12	2
125488	4.75" x 36" H Style Heatsink 4530 XX1024	4.75	1.245	36	2

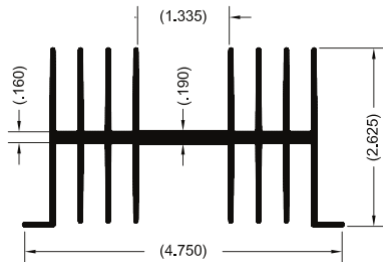


WKV Part Number	Description	Width	Height	Length	Thermal Resistance °C/w/3"
125493	4.75" x 12" H Style Heatsink 5410 xx1025	4.75	2.625	12	1.3
125494	4.75" x 36" H Style Heatsink 5410 xx1025	4.75	2.625	36	1.3

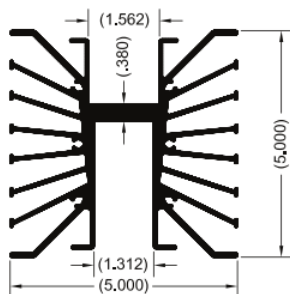


WKV Part Number	Description	Width	Height	Length	Thermal Resistance °C/w/3"
125499	5.00" x 12" H Style Heatsink 6542 xx1245	5	5	12	0.72
125500	5.00" x 36" H Style Heatsink 6542 xx1245	5	5	36	0.72

H & T Style/Mounting Shelf Heat Sinks


- Dimensions: Inches
- Thermal Resistance based on 3 Inch Length in Natural Convection Setting

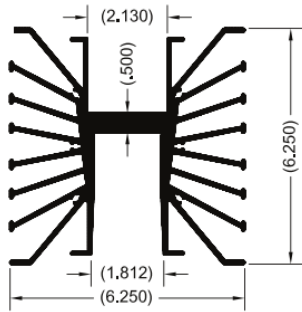

WKV Part Number	Description	Width	Height	Length	Thermal Resistance °C/w/3"
125505	6.25" Wide x 12" H Style Heatsink 16971 xx1541	6.25	6.25	12	0.59
125506	6.25" Wide x 36" H Style Heatsink 16971 xx1541	6.25	6.25	36	0.59

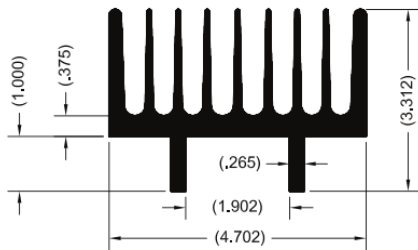


WKV Part Number	Description	Width	Height	Length	Thermal Resistance °C/w/3"
125637	4.702" Wide x 12" Mounting Shelf Extrusion 14264	4.702	3.312	12	1.8
125638	4.702" Wide x 12" Mounting Shelf Extrusion 14264	4.702	3.312	36	1.8

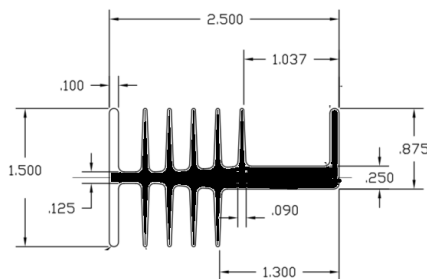


WKV Part Number	Description	Width	Height	Length	Thermal Resistance °C/w/3"
127741	2.5" Wide x 12" T Style Extrusion 19342	2.5	1.5	12	3.49
127799	2.5" Wide x 12" T Style Extrusion 19342	2.5	1.5	36	3.49

BGA Style Heat Sinks


- Dimensions: Inches
- Thermal Resistance based on 3 Inch Length in Natural Convection Setting

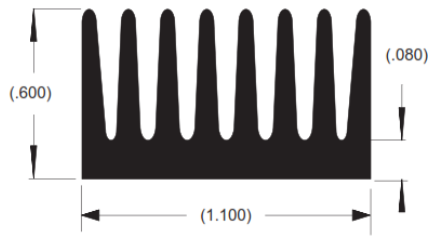


WKV Part Number	Description	Width	Height	Length	Thermal Resistance °C/w/3"
125283	1.10" Wide x 12" BGA Heatsink Extrusion 16240 xx8052-65	1.1	0.65	12	8
125284	1.10" Wide x 36" BGA Heatsink Extrusion 16240 xx8052-65	1.1	0.65	36	8

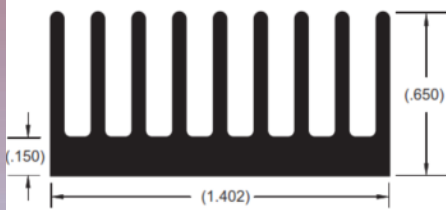


WKV Part Number	Description	Width	Height	Length	Thermal Resistance °C/w/3"
127692	1.40" Wide x 12" BGA Heatsink Extrusion 11381	1.4	0.65	12	6.2
127742	1.40" Wide x 36" BGA Heatsink Extrusion 11381	1.4	0.65	36	6.2

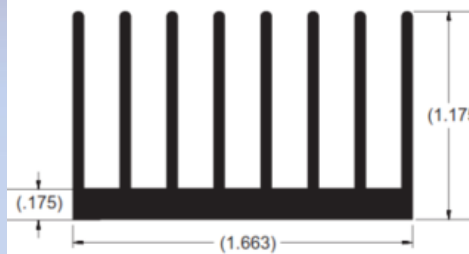

WKV Part Number	Description	Width	Height	Length	Thermal Resistance °C/w/3"
127693	1.66" Wide x 12" BGA Heatsink Extrusion 12704	1.66	1.175	12	3.6
127743	1.66" Wide x 36" BGA Heatsink Extrusion 12704	1.66	1.175	36	3.6

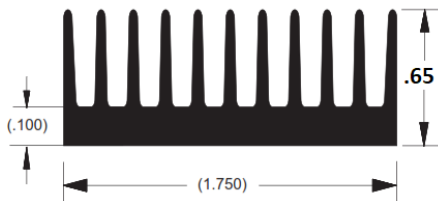


WKV Part Number	Description	Width	Height	Length	Thermal Resistance °C/w/3"
125289	1.75" Wide x 12" BGA Heatsink Extrusion 16249 XX8260-65	1.75	0.65	12	7.8
125290	1.75" Wide x 36" BGA Heatsink Extrusion 16249 XX8260-65	1.75	0.65	36	7.8

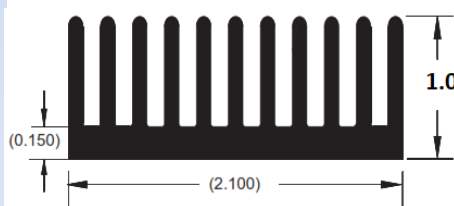


WKV Part Number	Description	Width	Height	Length	Thermal Resistance °C/w/3"
125307	2.10" Wide x 12" BGA Heatsink Extrusion 12554 xx8355-100	2.1	1	12	3.8
125308	2.10" Wide x 36" BGA Heatsink Extrusion 12554 xx8355-100	2.1	1	36	3.8

Center/Multi Channel Heat Sinks


- Dimensions: Inches
- Thermal Resistance based on 3 Inch Length in Natural Convection Setting

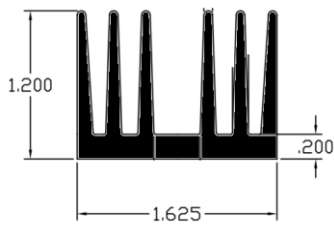


WKV Part Number	Description	Width	Height	Length	Thermal Resistance °C/w/3
127729	1.625" Wide x 12" Center Channel xx6863 19604	1.625	1.2	12	4.64
127787	1.625" Wide x 36" Center Channel xx6863 19604	1.625	1.2	36	4.64

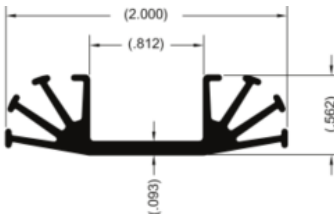


WKV Part Number	Description	Width	Height	Length	Thermal Resistance °C/w/3
127730	2.00" Wide x 12" Center Channel xx1284 6540	2	0.562	12	6.5
127788	2.00" Wide x 36" Center Channel xx1284 6540	2	0.562	36	6.5

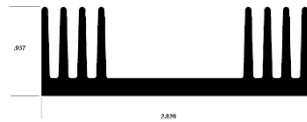


WKV Part Number	Description	Width	Height	Length	Thermal Resistance °C/w/3
127731	2.82" Wide x 12" Center Channel xx4306 15963	2.82	0.937	12	3.1
127789	2.82" Wide x 36" Center Channel xx4306 15963	2.82	0.937	36	3.1

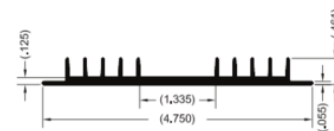

WKV Part Number	Description	Width	Height	Length	Thermal Resistance °C/w/3
127732	4.75" Wide x 12" Center Channel xx1327 6541	4.75	0.461	12	3.3
127790	4.75" Wide x 36" Center Channel xx1327 6541	4.75	0.461	36	3.3

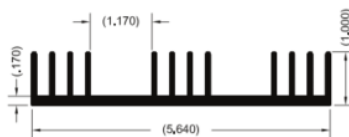


WKV Part Number	Description	Width	Height	Length	Thermal Resistance °C/w/3
127733	5.64" Wide x 12" Multi Channel 7999	5.64	1	12	2.26
127791	5.64" Wide x 36" Multi Channel 7999	5.64	1	36	2.26

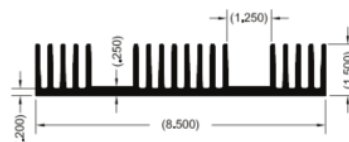


WKV Part Number	Description	Width	Height	Length	Thermal Resistance °C/w/3
127734	8.5" Wide x 12" Multi Channel xx5060 19223	8.5	1.5	12	0.87
127792	8.5" Wide x 36" Multi Channel xx5060 19223	8.5	1.5	36	0.87

Flatback w/ Mounting Feet Heat Sinks


- Dimensions: Inches
- Thermal Resistance based on 3 Inch Length in Natural Convection Setting

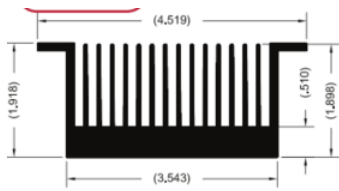


WKV Part Number	Description	Width	Height	Length	Thermal Resistance °C/w/3
127735	4.519" Wide x 12" Flatback w/mounting feet 19133	4.519	1.898	12	2.4
127793	4.519" Wide x 36" Flatback w/mounting feet 19133	4.519	1.898	36	2.4

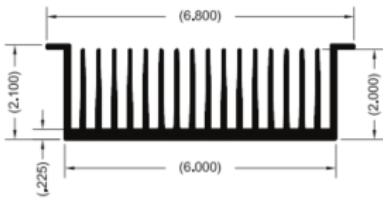


WKV Part Number	Description	Width	Height	Length	Thermal Resistance °C/w/3
127736	6.8" Wide x 12" Flatback w/ mounting feet 13994	6.8	2	12	0.9
127794	6.8" wide x 36" Flatback w/ mounting feet 13944	6.8	2	36	0.9

 


WKV Part Number	Description	Width	Height	Length	Thermal Resistance °C/w/3
127737	7.13" Wide x 12" Flatback w/mounting legs 21911	7.13	1.55	12	0.74
127795	7.13" Wide x 36" Flatback w/mounting legs 21911	7.13	1.55	36	0.74

 

WKV Part Number	Description	Width	Height	Length	Thermal Resistance °C/w/3
127738	7.62" Wide x 12" Flatback w/mounting feet 16493	7.62	1.655	12	1.24
127796	7.62" Wide x 36" Flatback w/mounting feet 16493	7.62	1.655	36	1.24

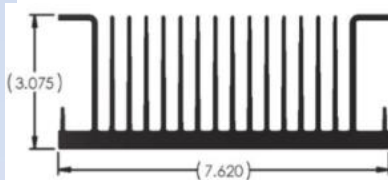

WKV Part Number	Description	Width	Height	Length	Thermal Resistance °C/w/3
127739	7.62" Wide x 12" Flatback w/mounting feet 16494	7.62	3.075	12	0.67
127797	7.62" Wide x 36" Flatback w/mounting feet 16494	7.62	3.075	36	0.67

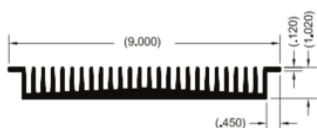

WKV Part Number	Description	Width	Height	Length	Thermal Resistance °C/w/3
127740	9.00" Wide x 12" Flatback w/ mounting feet 16922	9	1.02	12	2.1
127798	9.00" wide x 36" Flatback w/ mounting feet 16922	9	1.02	36	2.1

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Wakefield Thermal:](#)

[127726](#)